


Super-Size AkroBin® Lids

Industry-standard large capacity stacking bins

- Heavy-duty, industrial-grade polymer bins stack securely atop each other, even with lids in place
- Easy to carry with large handle molded onto back of bin

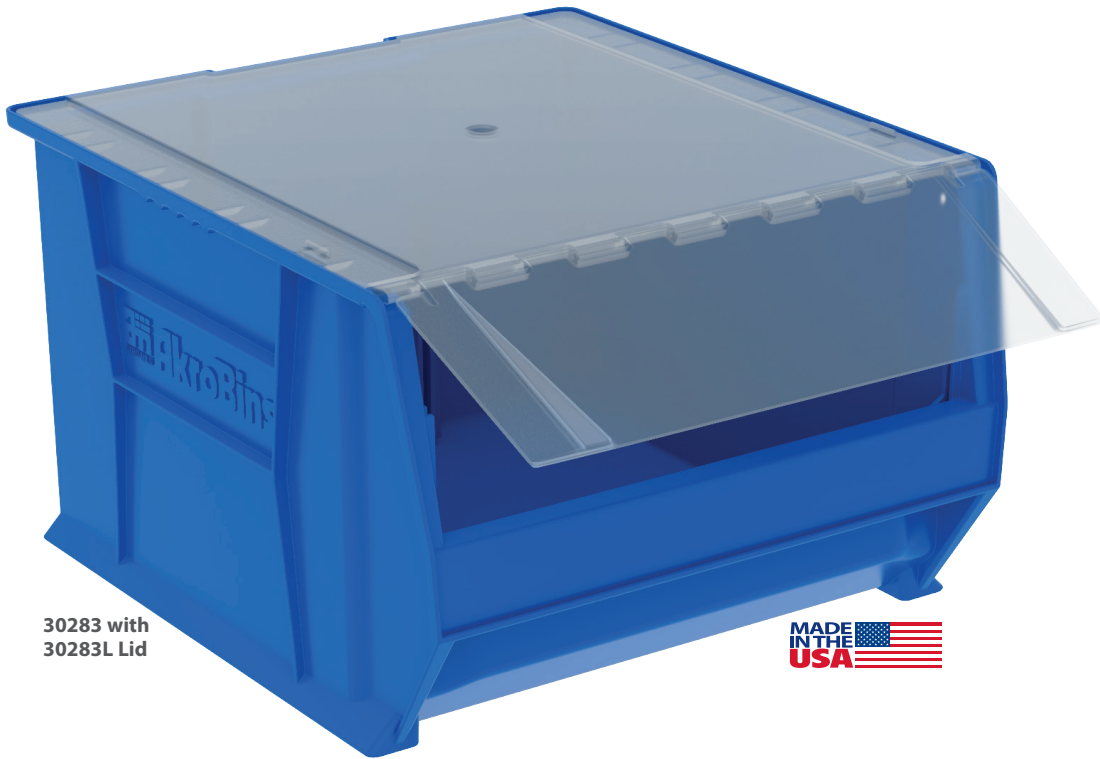

30283 with 30283L Lid



30292 with 29304
Card Stock Holder



30281 with 40281
Length Divider



30284 with 41284
Width Divider



30290 with 21283
Window



30293MOB
with Mobile Kit




Super-Size AkroBins	Outside Dimensions (In.)			Inside Dimensions (In.)				Capacity/Quantity			Accessories									
	Model No.	L	W	H	L	W	H	X	Max. Cap. per Bin	Stacking Cap./= Qty. Stacked	Ctn. Qty.	Width Dividers*	Length Dividers*	Divider Pkg. Qty. W L	Bin Lids	Lid Pkg. Qty.	Windows	Window Pkg. Qty.	Card Stock Holder	
30280	20	12-3/8	6	16-7/8	10-11/16	5-3/8	15-1/2		200 lbs.	40 lb./10	4	–	40280 (3)	–	2	30280L	4	21280	2	29304
30281	20	12-3/8	8	16-7/8	10-11/16	7-3/8	15-1/2		200 lbs.	50 lb./7	3	–	40281 (3)	–	3	30281L	3	21281	3	29304
30282	20	12-3/8	12	16-7/8	10-11/16	11-3/8	15-1/2		200 lbs.	60 lb./5	2	–	40282 (3)	–	1	30282L	2	21282	2	29304
30283	20	18-3/8	12	16-7/8	16-9/16	11-3/8	15-1/2		300 lbs.	150 lb./5	1	–	40282 (3)	–	1	30283L	1	21283	1	29304
30284	23-7/8	8-1/4	7	20-7/8	6-3/8	6-1/8	19-3/8		200 lbs.	150 lb./5	4	41284 (2)	40286 (1)	2	4	–	–	21284	4	29304
30286	23-7/8	11	7	20-7/8	9-1/8	6-1/8	19-5/16		200 lbs.	150 lb./5	4	41286 (2)	40286 (3)	2	4	30286L	4	21286	4	29304
30287	23-7/8	11	10	20-3/4	9	9-1/8	19-5/16		300 lbs.	150 lb./5	4	41287 (2)	40287 (3)	6	6	–	–	21287	4	29304
30288	23-7/8	16-1/2	11	20-3/4	14-3/8	10-1/8	19-5/16		300 lbs.	150 lb./5	1	41288 (2)	40287 (3)	6	6	–	–	21288	1	29304
30288MOB [‡]	Mobile 30288 bin with 3" locking casters**								200 lbs.	–	1	41288 (2)	40287 (3)	6	6	–	–	21288	1	29304
30289	23-7/8	18-1/4	12	20-3/4	16	11-1/8	19-1/4		300 lbs.	150 lb./5	1	41289 (2)	40289 (3)	2	1	–	–	21289	1	29304
30289MOB [‡]	Mobile 30289 bin with 3" locking casters**								200 lbs.	–	1	41289 (2)	40289 (3)	2	1	–	–	21289	1	29304
30290	29-1/4	18-3/8	12	26-1/8	16-9/16	11-3/8	24-3/4		300 lbs.	150 lb./5	1	–	40290 (3)	–	1	30290L	1	21283	1	29304
30290MOB [‡]	Mobile 30290 bin with 3" locking casters**								200 lbs.	–	1	–	40290 (3)	–	1	–	–	21283	1	29304
30292	29-7/8	11	10	26-3/4	9	9-1/8	25-5/16		300 lbs.	150 lb./5	4	41287 (2)	40292 (3)	6	6	–	–	21287	4	29304
30292MOB [‡]	Mobile 30292 bin with 3" locking casters**								200 lbs.	–	4	41287 (2)	40292 (3)	6	6	–	–	21287	4	29304
30293	29-7/8	16-1/2	11	26-3/4	14-3/8	10-1/8	25-5/16		300 lbs.	150 lb./5	1	41288 (2)	40292 (3)	6	6	–	–	21288	1	29304
30293MOB [‡]	Mobile 30293 bin with 3" locking casters**								200 lbs.	–	1	41288 (2)	40292 (3)	6	6	–	–	21288	1	29304

One color per carton: Specify Red, Blue, Yellow, Clear or Gray. Not recommended to hang on rack or panel systems. Order in carton quantities. * () = Max. # of divider slots per bin. †Assembly required. **Add 3" to overall height of bin with casters.

Super-Size AkroBin Shelving Systems

Super-Size AkroBin Wire Shelving Systems			Bin Dimensions (In.)			Shelf Dimensions (In.)			Quantity	
Model No.	Description	Super-Size AkroBin Colors	L	W	H	D	L	H	Bins	Shelves
AWS184830280	Wire Shelving w/ 30280 Bins	R, B, Y, SC	20	12-3/8	6	18	48	74	24	9
AWS184830281	Wire Shelving w/ 30281 Bins	R, B, Y, SC	20	12-3/8	8	18	48	74	18	7
AWS184830282	Wire Shelving w/ 30282 Bins	R, B, Y, SC	20	12-3/8	12	18	48	74	12	5
AWS184830283	Wire Shelving w/ 30283 Bins	R, B, Y, SC	20	18	12	18	48	74	8	5
AWS1848SAB	Wire Shelving w/ 30280, 281, 282, 283 Bins	R, B, Y, SC	See Above			18	48	74	4/3/4/4†	6
AWS24360284	Wire Shelving w/ 30284 Bins	R, B, Y, SC	23-7/8	8-1/4	7	24	36	74	28	8
AWS24360287	Wire Shelving w/ 30287 Bins	R, B, Y, SC	23-7/8	11	10	24	36	74	16†	6
AWS24360288	Wire Shelving w/ 30288 Bins	R, B, Y, SC	23-7/8	16-1/2	11	24	36	74	12	3
AWS24360SAB	Wire Shelving w/ 30287 & 30288 Bins	R, B, Y, SC	See Above			24	36	74	12/6†	3
AWS24361288	Wire Shelving w/ 30288 Bins	R, B, Y, SC	23-7/8	16-1/2	11	24	36	63	10	3

Bin color code: R=Red, B=Blue, Y=Yellow, SC=Clear. Specify one bin color when ordering. †Bonus bins included.

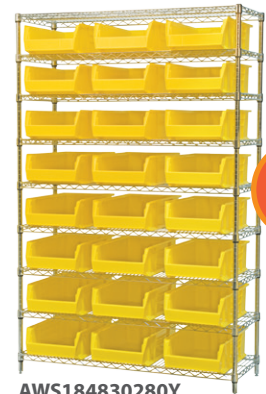

AWS184830280Y



AS3679292B

Super-Size AkroBin Steel Shelving Systems			Bin Dimensions (In.)			Shelf Dimensions (In.)			Quantity	
Model Number	Description	Super-Size AkroBin Colors	L	W	H	D	L	H	Bins	Shelves
AS2479284	24" Shelving with 30284 Bins	B, R, Y, SC	23-7/8	8-1/4	7	24	36	79	32†	9
AS2479287	24" Shelving with 30287 Bins	B, R, Y, SC	23-7/8	11	10	24	36	79	24†	3
AS2479288	24" Shelving with 30288 Bins	B, R, Y, SC	23-7/8	16-1/2	11	24	36	79	12	4
AS2479ASSORT	24" Shelving with 30287/30288 Bins	B, R, Y, SC	See Above			24	36	79	12/6	3
AS3679292	30" Shelving with 30292 Bins	B, R, Y, SC	29-7/8	11	10	30	36	79	24	3
AS3679293	30" Shelving with 30293 Bins	B, R, Y, SC	29-7/8	16-1/2	11	30	36	79	12	4
AS3679ASSORT	30" Shelving with 30292/30293 Bins	B, R, Y, SC	See Above			30	36	79	12/6	3

Bin color code: R=Red, B=Blue, Y=Yellow, SC=Clear. Specify one bin color when ordering. †Bonus bins included.

Super-Size AkroBin Dollies & Carts

Super-Size AkroBin Steel Dollies		Dimensions (In.)			Capacity/Quantity		
Model No.	Bin Compatibility	L	W	H	Casters	Ctn. Qty.	Capacity
RU843HR2018	30280, 30281, 30282 & 30283 Bins - Fits 1 wide	17-13/16	18-3/8	4-11/16	3" Polyolefin	1	900 lbs.
RU843HR2918	30290 Bins - Fits 1 wide	26-13/16	18-3/8	4-11/16	3" Polyolefin	1	900 lbs.
RU843TP2122	30286 & 30287 Bins - Fits 2 wide	20-7/8	21-7/8	4-11/16	3" Polyolefin	1	900 lbs.
RU843TP2227	30292 Bins - Fits 2 wide	21-7/8	26-7/8	4-11/16	3" Polyolefin	1	900 lbs.
RU843TP1721	30284 Bins - Fits 2 wide 30288 Bins - Fits 1 wide	16-1/2	20-7/8	4-11/16	3" Polyolefin	1	900 lbs.
RU843TP1727	30293 Bins - Fits 1 wide	16-1/2	26-7/8	4-11/16	3" Polyolefin	1	900 lbs.
RU843TP1821	30289 Bins - Fits 1 wide	18-1/2	20-7/8	4-11/16	3" Polyolefin	1	900 lbs.

Bins sold separately.



RU843TP1721 with 30284RED

Super-Size AkroBin Steel Carts		Dimensions (In.)			Accessories		Capacity/Qty.	
Model No.	Bin Compatibility	L	W	H	No. of Handles	Security Bar	Capacity (lbs.)	Ctn. Qty.
R214CS1841	Six 30283 Bins	41	18	48	2	RSSAKBINHDDWN6	900	1
R214CS1859	Nine 30283 Bins	59	18	48	2	RSSAKBINHDDWN9	1350	1
R214CS1878	Twelve 30283 Bins	78	18	48	2	RSSAKBINHDDWN12	1500	1
R214CS2841	Six 30290 Bins	41	27-1/2	48	2	RSSAKBINHDDWN6	900	1
R214CS2859	Nine 30290 Bins	59	27-1/2	48	2	RSSAKBINHDDWN9	1350	1
R214CS2878	Twelve 30290 Bins	78	27-1/2	48	2	RSSAKBINHDDWN12	1500	1
R216CS2236	Sixteen 30284 Bins or six 30286 Bins or six 30287 Bins or four 30288 Bins	35-1/2	22-1/8	35	1	-	900	1
R216CS2836	Six 30292 Bins or four 30293 Bins	35-1/2	28-1/8	35	1	-	900	1
R216CS2239	Four 30289 Bins	35-1/2	22-1/8	39	1	-	900	1

Optional security bar available for all sizes. Bins sold separately.



R214CS1878 with 30283BLUE and RSSAKBINHDDWN12



akro-mils.com

1293 South Main Street, Akron, Ohio 44301 • Tel: 800.253.2467 • Fax: 330.761.6348 • sales@akro-mils.com
 In Canada: Ak-West, Inc. • Tel: 877.979.8940 • Fax: 403.225.1696 • sales@ak-westinc.com • ak-westinc.com

