

Wire Shelving

INDUSTRIAL

HEALTHCARE

RETAIL

FEATURES

STRONG – Heavy gauge steel construction with durable nickel-chrome finish for use in dry storage applications.


VERSATILE – Akro-Mils wire shelving is perfect for almost any industrial, healthcare or retail setting. A wide range of accessories allows for countless configurations to adapt to your exact needs.

FUNCTIONAL – The open wire design prevents dust accumulation on shelves and allows light to pass through for better visibility of stored items. Deck wires run front-to-back to allow you to easily slide items on and off shelves.


EASY TO ASSEMBLE – Posts have double rings every 5" for quick shelf alignment. Shelving units are assembled in minutes and no special tools are required.

ADJUSTABLE – Quick-Adjust Clips lock onto shelf posts and unlock to adjust shelves in 1" increments. Posts included leveling feet to compensate for uneven surfaces.

NSF-Certified – Assurance that the shelving complies with strict standards for quality and safety.

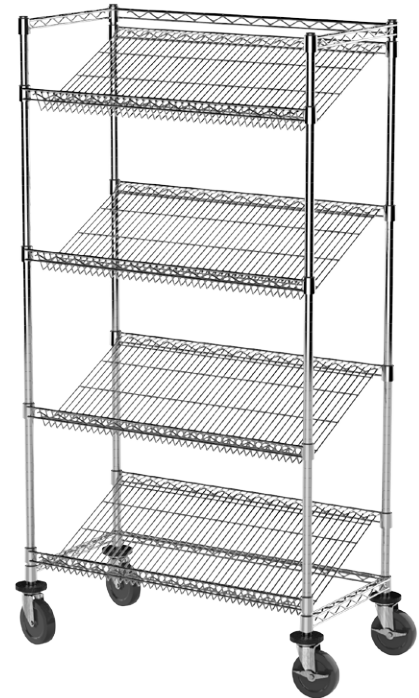

Available Shelf Sizes

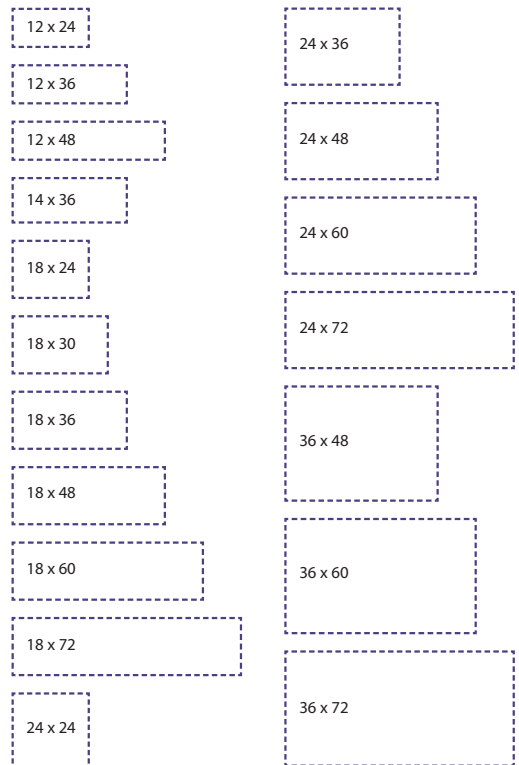

Wire Shelving Components

Wire Shelves - Plastic Quick-Adjust Clips included with each shelf. (replacement part: AWCLIP4PK).

Weight Capacity (evenly distributed) per shelf:


- Lengths up to 48" = 800 lbs.
- Lengths over 48" = 600 lbs.

Weight Capacity (evenly distributed) per stationary shelving unit = 2,000 lbs.


Construction:

- Frame Wire = 6.0mm
- Deck Wire = 3.3mm
- Truss Wire = 4.5mm

Wire Shelves - Chrome				
Model No.	Description	Ctn. Qty.	Unit Weight	Weight Cap.
AWS1224SHELF	12" x 24" Horizontal Wire Shelf	4	4.75	800
AWS1236SHELF	12" x 36" Horizontal Wire Shelf	4	6.75	800
AWS1248SHELF	12" x 48" Horizontal Wire Shelf	4	8.5	800
AWS1436SHELF	14" x 36" Horizontal Wire Shelf	4	7.5	800
AWS1824SHELF	18" x 24" Horizontal Wire Shelf	4	6.25	800
AWS1830SHELF	18" x 30" Horizontal Wire Shelf	4	7.25	800
AWS1836SHELF	18" x 36" Horizontal Wire Shelf	4	8.5	800
AWS1848SHELF	18" x 48" Horizontal Wire Shelf	4	11.5	800
AWS1860SHELF	18" x 60" Horizontal Wire Shelf	2	15	600
AWS1872SHELF	18" x 72" Horizontal Wire Shelf	2	17.5	600
AWS2424SHELF	24" x 24" Horizontal Wire Shelf	4	7.75	800
AWS2436SHELF	24" x 36" Horizontal Wire Shelf	4	11.25	800
AWS2448SHELF	24" x 48" Horizontal Wire Shelf	4	14.25	800
AWS2460SHELF	24" x 60" Horizontal Wire Shelf	2	19.5	600
AWS2472SHELF	24" x 72" Horizontal Wire Shelf	2	23	600
AWS3648SHELF	36" x 48" Horizontal Wire Shelf	2	22	800
AWS3660SHELF	36" x 60" Horizontal Wire Shelf	2	29	600
AWS3672SHELF	36" x 72" Horizontal Wire Shelf	2	34.5	600

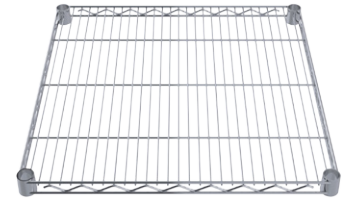

Horizontal Shelf

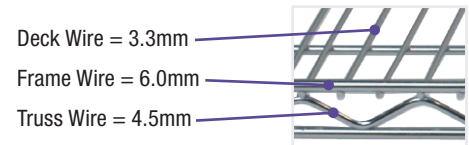

Posts - Posts feature a double-ring visual indicator for proper shelf spacing during assembly. Adjustment rings every 1". Posts have double rings every 5" for quick shelf alignment.

Posts include a Leveling Foot to compensate for uneven surfaces. (Replacement part: AWFOOTLEVEL4PK). Post height includes Leveling Foot fully tightened.

Optional Footplates are available and can be installed separately in place of Leveling Feet (Part number: AWFOOTPLATE4PK).

All posts include a plastic post top cap and a 3/8"-16 threaded base insert for installing feet and casters.

Construction:

- 1" O.D. tube
- 18 gauge tube wall


Wire Shelving Posts - Chrome				
Model No.	Description	Ctn. Qty.	Unit Weight	Weight Cap.
AWP34UPRIGHT	34" Shelf Post	4	1.5	-
AWP54UPRIGHT	54" Shelf Post	4	2.5	-
AWP63UPRIGHT	63" Shelf Post	4	2.75	-
AWP74UPRIGHT	74" Shelf Post	4	3.25	-
AWP86UPRIGHT*	86" Shelf Post	4	3.75	-
AWP96UPRIGHT*	96" Shelf Post	4	4	-

*2-piece post; requires assembly.

Double Ring



Shelf Posts

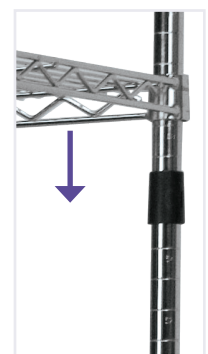

Posts include Leveling Foot

Wire Shelving Components

Slanted Shelves - Plastic Quick-Adjust Clips included with each shelf. (replacement part: AWCLIP4PK).

Weight Capacity (evenly distributed) per shelf = 400 lbs.


Shelf Angle (installed) = 27°

Construction:

- Frame Wire = 6.0mm
- Deck Wire = 3.3mm
- Truss Wire = 4.5mm

Always use 3-sided frame to support bottom slanted shelf and standard wire shelf for top shelf.


Slanted Wire Shelves - Chrome				
Model No.	Description	Ctn. Qty.	Unit Weight	Weight Cap.
AW51836SL	18" x 36" Slanted Wire Shelf	4	8.5	400
AW51848SL	18" x 48" Slanted Wire Shelf	4	11.25	400
AW52436SL	24" x 36" Slanted Wire Shelf	4	9.75	400
AW52448SL	24" x 48" Slanted Wire Shelf	4	12.75	400

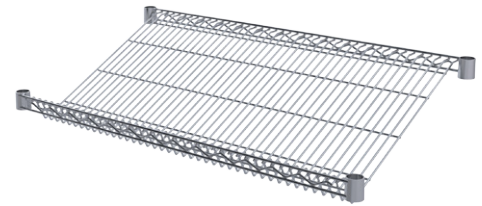


Slanted Shelf

3-Sided Frame - Adds support to slanted shelving units and other applications where full shelf is not required.

Wire Shelving Frames - Chrome				
Model No.	Description	Ctn. Qty.	Unit Weight	Weight Cap.
AW1836FRAME	Set of 2 - 3-Sided Frame 18 x 36	2	6	-
AW1848FRAME	Set of 2 - 3-Sided Frame 18 x 48	2	7	-
AW2436FRAME	Set of 2 - 3-Sided Frame 24 x 36	2	7	-
AW2448FRAME	Set of 2 - 3-Sided Frame 24 x 48	2	8.5	-

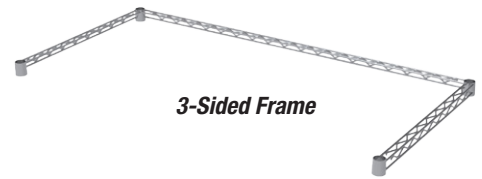

3-Sided Frame

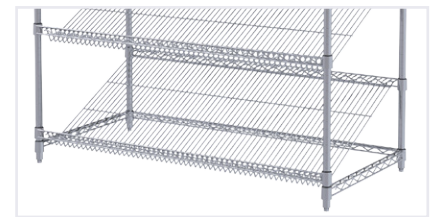

Wall-Mount Shelving Brackets -

Fixed: Mount brackets directly to wall. Mounting hardware included (alternate hardware may be required based on mounting surface).


Adjustable: Brackets attach to wall-mounted posts with 1" adjustment increments (posts sold separately).

Use double shelf brackets to make continuous runs of shelving.

Weight Capacity (evenly distributed) per pair of brackets = 250 lbs.

Wire Shelving Wall Mounting Brackets - Chrome				
Model No.	Description	Ctn. Qty.	Unit Weight	Weight Cap.**
AW18SPBKT*	18" Single Adj. Post Bracket	4	2	250
AW18DPBKT*	18" Double Adj. Post Bracket	4	3.5	250
AW24SPBKT*	24" Single Adj. Post Bracket	4	2.5	250
AW24DPBKT*	24" Double Adj. Post Bracket	4	4.5	250
AW18SWBKT	18" Single Fixed Wall Bracket	4	2	250
AW18DWBKT	18" Double Fixed Wall Bracket	4	3.5	250
AW24SWBKT	24" Single Fixed Wall Bracket	4	2.25	250
AW24DWBKT	24" Double Fixed Wall Bracket	4	4.5	250


Wall mounting hardware included. Wire shelves sold separately. *Posts sold separately. **Weight capacity = lbs. per set of 2

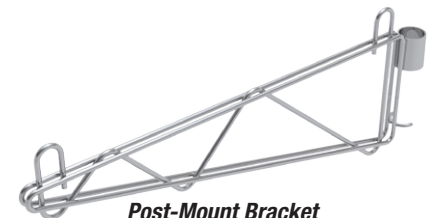

Post-Mount Bracket



Wall-Mount Bracket

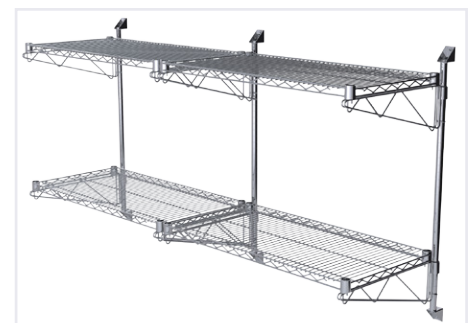

Wire Shelving Starter Units

Heavy-duty wire shelving units prevent dust accumulation and improve visibility of stored items. Assembles in minutes. No tools required.

Shelf Weight Capacity:

- 800 lbs. for shelf lengths up to 48"
- 600 lbs. for shelf lengths over 48"

Units Include:

4 - chrome wire shelves with Quick-Adjust Post Sleeves, 4 - posts with Leveling Feet, 1 - 8 pack of "S" Hooks for creating continuous shelving runs or 90° angles.

Wire Shelving Starter Units - 54" High		Components				
Model No.	Description	Post Qty.	Shelf Qty.	"S" Hook Qty.	Unit Weight	Weight Cap.
AWS541224SU	54" High 12" x 24" Starter Unit	4	4	1-8 Pack	30	3200
AWS541236SU	54" High 12" x 36" Starter Unit	4	4	1-8 Pack	38	3200
AWS541248SU	54" High 12" x 48" Starter Unit	4	4	1-8 Pack	45	3200
AWS541436SU	54" High 14" x 36" Starter Unit	4	4	1-8 Pack	41	3200
AWS541824SU	54" High 18" x 24" Starter Unit	4	4	1-8 Pack	36	3200
AWS541830SU	54" High 18" x 30" Starter Unit	4	4	1-8 Pack	40	3200
AWS541836SU	54" High 18" x 36" Starter Unit	4	4	1-8 Pack	45	3200
AWS541848SU	54" High 18" x 48" Starter Unit	4	4	1-8 Pack	57	3200
AWS541860SU	54" High 18" x 60" Starter Unit	4	4	1-8 Pack	41	2400
AWS541872SU	54" High 18" x 72" Starter Unit	4	4	1-8 Pack	46	2400
AWS542424SU	54" High 24" x 24" Starter Unit	4	4	1-8 Pack	42	2400
AWS542436SU	54" High 24" x 36" Starter Unit	4	4	1-8 Pack	56	2400
AWS542448SU	54" High 24" x 48" Starter Unit	4	4	1-8 Pack	68	2400
AWS542460SU	54" High 24" x 60" Starter Unit	4	4	1-8 Pack	50	2400
AWS542472SU	54" High 24" x 72" Starter Unit	4	4	1-8 Pack	57	2400
AWS543648SU	54" High 36" x 48" Starter Unit	4	4	1-8 Pack	55	2400
AWS543660SU	54" High 36" x 60" Starter Unit	4	4	1-8 Pack	69	2400
AWS543672SU	54" High 36" x 72" Starter Unit	4	4	1-8 Pack	80	2400



Wire Shelving Starter Units - 63"		Components				
Model No.	Description	Post Qty.	Shelf Qty.	"S" Hook Qty.	Unit Weight	Weight Cap.
AWS631224SU	63" High 12" x 24" Starter Unit	4	4	1-8 Pack	32	3200
AWS631236SU	63" High 12" x 36" Starter Unit	4	4	1-8 Pack	40	3200
AWS631248SU	63" High 12" x 48" Starter Unit	4	4	1-8 Pack	47	3200
AWS631436SU	63" High 14" x 36" Starter Unit	4	4	1-8 Pack	43	3200
AWS631824SU	63" High 18" x 24" Starter Unit	4	4	1-8 Pack	38	3200
AWS631830SU	63" High 18" x 30" Starter Unit	4	4	1-8 Pack	42	3200
AWS631836SU	63" High 18" x 36" Starter Unit	4	4	1-8 Pack	47	3200
AWS631848SU	63" High 18" x 48" Starter Unit	4	4	1-8 Pack	59	3200
AWS631860SU	63" High 18" x 60" Starter Unit	4	4	1-8 Pack	43	2400
AWS631872SU	63" High 18" x 72" Starter Unit	4	4	1-8 Pack	48	2400
AWS632424SU	63" High 24" x 24" Starter Unit	4	4	1-8 Pack	44	2400
AWS632436SU	63" High 24" x 36" Starter Unit	4	4	1-8 Pack	58	2400
AWS632448SU	63" High 24" x 48" Starter Unit	4	4	1-8 Pack	70	2400
AWS632460SU	63" High 24" x 60" Starter Unit	4	4	1-8 Pack	52	2400
AWS632472SU	63" High 24" x 72" Starter Unit	4	4	1-8 Pack	59	2400
AWS633648SU	63" High 36" x 48" Starter Unit	4	4	1-8 Pack	57	2400
AWS633660SU	63" High 36" x 60" Starter Unit	4	4	1-8 Pack	71	2400
AWS633672SU	63" High 36" x 72" Starter Unit	4	4	1-8 Pack	82	2400



Wire Shelving Starter Units

Heavy-duty wire shelving units prevent dust accumulation and improve visibility of stored items. Assembles in minutes. No tools required.


Shelf Weight Capacity:

- 800 lbs. for shelf lengths up to 48"
- 600 lbs. for shelf lengths over 48"


Units Include:

4 - chrome wire shelves with Quick-Adjust Post Sleeves, 4 - posts with Leveling Feet, 1 - 8 pack of "S" Hooks for creating continuous shelving runs or 90° angles.

Wire Shelving Starter Units - 74" High		Components				
Model No.	Description	Post Qty.	Shelf Qty.	"S" Hook Qty.	Unit Weight	Weight Cap.
AWS741224SU	74" High 12" x 24" Starter Unit	4	4	1-8 Pack	34	3200
AWS741236SU	74" High 12" x 36" Starter Unit	4	4	1-8 Pack	42	3200
AWS741248SU	74" High 12" x 48" Starter Unit	4	4	1-8 Pack	49	3200
AWS741436SU	74" High 14" x 36" Starter Unit	4	4	1-8 Pack	45	3200
AWS741824SU	74" High 18" x 24" Starter Unit	4	4	1-8 Pack	40	3200
AWS741830SU	74" High 18" x 30" Starter Unit	4	4	1-8 Pack	44	3200
AWS741836SU	74" High 18" x 36" Starter Unit	4	4	1-8 Pack	49	3200
AWS741848SU	74" High 18" x 48" Starter Unit	4	4	1-8 Pack	61	3200
AWS741860SU	74" High 18" x 60" Starter Unit	4	4	1-8 Pack	45	2400
AWS741872SU	74" High 18" x 72" Starter Unit	4	4	1-8 Pack	50	2400
AWS742424SU	74" High 24" x 24" Starter Unit	4	4	1-8 Pack	46	2400
AWS742436SU	74" High 24" x 36" Starter Unit	4	4	1-8 Pack	60	2400
AWS742448SU	74" High 24" x 48" Starter Unit	4	4	1-8 Pack	72	2400
AWS742460SU	74" High 24" x 60" Starter Unit	4	4	1-8 Pack	54	2400
AWS742472SU	74" High 24" x 72" Starter Unit	4	4	1-8 Pack	61	2400
AWS743648SU	74" High 36" x 48" Starter Unit	4	4	1-8 Pack	59	2400
AWS743660SU	74" High 36" x 60" Starter Unit	4	4	1-8 Pack	73	2400
AWS743672SU	74" High 36" x 72" Starter Unit	4	4	1-8 Pack	84	2400

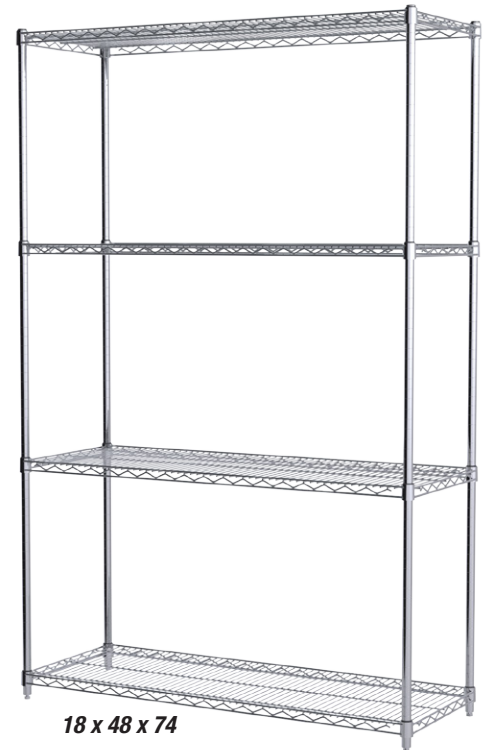

Wire Shelving Starter Units - 86" High		Components				
Model No.	Description	Post Qty.	Shelf Qty.	"S" Hook Qty.	Unit Weight	Weight Cap.
AWS861224SU	86" High 12" x 24" Starter Unit	4	4	1-8 Pack	35	3200
AWS861236SU	86" High 12" x 36" Starter Unit	4	4	1-8 Pack	43	3200
AWS861248SU	86" High 12" x 48" Starter Unit	4	4	1-8 Pack	50	3200
AWS861436SU	86" High 14" x 36" Starter Unit	4	4	1-8 Pack	46	3200
AWS861824SU	86" High 18" x 24" Starter Unit	4	4	1-8 Pack	41	3200
AWS861830SU	86" High 18" x 30" Starter Unit	4	4	1-8 Pack	45	3200
AWS861836SU	86" High 18" x 36" Starter Unit	4	4	1-8 Pack	50	3200
AWS861848SU	86" High 18" x 48" Starter Unit	4	4	1-8 Pack	62	3200
AWS861860SU	86" High 18" x 60" Starter Unit	4	4	1-8 Pack	46	2400
AWS861872SU	86" High 18" x 72" Starter Unit	4	4	1-8 Pack	51	2400
AWS862424SU	86" High 24" x 24" Starter Unit	4	4	1-8 Pack	47	2400
AWS862436SU	86" High 24" x 36" Starter Unit	4	4	1-8 Pack	61	2400
AWS862448SU	86" High 24" x 48" Starter Unit	4	4	1-8 Pack	73	2400
AWS862460SU	86" High 24" x 60" Starter Unit	4	4	1-8 Pack	55	2400
AWS862472SU	86" High 24" x 72" Starter Unit	4	4	1-8 Pack	62	2400
AWS863648SU	86" High 36" x 48" Starter Unit	4	4	1-8 Pack	60	2400
AWS863660SU	86" High 36" x 60" Starter Unit	4	4	1-8 Pack	74	2400
AWS863672SU	86" High 36" x 72" Starter Unit	4	4	1-8 Pack	85	2400

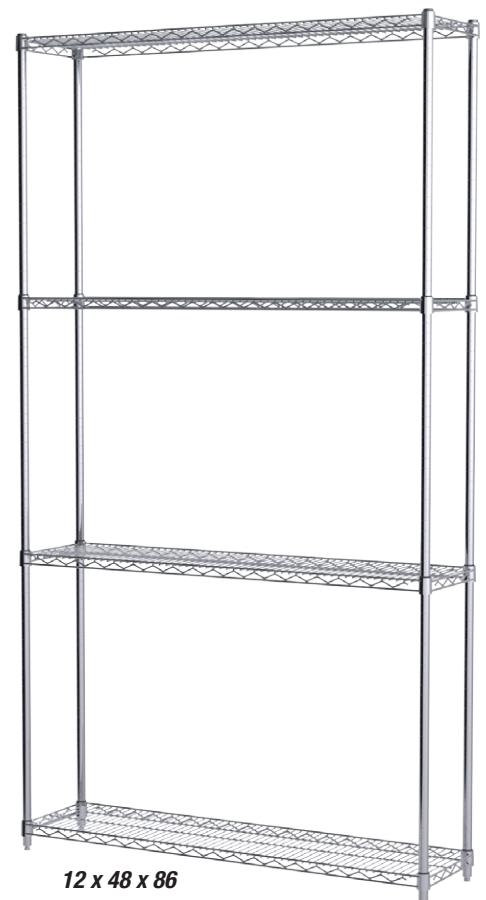

= Most Popular Models

Slanted Shelf Starter Units / Wire Utility Carts

Mobile Slanted Shelf Starter Units - Heavy-duty wire shelving units. Shelves adjust in 1" increments. Unit height = 68". Shelf Angle (installed) = 27°

Mobile Slanted Shelf Starter Units		Components			
Model No.	Description	Post Qty.	Shelf Qty.	Unit Weight	Weight Cap.
AWS1836SLMU	18" x 36" Mobile Starter Unit	4	4	65	500
AWS1848SLMU	18" x 48" Mobile Starter Unit	4	4	78	500
AWS2436SLMU	24" x 36" Mobile Starter Unit	4	4	72	500
AWS2448SLMU	24" x 48" Mobile Starter Unit	4	4	87	500

Units Include:
4 - chrome slanted wire shelves with Quick-Adjust Post Sleeves, 4 - posts with Leveling Feet, 2 - 3-Sided Frames, 5" swivel casters - 2 with brakes; 2 without brakes, 4 - Donut Bumpers.



Mobile Slanted Shelf Unit

Mobile Wire Utility Carts - All-purpose utility carts with chrome finish. All components come ready to assemble in a single convenient carton. Shelves adjust in 1" increments. Cart height = 38-3/8".

Mobile Wire Utility Carts				
Model No.	Description	Ctn. Qty.	Unit Weight	Weight Cap.
AWCART18362	18" x 36" 2-Shelf Cart	1	34	500
AWCART24362	24" x 36" 2-Shelf Cart	1	43.5	500
AWCART24482	24" x 48" 2-Shelf Cart	1	50	500
AWCART18363	18" x 36" 3-Shelf Cart	1	40	500
AWCART24363	24" x 36" 3-Shelf Cart	1	55	500
AWCART24483	24" x 48" 3-Shelf Cart	1	64	500

Units Include:
2 - Handle with Posts, wire shelves with Quick-Adjust Post Sleeves, 5" swivel casters, 2 with brakes; 2 without brakes, 4 - Donut Bumpers.



3-Shelf Cart

Optional Shelf Ledges and Shelf Dividers available.

Push Handles - Add a handle to easily push and maneuver mobile wire shelving units.

Wire Shelving Handles - Chrome				
Model No.	Description	Ctn. Qty.	Unit Weight	Weight Cap.
AWPHDL18*	18" Push Handle	2	1.5	-
AWPHDL24*	24" Push Handle	2	2	-
AWUHDL18	Handle with 2 Posts 18"	2	4	-
AWUHDL24	Handle with 2 Posts 24"	2	4	-

*Quick-Adjust Clips included with each handle.



Push Handle

Handle with Posts - Create wire shelf utility carts. Height of posts plus handle = 33".



Handle with Posts

Swivel Casters - Create mobile shelving units and carts with these swivel caster sets. 2 with brakes, 2 without brakes.

Caster Sets				
Model No.	Description	Pkg. Qty.	Unit Weight	Weight Cap.*
AWPCAST4	Set of 4 Casters - 2 w/Brakes 100 x 25 (4")	1	5	400
AWPCAST5	Set of 4 Casters - 2 w/Brakes 125 x 25 (5")	1	6.5	500

*Weight capacity = per set of 4




Swivel Casters

Add 3" rubber Donut Bumpers to prevent damage to carts and walls.

Wire Shelving Components

Shelf Liner Mat - 1mm thick clear polypropylene mat keeps small items from falling through shelves and prevents dust accumulation on shelves below.

Wire Shelving Shelf Liner Mats				
Model No.	Description	Ctn. Qty.	Unit Weight	Weight Cap.
AW1224LINER	12" x 24" Shelf Liner	4	0.75	-
AW1236LINER	12" x 36" Shelf Liner	4	0.75	-
AW1248LINER	12" x 48" Shelf Liner	4	1.25	-
AW1824LINER	18" x 24" Shelf Liner	4	1	-
AW1836LINER	18" x 36" Shelf Liner	4	1.25	-
AW1848LINER	18" x 48" Shelf Liner	4	1.75	-
AW1860LINER	18" x 60" Shelf Liner	4	2	-
AW1872LINER	18" x 72" Shelf Liner	4	2.5	-
AW2424LINER	24" x 24" Shelf Liner	4	1.25	-
AW2436LINER	24" x 36" Shelf Liner	4	1.75	-
AW2448LINER	24" x 48" Shelf Liner	4	2.25	-
AW2460LINER	24" x 60" Shelf Liner	4	2.75	-
AW2472LINER	24" x 72" Shelf Liner	4	3.25	-
AW3660LINER	36" x 60" Shelf Liner	4	4	-
AW3672LINER	36" x 72" Shelf Liner	4	5	-

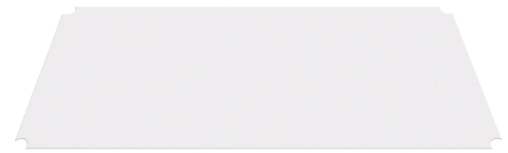


Shelf Liner Mat



Shelf Ledge - Slides onto edges of shelves. Prevent items from falling off sides and back of shelving. Great for carts and mobile units!

Side & Back Shelf Ledges - Chrome				
Model No.	Description	Ctn. Qty.	Unit Weight	Weight Cap.
AWLEDGE12	12" Wire Shelf Ledge	4	0.75	-
AWLEDGE18	18" Wire Shelf Ledge	4	1	-
AWLEDGE24	24" Wire Shelf Ledge	4	1.25	-
AWLEDGE36	36" Wire Shelf Ledge	4	1.75	-
AWLEDGE48	48" Wire Shelf Ledge	4	2.25	-
AWLEDGE60	60" Wire Shelf Ledge	4	2.75	-
AWLEDGE72	72" Wire Shelf Ledge	4	3.25	-

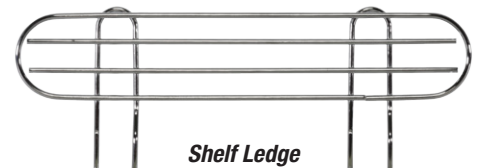

Shelf Ledge



Universal Plastic Divider - Plastic Shelf Divider easily clips on to shelving to create separated storage sections. Secure and easily adjustable. Dividers work with steel shelving too!

Wire Shelving Shelf Dividers - Plastic				
Model No.	Description	Pkg. Qty.	Pkg. Weight	Weight Cap.
45612	12" Plastic Shelf Divider (6-Pk)	6	1.8	-
45618	18" Plastic Shelf Divider (6-Pk)	6	2.3	-
45624	24" Plastic Shelf Divider (6-Pk)	6	3.2	-




Plastic Shelf Divider




Wire Shelf Divider - Create separated sections on shelves. Keep stacks of items from falling over.

Wire Shelving Shelf Dividers - Chrome				
Model No.	Description	Ctn. Qty.	Unit Weight	Weight Cap.
AWDIVER12	12" Wire Shelf Divider	4	1.25	-
AWDIVER18	18" Wire Shelf Divider	4	1.75	-
AWDIVER24	24" Wire Shelf Divider	4	1.75	-
AWDIVER36	36" Wire Shelf Divider	4	2.25	-

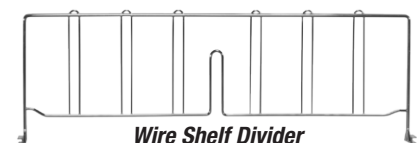

Wire Shelf Divider

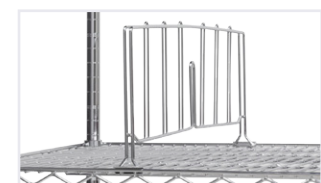

Wire Shelving Accessories

Leveling Feet - Levels shelving units on uneven surfaces.

Steel Feet Immobilizers - Provides extra stability; allows shelving units to be secured to the floor.


Donut Bumper - Keeps mobile units from damaging walls.

"S" Hooks - Allow for continuous runs of shelving or 90° angles. Use two hooks per shelf where posts are not used.

Quick-Adjust Clips - For assembling shelves to posts.

Post Clamps - Attach two units together for extra stability.

Wire Shelving Accessories				
Model No.	Description	Pkg. Qty.	Unit Weight	
AWFOOTLEVEL4PK	Set of 4 Leveling Steel Feet	4	0.095	
AWFOOTPLATE4PK	Set of 4 Steel Feet Immobilizers	4	0.145	
AWDONUT3	Donut Bumper 3"	1	0.1385	
AWSHOOK8PK	Set of 8 "S" Hooks	8	0.13	
AWCLIP4PK	Set of 4 Quick-Adjust Clips	4	0.104	
AWCLAMP2PK	Set of 2 Post Clamps	2	0.1975	

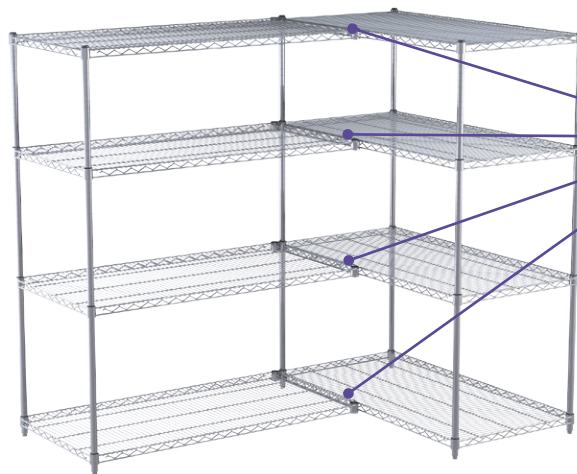

Leveling Feet



Steel Feet Immobilizers



Donut Bumper



"S" Hooks



Quick-Adjust Clips



Post Clamps



Angle•Vu™ Adjustable Label Holder - Snaps securely to the face of wire shelving units and can be easily adjusted to the proper viewing angle for any shelf height.

Angle-Vu	Dimensions (In.)		Total No.			
	Model No.	W	H	Cards Per Sheet	Sheets Per Pack	Cards Per Pack
29306	3	1¼	16	3	48	25



Angle•Vu Label Holder



Flat Label Holder - Attaches to the face of wire shelving units.

Flat Label Holder	Dimensions (In.)		Total No.			
	Model No.	W	H	Cards Per Sheet	Sheets Per Pack	Cards Per Pack
29308	3	1¼	16	3	48	25



Flat Label Holder



akro-mils.com

1293 South Main Street, Akron, Ohio 44301 • Tel: 800.253.2467 • Fax: 330.761.6348 • sales@akro-mils.com
 In Canada: Ak-West, Inc. • Tel: 877.979.8940 • Fax: 403.225.1696 • sales@ak-westinc.com • ak-westinc.com