

Perlator®

Faucet Aerator - 1.8 gpm

Flow Restricted Regular Size



flow, stop and go®

Features and Benefits

- ▶ Watercolours® design: Color coding to identify flow rate and stream pattern.
- ▶ Patented construction provides splash-free stream, well-aerated and soft to the touch.
- ▶ Integrated anti-liming honeycomb replaces conventional wire mesh screens prone to lime build up.
- ▶ Anti-clogging dome screen filters sediment and particles.
- ▶ Compatible with regular and vandal proof M22 & M24 metric housings.
- ▶ Available housing finishes: chrome, polished brass, brushed nickel and oil rubbed bronze.
- ▶ Laser marked housings with statutory marks.

Certifications

ANSI/NSF®-61-372
 ASME A112.18.1M and CSA B125
 Meets **CALGreen** requirements



Thread & Part Number

Part #	Designation	Thread Size	Qty.
5512905	Insert only		1
5509305	Regular male	15/16"-27	1
5509405	Regular female	55/64"-27	1
5509505	Regular dual thread	15/16"-27 x 55/64"-27	1
5509503	Regular dual thread	15/16"-27 x 55/64"-27	6
5509504	Regular dual thread	15/16"-27 x 55/64"-27	50
5509605	Vandal proof regular male	15/16"-27	1
5509705	Vandal proof regular dual thread	15/16"-27 x 55/64"-27	1
5509706	Vandal proof regular dual thread	15/16"-27 x 55/64"-27	40

Color Code

Dome	Ring	Basket
Brown	Natural	Dark Gray

Flow Rate Curve

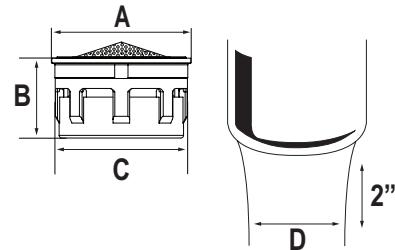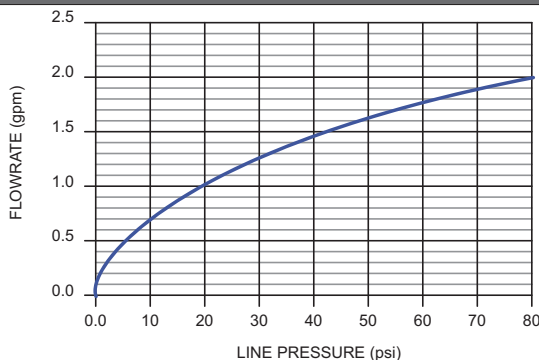

Dimensions

No	mm	In
A	20.88	.822
B	12.00	.472
C	19.97	.786
D	≈ 13	≈ 1/2

Housings



Technical Data

Materials: Body Acetal
 O-ring EPDM
 Washer EPDM

Continuous

Short-term (5 minutes max.)
 Per ASME A112.18.1 testing requirements.

