



MADE IN TACOMA
 — SINCE 1916 —
Rite in the Rain®
 = DEFYING MOTHER NATURE =

**Made in America for a century,
Rite in the Rain All-Weather Products
 Defy Mother Nature & Resist Father Time.**

Professionals in the field need reliable tools. They work hard to meet deadlines regardless of tough working conditions. Why would they carry anything to the job site that's not up for that same challenge?

— *featured products* —

**STAPLED
 NOTEBOOKS**

**WRITING
 INSTRUMENTS
 &
 REFILLS**

BOOK COVERS

— *additional* —

PRODUCT FLYERS AVAILABLE



**RITE IN THE RAIN
 SELLING TOOLS & TIPS
 INDUSTRY GROUPS**



**SIDE-SPIRAL &
 TOP-SPIRAL NOTEBOOKS
 WRITING INSTRUMENTS**



**HARD COVER BOOKS
 COPIER PAPER
 INDEX CARDS**



**SOFT COVER BOOKS
 BINDERS & LOOSE LEAF
 PLANNER & CALENDAR**

3¼" x 4⅝" MINI-STAPLED NOTEBOOKS (3 PACK)

		DESCRIPTION	ITEM N ^o	PAGE PATTERN	#'D PAGES	MFG. N ^o
	N ^o 38TD86	Sheet Size: 3¼" x 4⅝" Overall Size: 3¼" x 4⅝" x ⅛" Cover Material: Field-Flex Pages: 24 pages/12 sheets Binding: Saddle-stitched Paper Weight: 32# <i>Rite in the Rain</i> Rulers: Imperial & Metric Weight: 0.05 lbs	38TD86	Universal	✓	371FX-M
	N ^o 48RE09		48RE09	Universal	✓	771FX-M

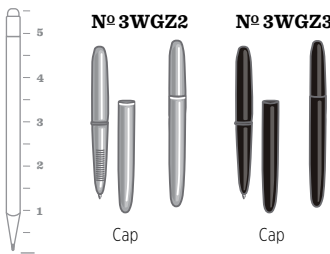

4⅝" x 7" STAPLED NOTEBOOKS (3 PACK)

		DESCRIPTION	ITEM N ^o	PAGE PATTERN	#'D PAGES	MFG. N ^o
	N ^o 38TD91	Sheet Size: 4⅝" x 7" Overall Size: 4⅝" x 7" x ¼" Cover Material: Field-Flex Pages: 48 pages/24 sheets Binding: Saddle-stitched Paper Weight: 32# <i>Rite in the Rain</i> Weight: 0.16 lbs	38TD88	Level	✓	311FX
			38TD89	Field	✓	351FX
			38TD91	Universal	✓	371FX
			38TD92	Metric Grid	✓	381FX
			38TD93	Journal	✓	391FX
			48RE10	Universal	✓	771FX

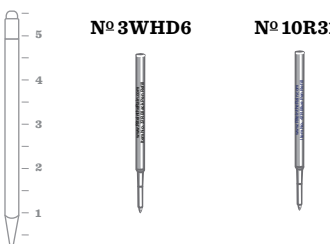
ALL-WEATHER PENS

		DESCRIPTION	ITEM N ^o	INK COLOR	MFG. N ^o
	N ^o 48RE43	DURABLE CLICKER PENS Size: Length 5¾", Barrel Diameter ⅜" Barrel: Rubberized Plastic Color: Flat black with ink color identification rings Description: Writes on wet paper and upside down, the pressurized ink cartridge performs in temperatures from -30F to 250F. Weight: 0.03 lbs	48RE43	Black	93K
	N ^o 48RE44		48RE44	Blue	93B
	N ^o 3WHD5	STANDARD CLICKER PENS Size: Length 5¾", Barrel Diameter ⅜" Barrel: Chrome/Plastic Colors: Chrome/Black, Chrome/Blue, or Chrome/Red Description: Writes on wet paper and upside down, the pressurized ink cartridge performs in temperatures from -30F to 250F. Weight: 0.05 lbs	3WHD5	Black	37
	N ^o 10R310		10R310	Blue	47
	N ^o 10R311		10R311	Red	57
	N ^o 10R312	METAL CLICKER PENS Size: Length 5¾", Barrel Diameter ⅜" Barrel: Metal Colors: Flat Black Description: Writes on wet paper and upside down, the pressurized ink cartridge performs in temperatures from -30F to 250F. Weight: 0.05 lbs	10R312	Black	97
			10R313	Blue	97B

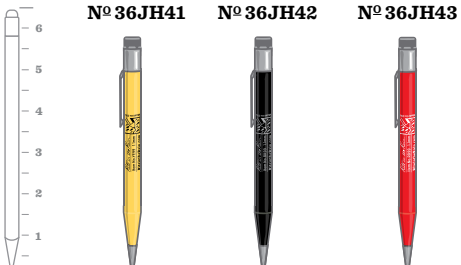
ALL-WEATHER PENS *continued*

	DESCRIPTION	ITEM N ^o	INK COLOR	MFG. N ^o
 <p>N° 3WGZ2 N° 3WGZ3</p> <p>Cap Cap</p>	<p>METAL BULLET PENS</p> <p>Size: Length 5¼" (open with cap attached to end), 3¾" closed, Barrel Diameter ⅜"</p> <p>Barrel: Metal, Flat Black, or Chrome</p> <p>Description: Writes on wet paper and upside down, the pressurized ink cartridge performs in temperatures from -30F to 250F.</p> <p>Weight: 0.05 lbs</p>	3WGZ2	Black	36
		3WGZ3	Black	96
 <p>N° 9HM45</p>	<p>METAL TREKKER PEN</p> <p>Size: Length 4", Diameter ⅜"</p> <p>Overall Size: Length with Ring 4½"</p> <p>Barrel: Metal, Flat Black</p> <p>Description: ¾" Key Ring. Writes on wet paper and upside down, the pressurized ink cartridge performs in temperatures from -30F to 250F.</p> <p>Weight: 0.05 lbs</p>	9HM45	Black	98

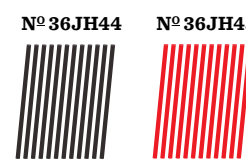

ALL-WEATHER PEN REFILLS

	DESCRIPTION	ITEM N ^o	INK COLOR	MFG. N ^o
 <p>N° 3WHD6 N° 10R314</p>	<p>Size: Length 3½", Diameter ⅜"</p> <p>Fits: All <i>Rite in the Rain</i> Pens</p> <p>Description: pressurized ink cartridge performs in temperatures from -30F to 250F. Includes plastic adapter for Parker® style pen retrofits.</p> <p>Weight: 0.02 lbs</p>	3WHD6	Black	37R
		10R314	Blue	47R

MECHANICAL PENCILS

	DESCRIPTION	ITEM N ^o	LEAD COLOR	MFG. N ^o
 <p>N° 36JH41 N° 36JH42 N° 36JH43</p>	<p>Size: Length 5¼", Diameter ⅜"</p> <p>Barrel: Strong Resin</p> <p>Lead: 1.1 mm</p> <p>Includes:</p> <ul style="list-style-type: none"> • 7 Leads, 1.1 mm • 3 Erasers <p>Weight: 0.05 lbs</p>	36JH41	Black / HB (No. 2)	YE99
		36JH42	Black / HB (No. 2)	BK99
		36JH43	Red / B (No. 1)	RD99

MECHANICAL PENCIL REFILLS

	DESCRIPTION	ITEM N ^o	LEAD COLOR	MFG. N ^o
 <p>N° 36JH44 N° 36JH45</p>	<p>LEAD REFILLS</p> <p>Fits: All <i>Rite in the Rain</i> Mechanical Pencils</p> <p>Size: 1.1mm, Length 1⅜"</p> <p>Qty: 12 Leads per pack</p> <p>Tube: Length 1¾", Diameter ½"</p> <p>Weight: 0.01 lbs</p>	36JH44	Black / HB (No. 2)	99BR
		36JH45	Red / B (No. 1)	99RR
 <p>N° 36JH46</p>	<p>ERASER REFILLS</p> <p>Fits: All <i>Rite in the Rain</i> Mechanical Pencils</p> <p>Qty: 3 Erasers per pack</p> <p>Tube: Length 2⅜", Diameter ½"</p> <p>Weight: 0.01 lbs</p>	36JH46		99ER

3" x 5" NOTEBOOK COVERS



DESCRIPTION	ITEM Nº	FABRIC COLOR	MFG. Nº
Size: 4¼" x 6" x ⅝" Materials: CORDURA® fabric with rugged zipper closure Fits: 3" x 5" and 3¼" x 5¼" Top-Bound Notebook Storage: 4 external writing instrument pockets Weight: 0.12 lbs	3WGY7	Tan	C935
	10R353	Black	C935B

4" x 6" NOTEBOOK COVERS



DESCRIPTION	ITEM Nº	FABRIC COLOR	MFG. Nº
Size: 5½" x 7¼" x ⅝" Materials: CORDURA® fabric with rugged zipper closure Fits: 4" x 6" Top-Bound Notebook Storage: 4 internal writing instrument pockets Weight: 0.13 lbs	3WGY9	Tan	C946
	10R354	Black	C946B

STANDARD BOOK COVERS



DESCRIPTION	ITEM Nº	FABRIC COLOR	MFG. Nº
Size: 5½" x 8¼" x ⅝" Materials: CORDURA® fabric with rugged zipper closure Fits: Side-Bound Books from 4¾" - 4¾" wide to 7" - 7½" tall Storage: 4 internal writing instrument pockets and 1 pen refill pocket Weight: 0.19 lbs	10R349	Tan	C980
	10R356	Black	C980B

1/2" RING BINDER COVERS



DESCRIPTION	ITEM Nº	FITS	COLOR	MFG. Nº
Size: 6¾" x 8⅞" x ⅝" Materials: CORDURA® fabric with rugged zipper closure Fits: 4⅞" x 7" Ring Binders, ½" capacity Storage: 4 internal writing instrument pockets and 1 pen refill pocket Weight: 0.21 lbs	10R350	4⅞" x 7" Ring Binders, ½" capacity	Tan	C9200
	10R355	4⅞" x 7" Ring Binders, ½" capacity	Black	C9200B

AVAILABLE THROUGH

GRAINGER®

For more information contact your Grainger representative or visit Grainger.com

FOR THE ONES WHO GET IT DONE