


Dismantling Tools

16
20

- > for stripping all common round cables
- > self-tightening holding lever
- > with adjusting screw for cutting depth adjustment
- > turnable blade for circular and longitudinal cutting
- > spare blade inside the handle
- > secure grip due to soft component material on handle and holding lever to avoid slipping
- > housing: plastic, impact-resistant

16 20 165 SB

With knife and hook blade, protective cap included

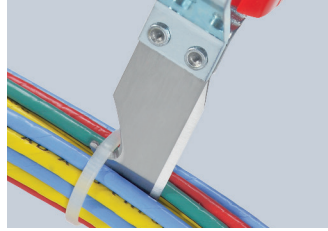

16 20 16 SB
⌘



16 20 165 SB
⌘

| Product Number | Packaging | ↔ Inch mm | | Stripping capacities Ø Inch Ø mm | ⚖ lbs |
|----------------|--|-----------------|---|--|----------|
| 16 20 16 SB | X | 5 1/8 130 | ⌘ | 3/16 - 5/8 4.0 - 16.0 | 0.17 |
| 16 20 165 SB | X | 6 1/2 165 | | 5/16 - 1 1/8 8.0 - 28.0 | 0.18 |
| 16 29 165 | Spare blade for 16 20 16 SB / 16 20 165 SB | | | | |

Dismantling Tool

16
30

- > for dismantling round cable sheaths made of PVC, rubber, silicone or PTFE from 6.0 - 29.0 mm dia.
- > self-tightening holding lever
- > with knurled nut for cutting depth adjustment
- > changing from circular to longitudinal cutting by turning the tool body
- > spiral cutting for removing intermediate pieces
- > replaceable blade
- > housing: plastic, impact-resistant



Setting the tool for circular cutting



Longitudinal cut



Spiral cutting



16 30 135 SB
⌘

| Product Number | Packaging | ↔ Inch mm | | Stripping capacities Ø Inch Ø mm | ⚖ lbs |
|----------------|------------------------------|-----------------|---|--|----------|
| 16 30 135 SB | X | 5 1/4 133 | ⌘ | 1/4 - 1 1/8 6.0 - 29.0 | 0.22 |
| 16 39 135 | Spare blade for 16 30 135 SB | | | | |