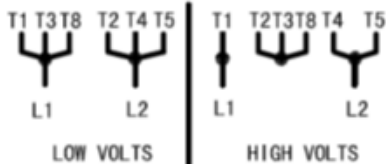


Dayton[®]**WASHDOWN MOTOR**

Mod.No. 11G245

HP: 1	HZ: 60	PH: 1	KVA CODE: K
RPM: 1745	FR: 56C		THERMALLY: NONE PROTECTED
VOLTS: 115/208-230	ENCL: TEFC		BALL BRG: 6205 / 6203
FLA: 11.2 / 5.8-5.6	INS CL: F		Permanently Lubricated, Relubrication not Required.
SFA: 12.6 / 6.5-6.3	SF: 1.15		
DUTY: Cont.	AMB: 40°C		

CONNECTIONS:**WARNING**

Failure to properly operate and ground this motor may cause serious injury to property and/or personnel. Read operating instructions.



Disconnect power before removing terminal box cover and/or performing maintenance. Ground in accordance with National Electric and local codes.

CW ROTATION SHOWN AT SHAFT END.
INTERCHANGE T5 AND T8 WIRES
TO REVERSE ROTATION.

Date Code: M11

Mfd for Dayton Electric Mfg. Co. Niles, IL 60714

Made in China