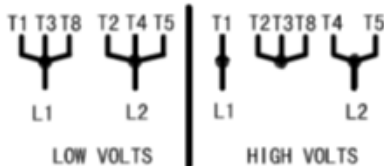


Dayton[®]**WASHDOWN MOTOR**

Mod.No. 11G252

HP: 1/2	HZ: 60	PH: 1	KVA CODE: L
RPM: 1745	FR: 56HC		THERMALLY : NONE
VOLTS: 115/208-230	ENCL: TEFC		PROTECTED
FLA: 5.0 / 2.6-2.5	INS CL: F		BALL BRG: 6205 / 6203
SFA: 5.6 / 2.9-2.8	SF: 1.15		Permanently Lubricated,
DUTY: Cont.	AMB: 40°C		Relubrication not Required.

CONNECTIONS:

CW ROTATION SHOWN AT SHAFT END.
INTERCHANGE T5 AND T8 WIRES
TO REVERSE ROTATION.

WARNING

Failure to properly operate and ground this motor may cause serious injury to property and/or personnel. Read operating instructions.



Disconnect power before removing terminal box cover and/or performing maintenance. Ground in accordance with National Electric and local codes.

Date Code: M11

Mfd for Dayton Electric Mfg. Co. Niles, IL 60714

Made in China