

Dayton®


WASHDOWN MOTOR

Mod.No. 11G255



HP: 1.5	HZ: 60	PH: 1	KVA CODE: J
RPM: 1745	FR: 56HC		THERMALLY : NONE
VOLTS: 115/208-230	ENCL: TEFC		PROTECTED
FLA: 14.8 / 7.6-7.4	INS CL: F		BALL BRG: 6205 / 6203
SFA: 16.9 / 8.7-8.45	SF: 1.15		Permanently Lubricated,
DUTY: Cont.	AMB: 40°C		Relubrication not Required.

CONNECTIONS:

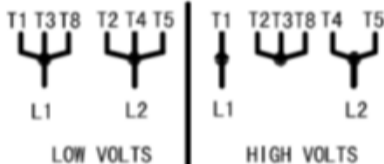

CW ROTATION SHOWN AT SHAFT END.
INTERCHANGE T5 AND T8 WIRES
TO REVERSE ROTATION.

WARNING



Failure to properly operate and ground this motor may cause serious injury to property and/or personnel.
Read operating instructions.



Disconnect power before removing terminal box cover and/or performing maintenance.
Ground in accordance with National Electric and local codes.

Date Code: M11

Mfd for Dayton Electric Mfg. Co. Niles, IL 60714

Made in China