

SUMNER*

FAB SAF JACK

Great for serious fabrication.

APPLICATIONS

- 3,5000 lbs (1,580 kg) load capacity
- Adjustable height from 32 in (81 cm) to 52 in (132 cm)
- Backed by forty years of jack stand manufacturing experience
- Roller head available
- CE certified

LARGE ADJUSTMENT SCREW

WORKS EASILY WITH GLOVED HANDS & TURNS EASILY WITH LOADS UP TO 3,500 LBS (1,5800 KG)

GALVANIZED INSIDE TUBE

RESISTS CORROSION

PATENTED FALL GUARD™

FEATURES ALLOWS 1IN (2.5 CM) SAFETY ZONE AROUND LOCK WASHER

VEE HEAD

7 IN (17 CM) WIDE 120 IN ANGLE IDEAL FOR PIPE UP TO 36 IN (900 MM) IN DIAMETER

RIB-SUPPORTED VEE HEAD

PREVENTS "PANCAKING"


SET SCREW

FOR DOUBLE MARGIN OF SAFETY

1IN (2.5 CM) SQUARE TUBE BASE CONSTRUCTION

ROUNDED FOOT PADS

NO SHARP EDGES

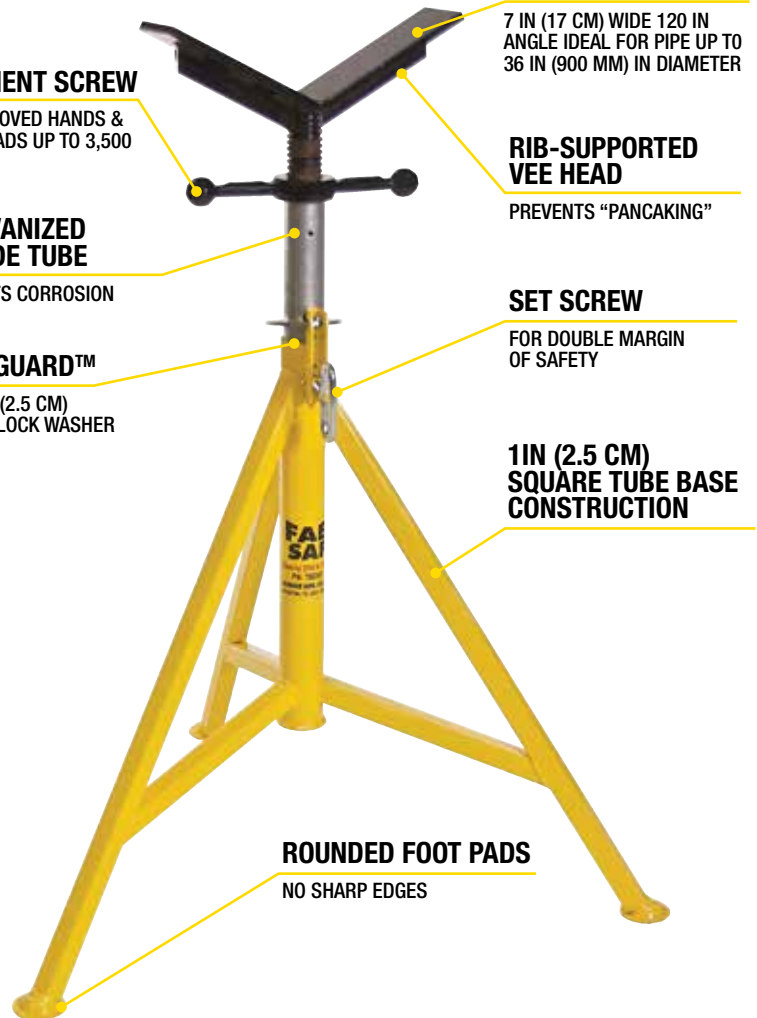

PART #	DESCRIPTION	WEIGHT
780395	FAB SAF Jack	26 lbs (11.8 kg)
780400	FAB SAFT Jack with Roller Head	26 lbs (11.8 kg)