



TECHSPRAY®

PRECISION · SAFETY · PERFORMANCE

*Advanced Chemistries to Improve
Your Products & Processes*



A Division of **TW**



TECHSPRAY®

DUSTER

- Ultra-pure HFC-134a
- Non-flammable
- Ideal for energized equipment



3XKC3 10 oz
3XKC4 15 oz

MAINTENANCE CLEANER

- Non-flammable
- Powerful cleaner
- Lower toxicity



9XYZ6 16 oz

ISOPROPYL ALCOHOL (IPA)

- 99.8% pure IPA
- Convenient packaging options

SEE TECHSPRAY IPA IN GRAINGER CATALOG ON PAGE 3638

 


3XJV4 1 pt 3XJW1 1 pt 3XJV5 100 wipes 6KCK5 1 gal 3XJV6 50 wipes

DESOLDERING BRAID (WICK)



- Ultra-clean copper
- Fast activation
- Available pre-fluxed rosin (Pro Wick) or no-clean
- Anti-static spools




Techspray Brand C

DESCRIPTION	5' LONG	10' LONG
Pro Wick Yellow #2 Braid	6KCH7	6KCH8
Pro Wick Green #3 Braid	6KCH9	6KCJ0
Pro Wick Blue #4 Braid	6KCJ1	6KCJ2
No-Clean Yellow #2 Braid	6KCJ3	6KCJ4
No-Clean Green #3 Braid	6KCJ5	6KCJ6
No-Clean Blue #4 Braid	6KCJ7	6KCJ8

SEE TECHSPRAY WICK IN GRAINGER CATALOG ON PAGE 3638

BOARD REPAIR PENS

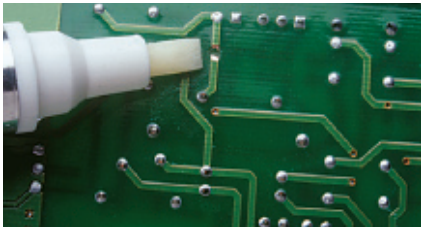

- Complete solution for trace repair
- Convenient, portable pens
- Meets IPC 7711 and ANSI J 001C board repair standards



3JDK7

PART #	DESCRIPTION
3JDK9	Trace Tech Conductive Pen
3JDK7	Trace Tech Flux Remover Pen
3JDL4	Trace Tech No-Clean Flux Pen
3JDL2	Trace Tech Overcoat Pen – Green
3JDL6	Conformal Coating Remover Pen

CLEANING TOOLS

3XKC5 – 1 brush

3XKC7 – 1 brush

3TAT3 – 1 brush

- Double-head
3TAT8 – 100 swabs
3TAT9 – 1000 swabs
- Single-head
3TAT6 – 100 swabs
3TAT7 – 1000 swabs

3TAT4 – 30 swabs

3TAU2 – 50 swabs
3TAU3 – 1000 swabs

3TAU1 – 50 swabs

3TAU4 – 50 swabs
3TAU5 – 1000 swabs

- Class 100 compatible
- Lint-free



3XKD7 9"x9" poly-cellulose, 100 wipes

3XKD6 9"x9" continuous fiber poly, 100 wipes


PLATO SOLDER TIP FEATURES...

- Tips to fit most common Weller, Hakko & Pace stations
- Long life – optimized for lead-free solders
- Fast heat recovery for faster soldering


SEE PLATO TIPS IN GRAINGER CATALOG ON PAGE 3641

WELLER

WELLER WES50, WES51, WD1, WD2

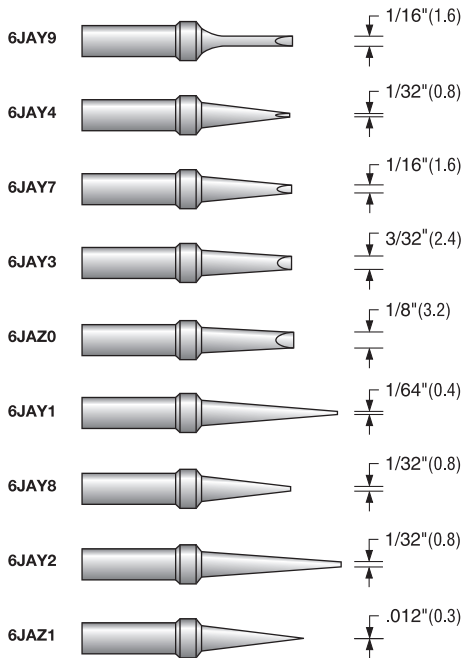


WELLER WSL, WSL2, WD1, WD2, WS80, WSD80, WSD81

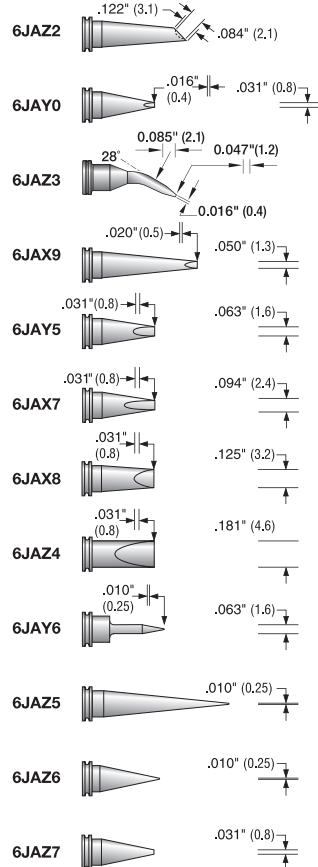


HAKKO

HAKKO FX-888, FX-8801, 926, 928, 936, 937, 951, 952, 958, 959, 701, 702B

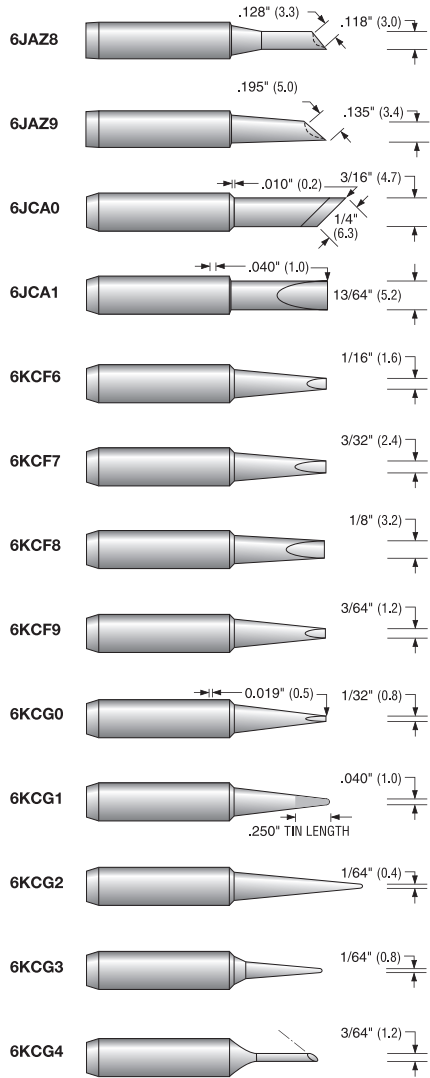

PACE

PACE 3/16" for PS-80, PS-90, SP2A, IR70

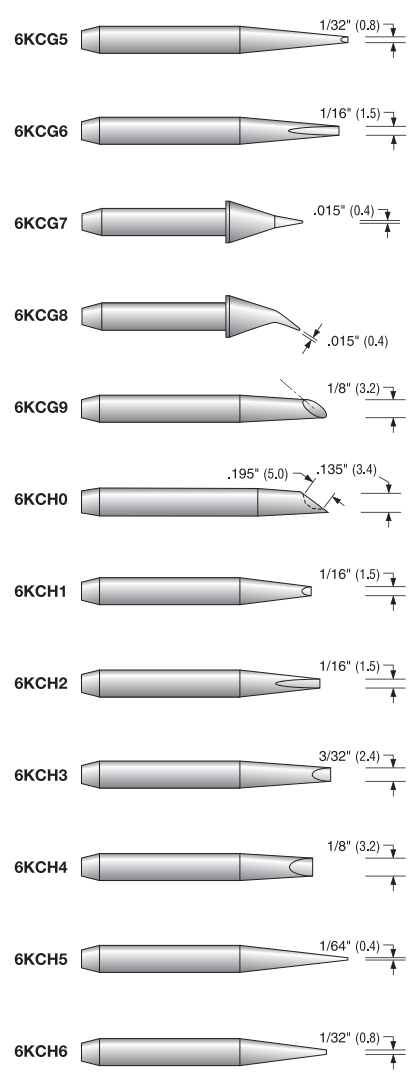

SOLDER POTS

	UNCOATED	PORCELAIN COATED
350W, 500-975°F	6KCG9	6KCK0
500W, 500-1100°F	6KCK1	6KCK2

SEE PLATO POTS IN GRAINGER CATALOG ON PAGE 3643



Electromechanical Controls

- 2 lb solder capacity
- Porcelain coated pot option – avoids corrosion
- Safety heat shield
- Removable dross tray for easy cleaning
- Standard 120V plug
- All metal ESD-safe design

**DUSTER**

GRAINGER NUMBER	TECHSPRAY NUMBER	DESCRIPTION	PKG SIZE	UNITS/CS
3XKC3	1671-10S	Non-Flammable Duster	10 oz	12
3XKC4	1671-15S	Non-Flammable Duster	15 oz	12

MAINTENANCE CLEANER

9XYZ6	1630-16S	G3 Maintenance Cleaner	16 oz	12
-------	----------	------------------------	-------	----

ISOPROPYL ALCOHOL (IPA)

3XJV5	1610-100DSP	Isopropyl Alcohol Wipes	100 ct	12
3XJV6	1610-50PK	Isopropyl Alcohol Wipes	50 ct	10
6KCK5	1610-G4	Isopropyl Alcohol	1 gal	4
3XJV4	1610-P	Isopropyl Alcohol	1 pt	12
3XJW1	1610-PT	Isopropyl Alcohol	1 pt	12

DESOLDERING BRAID (WICK)

6KCH8	1809-10F	Pro Wick Yellow #2 Braid	10'	25
6KCH7	1809-5F	Pro Wick Yellow #2 Braid	5'	25
6KCJ0	1810-10F	Pro Wick Green #3 Braid	10'	25
6KCH9	1810-5F	Pro Wick Green #3 Braid	5'	25
6KCJ2	1811-10F	Pro Wick Blue #4 Braid	10'	25
6KCJ1	1811-5F	Pro Wick Blue #4 Braid	5'	25
6KCJ4	1821-10F	No-Clean Yellow #2 Braid	10'	25
6KCJ3	1821-5F	No-Clean Yellow #2 Braid	5'	25
6KCJ6	1822-10F	No-Clean Green #3 Braid	10'	25
6KCJ5	1822-5F	No-Clean Green #3 Braid	5'	25
6KCJ8	1823-10F	No-Clean Blue #4 Braid	10'	25
6KCJ7	1823-5F	No-Clean Blue #4 Braid	5'	25

BOARD REPAIR PENS

3JDK9	2505-N	Trace Tech Conductive Pen	4.89 ml	12
3JDK7	2506-N	Trace Tech Flux Remover Pen	11.5 ml	12
3JDL4	2507-N	Trace Tech No-Clean Flux Pen	11.5 ml	12
3JDL2	2509-GN	Trace Tech Overcoat Pen – Green	5 ml	12
3JDL6	2510-N	Conformal Coating Remover Pen	10 ml	12

CLEANING TOOLS

3XKC5	2040-1	Brush 1 3/16 x 3/16" Horse Hair		6
3XKC7	2042-1	Brush 1 3/16 x 5/16" Horse Hair		6
3TAT3	2043-1	Brush 1 3/16 x 5/16" Stainless Steel		6
3TAT8	2300-100	Double-Tip Cotton Stick	100 ct	48
3TAT9	2300-1000	Double-Tip Cotton Stick	1000 ct	1
3TAT6	2301-100	Single-Tip Cotton Stick	100 ct	48
3TAT7	2301-1000	Single-Tip Cotton Stick	1000 ct	1
3TAU3	2302-1000	Absorb-Tip Foam Swab	1000 ct	1
3TAU2	2302-50	Absorb-Tip Foam Swab	50 ct	12
3TAU1	2306-50	Super-Tip Foam Swab	50 ct	12
3TAU5	2307-1000	Mini-Tip Foam Swab	1000 ct	1
3TAU4	2307-50	Mini-Tip Foam Swab	50 ct	12
3TAT4	2313-30	Double-Tip Pointed Cotton Stick	30 ct	24
3XKD7	2350-100	Techclean Wiper	100 ct	12
3XKD6	2355-100	Techclean Purwipe	100 ct	12

SOLDER POTS

6KCK9	SP-101	Solder Pot, Electromech Controls		1
6KCK0	SP-101P	Solder Pot, Electromech Controls, Porcelain Coated		1
6KCK1	SP-301	Solder Pot, Electronic Controls		1
6KCK2	SP-301P	Solder Pot, Electronic Controls, Porcelain Coated		1

SOLDERING TIPS

GRAINGER NUMBER	TECHSPRAY NUMBER	CROSS NUMBER	DESCRIPTION	UNITS/CS
-----------------	------------------	--------------	-------------	----------

WELLER WES50, WES51, WD1, WD2

6JAY9	EW-101	ETR	Weller Compatible Soldering Tip	10
6JAY4	EW-301	ETH	Weller Compatible Soldering Tip	10
6JAY7	EW-303	ETA	Weller Compatible Soldering Tip	10
6JAY3	EW-305	ETB	Weller Compatible Soldering Tip	10
6JAZ0	EW-307	ETC	Weller Compatible Soldering Tip	10
6JAY1	EW-402	ETS	Weller Compatible Soldering Tip	10
6JAY8	EW-403	ETP	Weller Compatible Soldering Tip	10
6JAY2	EW-404	ETO	Weller Compatible Soldering Tip	10
6JAZ1	EW-4796	—	Weller Compatible Soldering Tip	10

WELLER WSL, WSL2, WD1, WD2, WS80, WSD80, WSD81

6JAZ2	MS-0100	LTGW	Weller Compatible Soldering Tip	10
6JAY0	MS-3110	LTH	Weller Compatible Soldering Tip	10
6JAZ3	MS-3125	LT4X	Weller Compatible Soldering Tip	10
6JAX9	MS-3150	LTK	Weller Compatible Soldering Tip	10
6JAY5	MS-3200	LTA	Weller Compatible Soldering Tip	10
6JAX7	MS-3300	LTB	Weller Compatible Soldering Tip	10
6JAX8	MS-3400	LTC	Weller Compatible Soldering Tip	10
6JAZ4	MS-3600	LTD	Weller Compatible Soldering Tip	10
6JAY6	MS-4100	LT1S	Weller Compatible Soldering Tip	10
6JAZ5	MS-4110	LT1L	Weller Compatible Soldering Tip	10
6JAZ6	MS-4120	LT1	Weller Compatible Soldering Tip	10
6JAZ7	MS-4140	—	Weller Compatible Soldering Tip	10

HAKKO FX-888, FX-8801, 926, 928, 936, 937, 951, 952, 958, 959, 701, 702B

6JAZ8	HS-0530	—	Hakko Compatible Soldering Tip	10
6JAZ9	HS-0531	—	Hakko Compatible Soldering Tip	10
6JCA0	HS-0927	900M-T-K, T18-K	Hakko Compatible Soldering Tip	10
6JCA1	HS-1665	900M-T-S3, T18-S3	Hakko Compatible Soldering Tip	10
6KCF6	HS-2751	900M-T-1.6D, T18-D16	Hakko Compatible Soldering Tip	10
6KCF7	HS-2752	900M-T-2.4D, T18-D24	Hakko Compatible Soldering Tip	10
6KCF8	HS-2753	900M-T-3.2D, T18-D32	Hakko Compatible Soldering Tip	10
6KCF9	HS-2796	900M-T-1.2D, T18-D12	Hakko Compatible Soldering Tip	10
6KCG0	HS-2863	900M-T-0.8D, T18-D08	Hakko Compatible Soldering Tip	10
6KCG1	HS-4785	900M-T-B	Hakko Compatible Soldering Tip	10
6KCG2	HS-4786	900M-T-LB	Hakko Compatible Soldering Tip	10
6KCG3	HS-4787	900M-T-I	Hakko Compatible Soldering Tip	10
6KCG4	HS-5701	900M-T-1C, T18-C1	Hakko Compatible Soldering Tip	10

PACE 3/16" for PS-80, PS-90, SP2A, IR70

6KCG5	33-1144	1121-0359	Pace Compatible Soldering Tip	10
6KCG6	33-1147	1121-0499	Pace Compatible Soldering Tip	10
6KCG7	33-3981	1121-0516	Pace Compatible Soldering Tip	10
6KCG8	33-3982	1121-0526	Pace Compatible Soldering Tip	10
6KCG9	33-5894	1121-0406	Pace Compatible Soldering Tip	10
6KCH0	33-5895	1121-0490	Pace Compatible Soldering Tip	10
6KCH1	33-6055	1121-0335	Pace Compatible Soldering Tip	10
6KCH2	33-6056	1121-0414	Pace Compatible Soldering Tip	10
6KCH3	33-6057	1121-0360	Pace Compatible Soldering Tip	10
6KCH4	33-6058	1121-0337	Pace Compatible Soldering Tip	10
6KCH5	33-8141	1121-0357	Pace Compatible Soldering Tip	10
6KCH6	33-8142	1121-0336	Pace Compatible Soldering Tip	10

AVAILABLE THROUGH

GRAINGER®

FOR THE ONES WHO GET IT DONE