 


## 30 Amp, 125, 250 Volts and 277 Volts AC 2 Pole, 3 Wire, Grounding



### Connector Bodies

#### Watertight Safety-Shroud®

Description	Cord Dia.	IP66 SUITABILITY		UL Type 4x, 12
		Catalog Number	Catalog Number	
Black Valox® housing, white Valox® clamps.	.360"-.930" (9-24)	<b>HBL2613SW</b>	<b>HBL2623SW</b>	-
Reverse service, black Valox® housing, white Valox® clamps (use with HBL2615SWR), (Not shown).	.360"-.930" (9-24)	<b>HBL2613SR</b>	-	-

#### Insulgrip®

Description	Cord Dia.	IP20 SUITABILITY		
		Catalog Number	Catalog Number	Catalog Number
Black and white nylon.	.360"-.930" (9-24)	<b>HBL2613</b>	<b>HBL2623</b>	<b>HBL2633</b>
Heat stabilized, gray nylon, 220° F (104° C).	.360"-.930" (9-24)	<b>HBL2613F</b>	<b>HBL2623F</b>	-
Corrosion resistant, yellow nylon.	.360"-.930" (9-24)	<b>HBL26CM13</b>	<b>HBL26CM23</b>	-
All black nylon.	.360"-.930" (9-24)	<b>HBL2613BK</b>	<b>HBL2623BK</b>	-

Note: See page B-54 for accessories.

#### Valise®

Description	Cord Dia.	IP20 SUITABILITY		
		Catalog Number	Catalog Number	Catalog Number
Yellow nylon.	.590"-.930" (15.0-23.6)	<b>HBL2613VY</b>	<b>HBL2623VY</b>	-
Corrosion resistant, yellow nylon.	.590"-.930" (15.0-23.6)	<b>HBL26CM13V</b>	-	-
Black nylon.	.590"-.930" (15.0-23.6)	<b>HBL2613VBK</b>	<b>HBL2623VBK</b>	-
Cord clamps with removable inserts. All black nylon.	.360"-.930" (9-24)	-	<b>HBL2623EBK</b>	-

Note: See page B-55 for accessories.

### Receptacles

#### Watertight Safety-Shroud®

Description	IP66 SUITABILITY		UL Type 4x, 12
	Catalog Number	Catalog Number	
Gray Valox® housing and flange, back wired.	<b>HBL2610SW</b>	<b>HBL2620SW</b>	-

Note: See page B-56 for accessories.

#### Safety-Shroud® Twist-Lock®

Description	IP20 SUITABILITY		
	Catalog Number	Catalog Number	Catalog Number
Gray Valox® angle housing, one gang, back wired.	<b>HBL2610AR</b>	<b>HBL2620AR</b>	-
Gray Valox® surface mounting, one gang, back wired.	<b>HBL2610SR</b>	<b>HBL2620SR</b>	-
Gray Valox® semi-flush, two gang, back wired.	<b>HBL2610SR2</b>	<b>HBL2620SR2</b>	-

#### Single Flush Receptacles

Description	IP20 SUITABILITY		
	Catalog Number	Catalog Number	Catalog Number
Black nylon face, back and side wired.	<b>HBL2610</b>	<b>HBL2620</b>	<b>HBL2630</b>
Black nylon face, spring terminals.	<b>HBL2610ST</b>	<b>HBL2620ST</b>	-
Blue nylon face, back and side wired.	<b>HBL2610M6</b>	<b>HBL2620M6</b>	-
Isolated ground, orange nylon face, back and side wired.	<b>IG2610</b>	<b>IG2620</b>	-
Corrosion resistant, yellow nylon face, back and side wired.	<b>HBL26CM10</b>	<b>HBL26CM20</b>	-
Ring terminal connection.	<b>HBL2610RT</b>	<b>HBL2620RT</b>	-

Note: See page B-54 for accessories.

#### Insulgrip® Flanged Receptacles

Description	Catalog Number		
	Nylon casing, back wired.	<b>HBL2616</b>	<b>HBL2626</b>
Heat stabilized, gray nylon, 220° F (104° C).	<b>HBL2616F</b>	<b>HBL2626F</b>	-

Note: See page B-54 for accessories.


Valox® is a trademark of SABIC Innovative Plastics, acquired from General Electric Company.



**HBL2613SW**




**HBL2623**

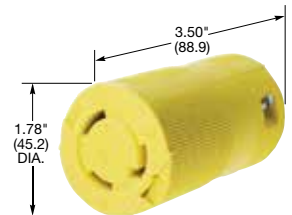

**HBL2613VY**



**HBL2610SW**

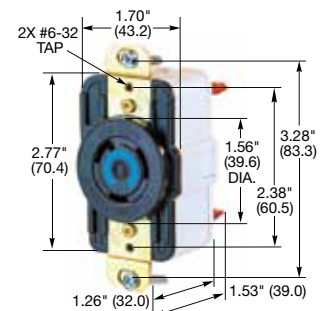

**HBL2610ST**



**HBL2620SR**

Dimensions in Inches (mm)