

## Heavy-Duty Portable Outlet Boxes and Cover Plates

| Description   | Catalog Number   |
|---|------------------|
| Box with cord strain relief, with one blank cover plate.                    | <b>HBLPOB1</b>   |
| Box with cord strain relief, with one blank cover plate, black.             | <b>HBLPOB1BK</b> |
| Box with cord strain relief, with two duplex (indoor) cover plates.         | <b>HBLPOB1D</b>  |
| Box with cord strain relief, with two duplex (indoor), yellow cover plates. | <b>HBLPOB1DY</b> |
| Blank, non-metallic FS cover plate with foam gasket, gray.                  | <b>HBLP14FS</b>  |
| Duplex, non-metallic FS cover plate, gray.                                  | <b>HBLP8FS</b>   |
| Duplex, non-metallic FS cover plate, yellow.                                | <b>HBLP8FSY</b>  |
| Single receptacle (1.39"), non-metallic FS cover plate, gray.               | <b>HBLP7FS</b>   |
| Single receptacle (1.56"), non-metallic FS cover plate, gray.               | <b>HBLP720FS</b> |
| Rectangular opening, non-metallic FS cover plate, gray.                     | <b>HBLP26FS</b>  |



**HBLPOB1**

## Other Cover Plates and Devices

which may be used with Heavy-Duty Portable Outlet Boxes

| Description  | Catalog Number   |
|--|--|
| Duplex cover plate, weatherproof.                    | <b>HBL5221, HBL52CM21</b>                                    |
| Single receptacle (1.39") cover plate, weatherproof. | <b>HBL7423WO, HBL74CM23WO</b>                                |
| Single receptacle (1.56") cover plate, weatherproof. | <b>HBL7425WOA, HBL74CM25WOA</b>                              |
| Safety-Shroud Twist-Lock® surface receptacles.       | <b>HBL2310SR, HBL2320SR, HBL2330SR, HBL2610SR, HBL2620SR</b> |



**Cover Plates**

Note: Standard product gray, CM yellow.

## Deluxe Cord Grips Straight Male Thread Nylon Fittings, Stainless Steel Mesh, Liquidtight, for Insulated Cables

| Grip Diameter Range<br>Inches (mm) | Thread Size<br>NPT (inches) | Form<br>Size | Catalog Number   |
|------------------------------------|-----------------------------|--------------|------------------|
| .375"-.500" (9.5-12.7)             | 3/4"                        | F3           | <b>074011335</b> |
| .500"-.625" (12.7-15.9)            | 3/4"                        | F3           | <b>074011336</b> |
| .625"-.750" (15.9-19.0)            | 3/4"                        | F3           | <b>074011337</b> |

## Gray Nylon Cord Connector Straight Male Thread

| Grip Diameter Range<br>Inches (mm) | Thread Size<br>NPT (inches) | Form<br>Size | Catalog Number   |
|------------------------------------|-----------------------------|--------------|------------------|
| .375"-.500" (9.5-12.7)             | 3/4"                        | F3           | <b>SHC1035CR</b> |
| .500"-.625" (12.7-15.9)            | 3/4"                        | F3           | <b>SHC1036CR</b> |
| .625"-.750" (15.9-19.0)            | 3/4"                        | F3           | <b>SHC1037CR</b> |



**Deluxe Cord Grips (purchased separately)**


## Specifications for Heavy-Duty Portable Outlet Boxes and Cover Plates

|                                     |  |
|-------------------------------------|--|
| UL Listed                           | UL514C, UL467 and UL50 Enclosures Types 1, 3R.   |
| CSA Certified                       | C22.2 No. 18 and C22.2 No. 94 Enclosures Types 1, 3R and C22.2 No. 0.4 (Impedance).  |
| Box Specifications:                 |  |
| Moisture Resistance                 | Wet and damp locations, enclosure Type 3R when used with weatherproof cover plates; Dry, indoors locations, enclosure Type 1 with all other cover plates |
| Flammability                        | UL94V-0, 94-5VA classification   |
| Operating Temperature               | 80°C maximum; -35°C minimum  |
| UV Resistance                       | All materials are UV stabilized  |
| Impact and Crush Resistance         | In accordance with UL514C, UL50, C22.2 No. 18 and C22.2 No. 94   |
| Material                            | Valox®   |
| Cord Connector Materials            | Nylon nut; nylon Gotcha® ring; neoprene grommet  |
| Cord Diameter Range                 | .38" to .75" diameter  |
| Bonding Strap Material              | Brass  |
| Threaded Inserts                    | Brass  |
| Grounding Screw Material            | Brass  |
| Indoor Cover Plate Screws Material  | Zinc plated steel  |
| Outdoor Cover Plate Screws Material | Stainless steel  |
| Cover Plate Gasket Material         | UL recognized closed-cell foam (aging and oil resistant)   |



**Gray Nylon Cord Connector**

## Dimensions

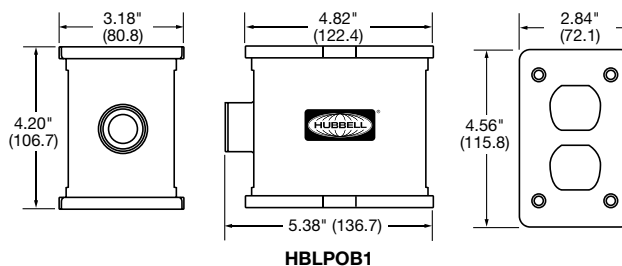

Valox® is a trademark of SABIC Innovative Plastics, acquired from General Electric Company.

Dimensions in Inches (mm)