

**30 Amp, 3ØY 120/208, 277/480 and 347/600 Volts AC
4 Pole, 5 Wire, Grounding**



HBL2811SW




HBL2811S



HBL2811



HBL2815SW

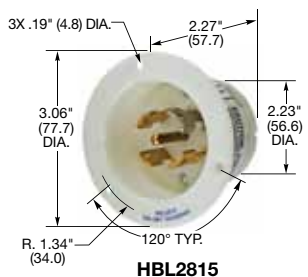

HBL2815

Dimensions in Inches (mm)

Plugs

Watertight Safety-Shroud®

Description	Cord Dia.	Catalog Number	IP66 SUITABILITY	UL Type 4x, 12
Black Valox® housing, white Valox® clamps.	.350"-1.150" (9-29)	HBL2811SW HBL2801		HBL2821SW HBL2831SW

Safety-Shroud®

Description	Cord Dia.	Catalog Number	IP20 SUITABILITY
Black and white nylon body, white Valox® shroud. Can be used with the Insulgrip Connector Bodies.	.350"-1.150" (9-29)	HBL2811S	- - -

Note: See page B-54 for accessories.

Insulgrip®

Description	Cord Dia.	Catalog Number	IP20 SUITABILITY
Black and white nylon.	.350"-1.150" (9-29)	HBL2811	- HBL2821 HBL2831
Corrosion resistant, yellow nylon.	.350"-1.150" (9-29)	HBL28CM11	- - -
Black and white for flat cable.	.350"-1.150" (9-29)	HBL2811FC	- - -
All black nylon.	.350"-1.150" (9-29)	HBL2811BK	- - -

Note: See page B-54 for accessories.

Flanged Inlets

Watertight Safety-Shroud®

Description	Catalog Number	IP66 SUITABILITY	UL Type 4x, 12
Gray Valox® housing and flange.	HBL2815SW HBL2805		- -

Note: See page B-56 for accessories.

Insulgrip®

Description	Catalog Number	IP20 SUITABILITY
Nylon casing, back wired.	HBL2815	- HBL2825 HBL2835

Note: See page B-54 for accessories.

See pages B-71 and B-72 for technical information on Twist-Lock and Watertight Safety-Shroud devices.

Twist-Lock® 3-Phase Circuit Tester

Description	Rating	Catalog Number	IP66 SUITABILITY	UL Type 4x, 12
3-Phase Circuit Tester	3Ø 120/208V AC Min. Voltage: 90V AC	HBL3PT2811		- - -

Note: Testers in other NEMA configurations can be developed upon request. See page B-55 for additional circuit testers.



HBL3PT2811

HBLMITL - For use with Watertight Safety-Shroud receptacles, see page B-43.



Valox® is a trademark of SABIC Innovative Plastics, acquired from General Electric Company.