



PRODUCTS FLAGGER PRODUCTS FLAGGER PRODUCTS FLAGGER PRODUCTS FLAGGER PR
R PRODUCTS FLAGGER PRODUCTS FLAGGER PRODUCTS FLAGGER PRODUCTS FLAGGE
PRODUCTS FLAGGER PRODUCTS FLAGGER PRODUCTS FLAGGER PRODUCTS FLAGGER PR
ER PRODUCTS FLAGGER PRODUCTS FLAGGER PRODUCTS FLAGGER PRODUCTS FLAGGI
PRODUCTS FLAGGER PRODUCTS FLAGGER PRODUCTS FLAGGER PRODUCTS FLAGGER PR
PRODUCTS FLAGGER PRODUCTS FLAGGER PRODUCTS FLAGGER PRODUCTS FLAGGER PR
R PRODUCTS FLAGGER PRODUCTS FLAGGER PRODUCTS FLAGGER PRODUCTS FLAGGER
PRODUCTS FLAGGER PRODUCTS FLAGGER PRODUCTS FLAGGER PRODUCTS FLAGGER PR
ER PRODUCTS FLAGGER PRODUCTS FLAGGER PRODUCTS FLAGGER PRODUCTS FLAGGI
PRODUCTS FLAGGER PRODUCTS FLAGGER PRODUCTS FLAGGER PRODUCTS FLAGGER PR

FLAGGER PRODUCTS




STOP



STOP SLOW SIGNS

STOP/SLOW PADDLES

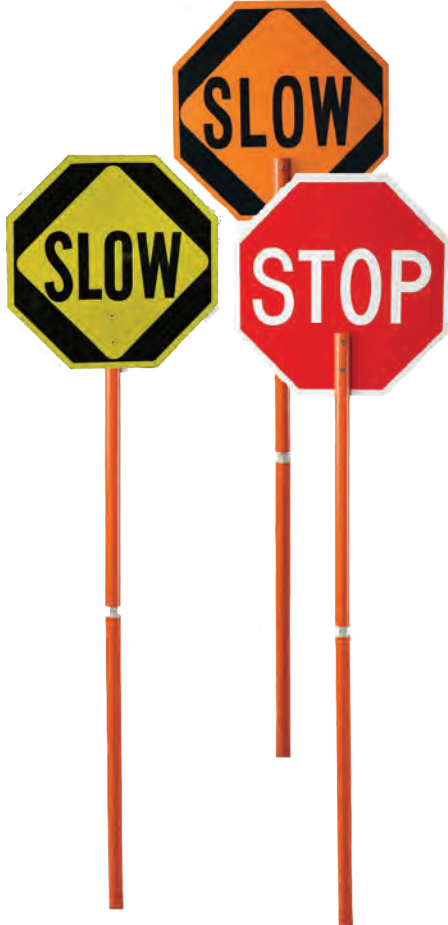

- Extremely durable recycled rubber will not warp, crack, or rot
- Resistant to oil, UV and moisture
- Stands up in wide temperature extremes
- Painted yellow reflective stripes

ITEM # DESCRIPTION

03-822	24" EGR Sheeting
03-822P	24" EGR Sheeting w 81" Plastic Handle
03-823	24" HI Sheeting
03-823P	24" HI Sheeting w 81" Plastic Handle
03-826	24" Diamond Grade
03-826P	24" Diamond Grade w 81" Plastic Handle
03-827	24" Silk Screened
03-827P	24" Silk Screened w 81" Plastic Handle
03-835	18" EGR Sheeting
03-836	18" HI Sheeting
03-837	18" Diamond Grade Sheeting
03-838	18" Silk Screened
03-851	18" Silk Screened w 9" Polygrip Handle
03-852	18" EGR Sheeting w 9" Polygrip Handle
03-853	18" HI Sheeting w 9" Polygrip Handle
03-854	18" Silk Screened w 9" Polygrip Handle
03-855	18" EGR w 9" Polygrip Handle
03-856	18" HI Sheeting w 9" Polygrip Handle
03-858ON	18" Paddle Stop/Slow Plastic DG Sheeting - Ontario

HANDLES AND COMPONENTS

03-850	9" Polygrip Handle Only
03-842-HD	Heavy Duty Plastic Handle - 81"
03-650	18" Stop/ Slow Paddle Blank
03-601	24" Stop/Slow Paddle Blank
03-601B	24" Stop/Slow Paddle Blank - Black
13-01-01	Bolt Kit for Paddle

QUICK DEPLOY STOP SIGN

- Quick set up and easy to use
- Effective traffic control system designed for use in industrial plants, 4-way intersections, parking lots, schools, airports, hospitals, and places where stop light is inoperable due to natural disasters, etc
- Highly visible
- Kit includes 1 white delineator post, 1 - 15 lb recycled rubber base, and 2 - 18" ABS STOP signs

ITEM #	DESCRIPTION
03-747QD	Non-reflective
03-747QDHI15	18" High Intensity Reflective
03-747QDDG15	18" Fluorescent Orange Prismatic
Bases Also Sold Separately	
03-730	Rubber Base 10 lb
03-731	Rubber Base 15 lb





STOP /SLOW SIGNS

LED STOP/SLOW PADDLES



- Meets/exceeds all DOT FMVSS125 Requirements

ITEM #	DESCRIPTION
03-816	12" Stop/Stop w 6" paddle handle
03-817	12" Stop/Stop w 6" paddle handle (Canada)
03-818	18" Stop/Stop w 6" paddle handle
03-819	18" Stop/Slow w 6" paddle handle

NON REFLECTIVE HAND HELD ABS PADDLE WITH HANDLE



- Meets MUTCD Requirements
- Available non reflective silk screened or reflective Engineer Grade, HI-Intensity, or Diamond Grade sheeting
- Ideal for school crossing guards, flaggers, and plant security guards
- Heavy duty ABS

ITEM #	DESCRIPTION
03-851	18" Stop/Slow Silk Screened with Polygrip Handle
03-835	18" Stop/Slow EGR Sheeting with Polygrip Handle
03-836	8" Stop/Slow HI Sheeting with Polygrip Handle
03-837SW	18" Stop/Slow Diamond Grade Sheeting with Polygrip Handle
03-838SW	18" Stop/Slow Silk-Screened with Polygrip Handle


ALUMINUM PADDLES WITH HANDLE



- Meets MUTCD Requirements
- Available non reflective silk screened or reflective Engineer Grade, HI-Intensity, or Diamond Grade sheeting
- Ideal for school crossing guards, flaggers, and plant security guards

ITEM #	DESCRIPTION
03-850	9" Polygrip Handle only for Stop/Slow Paddle
03-830	18" Stop/Slow with 9" Polygrip Handle
03-831	18" Stop/Stop with 9" Polygrip Handle
03-851-1	15" Stop/Stop, Silk Screened, with 9" Polygrip Handle
03-863	18" Stop/Slow with Aluminum Handle
03-864	18" Stop/Slow with Wood Handle

ELECTRONIC SAFETY BATONS

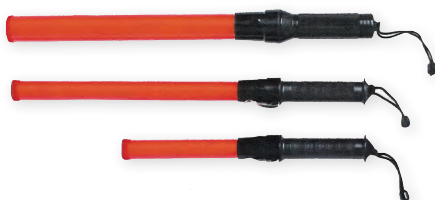

- Pulsating high intensity LED lights
- Water and impact resistant construction
- Battery Operated

ITEM #	DESCRIPTION
03-300	12" C-Cell Steady On / Slow Flash / Fast Flash
03-301	9" C-Cell Steady On / Fast Flash
03-303	12" D-Cell Steady On / Fast Flash16


FLAGGER PRODUCTS





FLAGS - BANNERS - WINDSOCKS


VINYL WARNING FLAGS



- Reinforced heavy duty vinyl
- Fluorescent red-orange
- Standard pack of 50
- * 100 per pack

ITEM #	DESCRIPTION
03-229-3415*	16" Orange Throw Away- no dowel
03-229-3404	18" Orange w 30" Wood Dowel
03-229-3405	18" Orange w 36" Wood Dowel
03-229-3417	18" Orange w 24" Wood Dowel
03-229-342	18" Red w 24" Wood Dowel
03-229-3472*	18" Orange Throw Away no dowel
03-229-3408	24" Orange w 30" Wood Dowel
03-229-3418	24" Orange w 36" Wood Dowel
03-229-3440	24" Red w 36" Wood Dowel

MESH WARNING FLAGS



- Reinforced heavy duty mesh
- Fluorescent red-orange
- Standard pack of 50


ITEM #	DESCRIPTION
03-229-3406	18" Orange w 24" Wood Dowel
03-229-3407	18" Orange w 30" Wood Dowel
03-229-3412	18" Orange - no dowel
03-229-3410	24" Orange w 36" Wood Dowel
03-229-3409	24" Orange w 30" Wood Dowel
03-229-3410	24" Orange 36" Wood Dowel

PENNANTS



ITEM #	DESCRIPTION
03-407	60' Red DANGER
03-400-60	60' Red
03-401-60	60' Red/White
03-402-60	60' Orange
03-404-60	60' Orange/White
03-405-60	60' Yellow
03-406	60' Red/Yellow alternating legends - Danger Keep Out/Safety First/Danger Ahead/ Be Careful/Safety Always
03-403-60	60' Multi
03-400	100' Red
03-401	100' Red/White
03-402	100' Orange
03-403	100' Multi
03-404	100' Orange/White
03-405	100' Yellow
03-400-105	105' Red- OSHA
03-405-105	105' Yellow - OSHA
03-407-105	105' Red/Yellow - OSHA

BANNER



- 18" x 96"
- 5' Rope Ties in Each Corner
- Wide Load / Oversize Load - Front / Back
- Bright yellow reinforced vinyl
- Letter size = 12"

ITEM #	DESCRIPTION
03-11-000	Highway Banner


AIRPORT FLAG



- Heavy nylon
- Red / White Checkered

ITEM #	DESCRIPTION
03-229-3423	36" x 36" Nylon

WINDSOCK



- International Orange
- UV Inhibitors
- Double stitched at all seams
- Weather proof and durable for variety of applications
- Corrosion resistant aluminum frame

ITEM #	DESCRIPTION
03-WS-3	3' Windsock Only
03-WS-FO-3	3' Frame Only
03-WS-3KT	3' w 10" Opening
03-WS-4	4' w 18" Opening
03-WS-4KT	4' w 18" Opening
03-WS-8	8' w 18" Opening
03-WS-8KT	8' w 18" Opening
03-WS-55KT	47" w 13" Opening

SEE PRICE LIST FOR ADDITIONAL OPTIONS



OVERSIZE LOAD



WWW.CORTINACO.COM

UNITED STATES 800.225.5206
WORKZONE@CORTINACO.COM

CANADA 866.757.1900
WORKZONECANADA@CORTINACO.COM

INTERNATIONAL 847.455.2800
WORKZONE@CORTINACO.COM / WORKZONECANADA@CORTINACO.COM

© 2017 CORTINA SAFETY PRODUCTS GROUP