



PRODUCTS WORKSITE PRODUCTS WORKSITE PRODUCTS WORKSITE PRODUCTS WORK
SITE PRODUCTS WORKSITE PRODUCTS WORKSITE PRODUCTS WORKSITE PRODUCTS WC
WORKSITE PRODUCTS WORKSITE PRODUCTS WORKSITE PRODUCTS WORKSITE PRODU
CTS WORKSITE PRODUCTS WORKSITE PRODUCTS WORKSITE PRODUCTS WORKSITE PRO
WORKSITE PRODUCTS WOR...
CTS WORKSITE PRODUCTS WOR...
WORKSITE PRODUCTS WORKSITE PRODUCTS WORKSITE PRODUCTS WORKSITE PRODU
CTS WORKSITE PRODUCTS WORKSITE PRODUCTS WORKSITE PRODUCTS WORKSITE PR
PRODUCTS WORKSITE PRODUCTS WORKSITE PRODUCTS WORKSITE PRODUCTS WORK
ITE PRODUCTS WORKSITE PRODUCTS WORKSITE PRODUCTS WORKSITE PRODUCTS WO

WORKSITE PRODUCTS



WORKSITE PRODUCTS

A-20 BARGARD™ COVERS



- Fits rebar 1" to 2-1/4" diameter
- Fits inside 1-3/4" I.D.
- 100 per pack

ITEM #	DESCRIPTION
97-1813	A-20 Lime 2.75" x 3.5"
97-1814	A-20 White 2.75" x 3.5"

A-5 BARGARD™ COVERS



- Fits rebar 3/8" to 3/4" diameter
- Fits inside 1" I.D.
- 100 per pack

ITEM #	DESCRIPTION
97-1811	A-5 Lime 2.25" x 2.5"

BARGARD™ PROTECTOR COVERS



- Fits rebar #3-9, 3/8" to 7/8" diameter
- Metal reinforced
- Safety Orange for visibility
- 100 per pack

ITEM #	DESCRIPTION
97-1810	3.5"x3.5" Cal-OSHA Orange Rebar Cap

A-10 BARGARD™ COVERS



- Fits rebar 3/8" to 1-1/4" diameter
- Fits inside 1-3/4" I.D.
- 100 per pack

ITEM #	DESCRIPTION
97-1812-1	2.5" x 2.55"

PENNANTS



ITEM #	DESCRIPTION
03-407	60' Red DANGER
03-400-60	60' Red
03-401-60	60' Red/White
03-402-60	60' Orange
03-404-60	60' Orange/White
03-405-60	60' Yellow
03-406	60' Red/Yellow alternating legends - Danger Keep Out/Safety First/Danger Ahead/ Be Careful/Safety Always
03-403-60	60' Multi
03-400	100' Red
03-401	100' Red/White
03-402	100' Orange
03-403	100' Multi
03-404	100' Orange/White
03-405	100' Yellow
03-400-105	105' Red- OSHA
03-405-105	105' Yellow - OSHA
03-407-105	105' Red/Yellow - OSHA

ROOF PERIMETER LINE WARNING KIT




- High Visibility Orange
- Molded Hi-Density Polyethylene with UV Color Stabilization
- 49.8" Overall Height, 42" Conical Height, and 7.56" Conical Width Base
- 12" x 18" Pennant Flags
05' ft - OSHA Complaint

ITEM #	DESCRIPTION
03-750	Plain Post
03-752-30	30 lb Base
03-400-105	Pennants Red Pennants
03-405-105	Pennants Red/Yellow alternating



FENCING


GENERAL PURPOSE FENCING

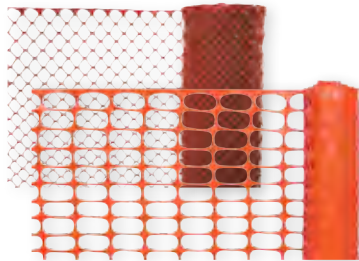

- Orange Polyethylene
- Highly visible
- UV Stabilized
- Rugged and reusable

ITEM #	DESCRIPTION
03-900	Orange 4' x 50'
03-901	Orange 4' x 100'
03-902	Orange Lightweight barrier fence- 4' x 100'

KRYPTONITE FENCING

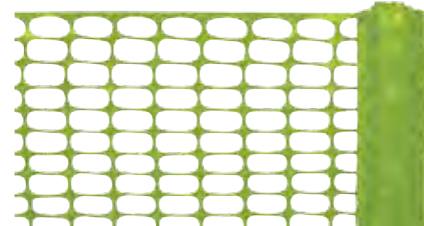

- Lime Polyethylene
- Highly visible
- UV Stabilized
- Rugged and reusable

ITEM #	DESCRIPTION
03-902-1	Lime Lightweight barrier fence - 4' x 100'


MODULAR BARRICADE SYSTEM



- Polyethylene
- Highly visible
- UV Stabilized
- Rugged and reusable

ITEM #	DESCRIPTION
03-905G	40" x 40" Orange Barrier System
03-906G	40" x 40" Yellow Barrier System
03-907G	48" x 48" Green Barrier System
03-908G	48" x 48" Orange Barrier System

MEDIUM AND HEAVY GRADE FENCING

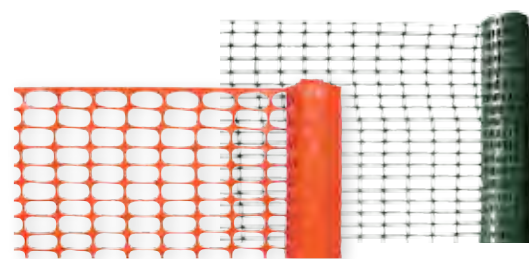

- Smooth top and bottom
- Heavier and more visible than light duty diamond fencing
- Medium Tensile strength - MD: 160 lbs / ft TD: 100 lbs / ft
- Heavy Duty Tensile strength - MD: 180 lbs / ft TD: 176 lbs / ft
- Rugged and reusable

ITEM #	DESCRIPTION
03-906-MGO	14 lb Diamond 4' x 50' Orange -30 Rolls/Pallet
03-907-5MGO	23 lb Diamond 5' x 50' Orange - 30 Rolls/Pallet



WWW.CORTINACO.COM

UNITED STATES 800.225.5206
WORKZONE@CORTINACO.COM

CANADA 866.757.1900
WORKZONECANADA@CORTINACO.COM

INTERNATIONAL 847.455.2800
WORKZONE@CORTINACO.COM / WORKZONECANADA@CORTINACO.COM

© 2017 CORTINA SAFETY PRODUCTS GROUP