


The RIGHT Choice For Your Jobsite Radio Communications...

JOBCOM®

Introducing
the HIGH POWER
J Series

Business Band
Two-way Radio

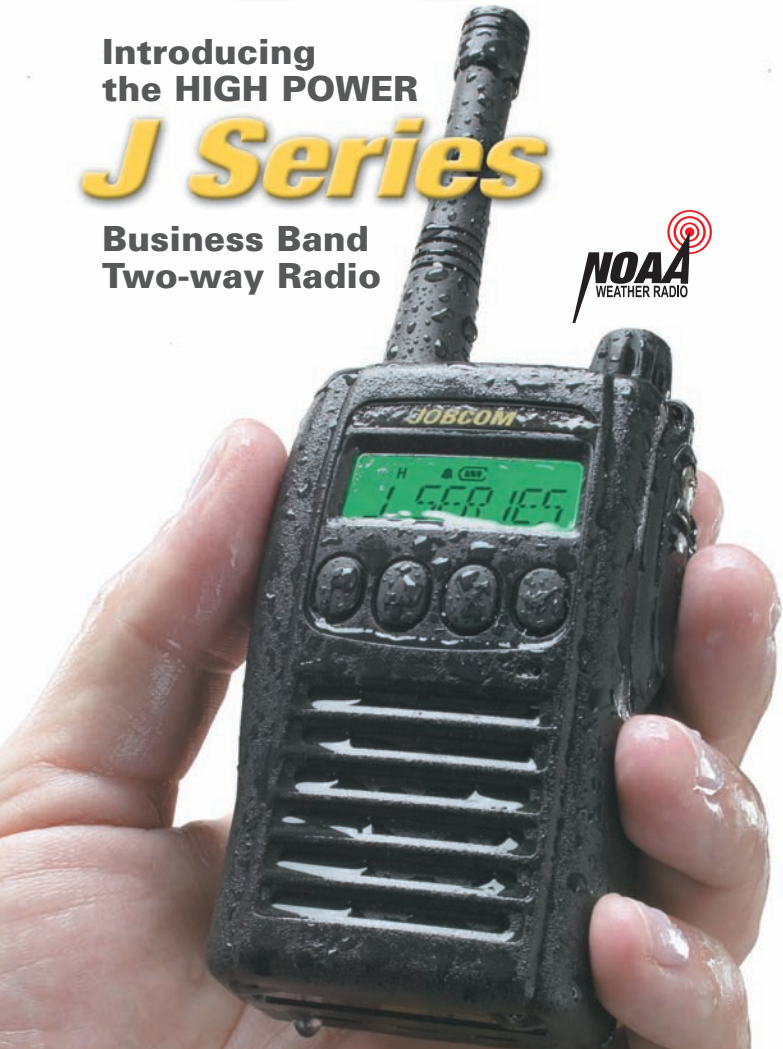

THE LEADER IN JOBSITE RADIOS!

Introducing the high powered* Jobcom J Series radio. With its ultra small size, lightweight, and high power transmitter, the J Series radio is the ideal solution for your on-site and in-plant communications. At the push-of-a-button, you can be in two places at once to communicate with multiple work groups, coordinate activities, or expedite customer orders.

The rugged and reliable Jobcom J Series portable radio will save you time and money by allowing your crew to work smarter and more efficiently **with no air-time charges or monthly fees.** Jobcom radios transmit directly radio-to-radio—no extra equipment required. They're compatible with other Jobcom portable radios, our desk-top base stations and OutPost Callboxes, and with virtually any other brand of two-way radio operating on the same frequency, so you can add other radios to the system as your needs grow.

Ultra Small, Lightweight -Measures only 3 7/8" H x 2 7/8" W x 1 1/4" D and weighs 9.6 oz.

High Power Transmitter * -VHF:5or2Watt UHF: 4 or 2 Watt.

Military Durability 810 F, IP 55 -Guards against rain, dust, shock, vibration.

Up to 10 Channel Capacity

Programmable Frequency and Privacy Codes -26 VHF or 77 UHF codes and 158 privacy codes.

3 Programmable Function Buttons -Allows fast access to certain features.

Key Pad Lock Button -Prevents accidental activation of front panel buttons.

Large Speaker -Loud, easy-to-hear audio.

13 Hour Battery Life -Based on a 90-5-5 duty cycle.

Low Battery Alert • Battery Meter Indicator

Channel Scan -Allows easy monitoring of multiple work groups.

NOAA Weather Scan (VHF model only) -Monitor weather broadcasts to increase safety and stay informed.

Voice Inversion Scrambler Built-in -Adds a measure of security and privacy against casual eavesdropping.

Internal Hands-Free, VOX-Ready -For tasks requiring hands-free communications...uses standard audio accessories.

Call Tone Feature -Causes alert tone to sound in other radio's speaker...perfect for signaling others in noisy environments.

Rugged Screw-on Accessory Connector -Customize with earbuds, headsets, speaker microphone.

Emergency Call Feature -Added safety and security.

Each J Series radio includes:

Flexible Antenna, Lithium-ion Battery, Spring Action Belt Clip and Dual Slot Charger (2.5 HR) with 110-240 VAC, 47-64 Hz cube power supply.

Like all other Jobcom radios, the J Series radios are designed for easy set-up and operation. J Series radios can be field-programmed to meet your specific needs. They can be programmed to display as many as 10 channels, or just 1 channel if that's all you require. For maximum compatibility you can choose from 26 operating frequencies in the VHF model and 77 in the UHF model. They also include 158 user-programmable Quiet Call privacy codes. Other useful features include channel scan, NOAA weather scan, voice scrambler, and hands-free VOX capability.

For more information about the new Jobcom J Series Radios

Call 800.872.1872

Go Beyond Normal Limits...™

RITRON®
WIRELESS SOLUTIONS

* By FCC mandate, certain frequencies in the Jobcom J Series radios are preset for a maximum of 2 Watt.

Applications

Security • Schools • Construction • Retail Stores • Manufacturing/Warehousing
Special Events • Maintenance • Hotel/ Motel/Property Management

J-Series Accessories



BP-Li-18
1800 mAh Li-Ion
Battery Pack



CB-SLX
Spring Action
Belt Clip



BC-JX
Dual Slot Desktop 2.5 Hour Rapid
Charger (100-240 VAC, 47-64 Hz)
Holds two batteries. Charges
sequentially (front to back).



RHD-11X
Security Earset with Pendant
Microphone, PTT and Clip



RSM-5XA
Speaker Microphone with
Rotating Spring Action Clip



RHD-14X
Lapel Microphone, PTT and
Earloop with Clip



RHD-12X
Behind-the-Head Headset with
Boom Microphone, PTT and Clip

* For superior durability, all J-Series audio accessories feature a low-profile strain relief connector.

Your Ritron Dealer:

Compatible Ritron Products



OutPost® Radio Call Box

Put communication right where it's needed with an OutPost radio call box. Provides long-range (miles, not feet) voice communication between the call box and radio-equipped personnel, even the most remote locations. Ideal for golf courses, parking lots, gated entry points.



DoorCom® Wireless Intercom

Improves communication, security and efficiency. Installs easily at any door. Permits visitors to announce their arrival via radio. Long-range allows radio-equipped staff to receive the call from anywhere in the building and instantly answer back using their 2-way radio.



QuickAssist®

Designed for retail applications. Allows customer to send a wireless page directly to a sales clerk. Retailer benefits from efficient use of manpower and quicker customer response. Annoying overhead paging is eliminated.



Quick Talk™

It's like being in 2 places at once! 24/7 wireless monitoring of any switch or sensor without the cost of additional manpower. Unit sends wireless voice message directly to any 2-way radio. Use to alert of power failure, machine down, tamper, panic button.

Desk-Top Base Station/Wireless Intercom

Fixed location 2-way radio, compact size, desk top or wall mount capable. AC and/or 12VDC powered.
Always Ready...Always There...Always On!

Coverage estimates: At full power, line-of-sight, no obstructions the range is approximately 2+miles. Indoor coverage at VHF is approximately 270,000 sq ft and 300,000 sq ft at UHF. Expect about 10 floors vertical coverage at VHF and up to 15 floors at UHF.

Note: Range and coverage are estimates and are not guaranteed.

Go Beyond Normal Limits...™



505 W. Carmel Drive, Carmel, IN 46032 • ph: 317-846-1201 • fx: 317-846-4978
email: sales_info@ritron.com • website: www.ritron.com

©2005-2006 Ritron, Inc. All rights reserved. Ritron, DoorCom, Jobcom, OutPost, GateGuard, QuickAssist and RadioNexus are registered trademarks of Ritron, Inc. Quick Talk and Liberty are trademarks of Ritron, Inc. P/N 14610041 2013