

Mastermind of synchronized time.

Improve punctuality, productivity & efficiency in the workplace with perfectly synchronized time. Choose from standard analog or highly visible LED digital clocks. Add on bells for the highest level of workplace productivity.



Clocks & bells sold separately.



- Improves punctuality, productivity & efficiency
- Synchronizes up to 200 analog or digital wall clocks
- Powers up to 8 analog clocks (part #5200), up to 35 bells (part #41361, 41392) and up to 20 horns (part #41362)
- Schedules up to 300 bell or horn events
- Automatic Daylight Saving Time adjustment
- Automatic Time correction within 2 minutes of power restoration



scan

Smart.
scan QR code for
industry solutions




TIMETRAX™ Sync 7000

Master Clock Controller



SPECIFICATIONS	
Time Set	Manual
Power Output	800mA
BCD Updates	Up to 200 clocks, 8 bells & 20 horns (powers up to 8 model 5200 Analog Clocks)
Operating Temp	-30° F (-34.44° C) to 130° F (54.44° C)
Display	LCD, time & date
Housing	Textured powder coat surface metal
Color	Black
Mounting	Wall Mount
Warranty	1-Year manufacturer's limited warranty
Dimensions	5.5inW x 7.125inH x 1.75inD (13.9cm x 18.1cm x 4.4cm)
Weight	1.81lbs (.81kg)
Shipping Weight	4.451lbs (2.01kg)

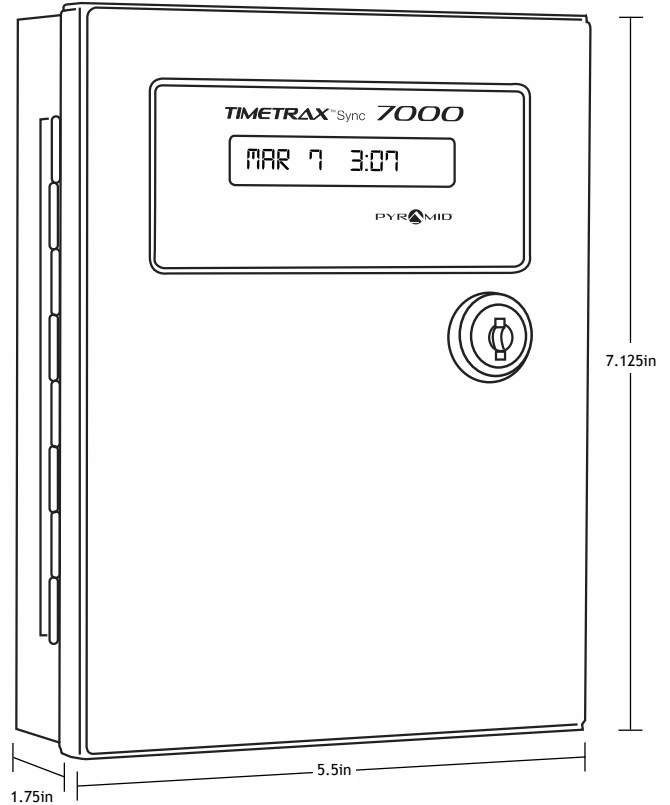

ACCESSORIES	
PART #	DESCRIPTION
41357G	4" x 4-digit Red LED Digital Clock
613576	4" x 6-digit Red LED Digital Clock
5200	13" Analog Clock 12 Hour Face
41269	RJ45 BCD Cable, 50'
41314	RJ45 BCD Cable, 100'
41270	RJ45 Y-Splitter Cable
41361	6" 24 Volt DC Bell
41392	8" 24 Volt DC Bell
41362	24 Volt DC Horn
41449	Bell Wire, 100' Spool
41450	Bell Wire, 250' Spool

¹Powers eight 5200 Analog Clocks.

