 




# ***FIRE TOOLS***


**GET THE STRIPE**




**Pike Pole  
D-Grip**



**Pike Pole  
Butt Grip**

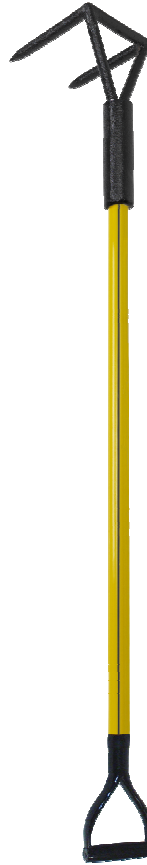

 **Rubbish Hook /  
Ventilation  
Hook Pole  
D-grip**



**Ceiling Wall  
Hook Pole  
D-grip**



**Two-piece Pike Pole  
head end and butt  
grip end**



**Two-piece Rubbish  
Hook head end and  
D-grip end**






# ***FIRE TOOLS***


**GET THE STRIPE**




**Pick Head Fire Axe  
Ergo handle**

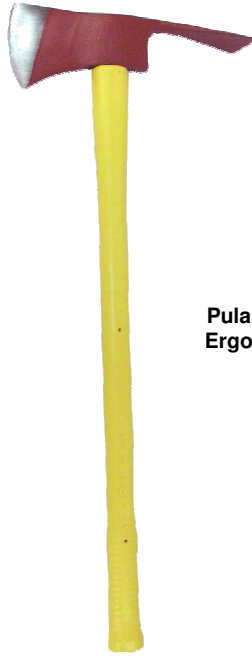

**Pulaski Axe  
Ergo handle**

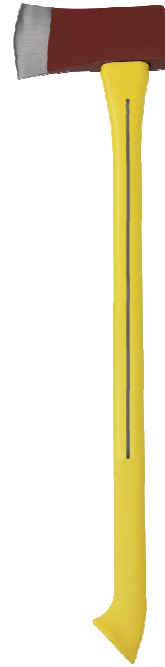

**Flat Head Fire Axe  
Ergo handle**

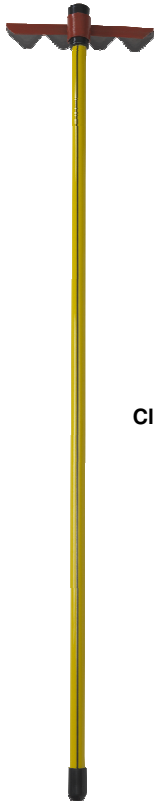

**Fire Rake  
Classic handle**



**Fire Swatter  
Classic handle**



**McLeod Fire Rake  
Classic handle**

**Fire Pole** handles are made of Nuplaglas® through a pultrusion process that uses a unique resin and thousands of strands of fiberglass with solid reinforcement bars at critical stress points of the handle. This design produces optimum strength-to-weight ratios and provides safety and durability in heavy duty applications. Handles have a choice of butt grips or steel D-grips. Nuplaglas® handles have excellent dielectric properties and provide additional safety in wet conditions. Smooth, resin rich handle surfaces protect users from splinters and resist UV deterioration. Handles are unaffected by cuts, blows, moisture, most industrial chemicals and are easy to clean. They have an extended job life since they are unaffected by fungus, termites or dry rot as with wood handles.

**Fire Axes** and the **Pulaski** feature Ergo Power® injection-molded handles in safety-yellow. The Ergo handle has a solid Nuplaglas® core made through a pultrusion process that uses a unique resin and thousands of strands of fiberglass becoming resistant to weather and chemicals. It will not conduct heat/cold or absorb moisture. The ergonomically designed 36" contoured handle with a deer-foot grip style prevents slippage even in wet conditions. Due to less gripping effort, it reduces arm strain and fatigue. Handles are unaffected by cuts, blows, moisture, most industrial chemicals and are easy to clean. They have a high shelf life since they are unaffected by fungus, termites or dry rot as with wood handles. All tools are designed for safety, strength and durability. The handles are more rigid and considerably safer than wood.

**Pike Poles** have a 2.5 lb. ductile iron pike head in 6 or 8 ft. fiberglass handle lengths with butt or steel D-grip options. The Poles are used by firefighters to pull down and search for fires hidden behind sheetrock in walls and ceilings, and for ventilating structures. Also used for salvage operations and in such events as constructing water chutes to displace water. Ductile iron head can withstand intense heat and flame. Poles are used for reaching, holding, pulling, lifting such as the sides of a timber framed structures. Also used in lumbering i.e. log rafting to control floating logs.

**Rubbish/Roof Ventilation Hook Poles** have a 5.18 lb. ductile iron cast head in 6 or 8 ft. fiberglass handle lengths with a steel D-grip. This is a rugged tool used for ventilation of buildings constructed of modern sheet material such as plywood. The head has two hooks for enhanced control of sheet materials and broad surface for sounding. "V" structural supports prevent hook from hanging up.

**Ceiling/Wall Hook Pole** has a 2.5 lb. ductile iron cast head in a 4 ft. Nuplaglas® handle length with a steel D-grip. The Hook Pole is used for ventilating lathe/plaster and sheet materials. A honed point penetrates up to 4" of material and creates a broad opening while its four broad teeth grip the material firmly. Set at 45 degrees, the hook facilitates working in tight confines.

**2-piece Pike and Rubbish/Roof Ventilation Hook Poles** are a knockdown version of standard poles, designed for easy field assembly with less costly transportation. Available in 8 or 10 ft. lengths with choice of butt or steel D-grips. Kits include head end with fiberglass handle, grip end with steel sleeve, pins and epoxy kit.

**Pick Head Axe 6 lb.** has a drop forged, heat treated, red-trim head with polished blade and 36" Ergo handle. The ground, tempered cutting blade edge enhances nick resistance and prolongs wear of the blade. The 6 lb. head and heavy duty Ergo handle are well balanced. The Pick Head Axe is used for fast cutting in critical fire situations. The pointed pick end is used for penetration of objects whereas the cutting axe edge is used for making deep, clean and fast cuts.

**Pulaski Axe 3.5 lb.** combination axe and grub hoe has a drop forged, heat treated head and 36" Ergo handle. The ground and tempered cutting edge enhances nick resistance and prolongs wear of the blade. The Pulaski Axe is used for digging fire lines in soft and hard soils.

**Flat Head Axe 6 lb.** has a drop forged, heat treated, red-trim head with polished blade and 36" Ergo handle. The ground, tempered cutting blade edge enhances nick resistance and prolongs wear of the blade. The 6 lb. head and heavy duty Ergo handle are well balanced. The Flat Head Axe is used for fast cutting in critical fire situations. The cutting axe edge is wedge shaped and used for making deep, clean and fast cuts.

**Fire Rake** has a 1.94 lb. heat treated drop forged angle iron 12” head with 4 tempered V-shaped sharp teeth and a 60” press-fit fiberglass handle with cap grip. The Rake is used for raking fire lines, digging, rolling burning logs and cutting grass, small brush or saplings.

**Fire Swatter** has a 3.53 lb. neoprene flap 12” x 15.25”, with a 60” fiberglass handle and a cap grip. The Swatter is used to smother and extinguish fires in grass, straw and low weeds.

**McLeod Forester Fire Hoe/Rake** has a 3.2 lb. head, 10.25” x 8.88”, with 6 drop forged, tempered tines, and a 4 ft. fiberglass handle with cap grip. The combination hoe/rake is used when building a fire line for raking, scraping, grubbing and tamping to remove plants and shrubs.

| COMP. NUPLA PART | PART NUMBER | GRAINGER PART | PART DESCRIPTION   | Grip Type        | Tip Type     | Head   | Handle | Handle Material                   |
|------------------|-------------|---------------|--|------------------|--------------|--------|--------|-----------------------------------|
|                  |             |               |  |                  | Size         | Weight | Length |                                   |
|                  |             |               |  |                  | (in.)        | (lbs.) | (in.)  | (in.)                             |
| <b>Fire</b>      |             |               |  |                  |              |        |        |                                   |
| 31687            | 6894272     | 1THA3         | 6lb Pick Head Axe, 36" Ergo Power Slim contoured handle, single bit grip | Contoured        | 4 3/4        | 6      | 36     | Fiberglass w/Polypro Outer Jacket |
| 31776            | 6894273     | 1THA4         | 3.5lb Pulaski Axe, 36" Ergo Power handle, CS grip                        | CS               | 4 1/2        | 3 1/2  | 36     | Fiberglass w/Polypro Outer Jacket |
| 33661            | 6894274     | 1THA5         | 6lb Flat Head Axe, 36" Ergo Power handle, SG grip                        | Contoured        | 4 3/4        | 6      | 36     | Fiberglass w/Polypro Outer Jacket |
| 35616            | 6894240     | 2LTA9         | 4' Ceiling/Wall Hook Pole, Heavy Duty Classic Round, D-grip              | Steel D          | 5 x 2 2.5    | 2.25   | 48     | Fiberglass                        |
| 36106            | 6894235     | 2LTA4         | 6' Pike Pole, Heavy Duty Classic Round, D-grip                           | Steel D          | 10 x 4.25    | 2.5    | 72     | Fiberglass                        |
| 36108            | 6894237     | 2LTA6         | 8' Pike Pole, Heavy Duty Classic Round, D-grip                           | Steel D          | 10 x 4.25    | 2.5    | 96     | Fiberglass                        |
| 36206            | 6894234     | 2LTA3         | 6' Pike Pole, Heavy Duty Classic Round, Butt grip                        | Polythylene Butt | 10 x 4.25    | 2.5    | 72     | Fiberglass                        |
| 36208            | 6894236     | 2LTA5         | 8' Pike Pole, Heavy Duty Classic Round, Butt grip                        | Polythylene Butt | 10 x 4.25    | 2.5    | 96     | Fiberglass                        |
| 36560            | 6894238     | 2LTA7         | 6' Rubbish/Roof Ventilation Pole, Heavy Duty Classic Round, D-grip       | Steel D          | 12 x 6.5     | 5.18   | 72     | Fiberglass                        |
| 36566            | 6894239     | 2LTA8         | 8' Rubbish/Roof Ventilation Pole, Heavy Duty Classic Round, D-grip       | Steel D          | 12 x 6.5     | 5.18   | 96     | Fiberglass                        |
| 69214            | 6894244     | 2LTC4         | Classic Fire Rake, 60" Press-Fit Fire Handle, end cap                    | Polythylene Cap  | 12 x 3.19    | 1.94   | 60     | Fiberglass                        |
| 69215            | 6894243     | 2LTC3         | Classic Fire Beater/Swatter, 60" Nuplabond Handle, end cap               | Polythylene Cap  | 12 x 15.25   | 3.52   | 60     | Fiberglass                        |
| 69216            | 6894242     | 2LTC2         | McLeod Tool,,combination hoe and rake, 48" Classic handle, butt grip     | Polythylene Cap  | 10.25 x 8.88 | 3.2    | 48     | Fiberglass                        |
| 35256            | 6894241     | 2LTC1         | 6' Ceiling/Wall Hook Pole, Heavy Duty Classic Round, D-grip              | Steel D          | 5 x 2.25     | 2.25   | 60     | Fiberglass                        |
| 36750            | 6894289     | 4GFY7         | 8 Ft. 2Pc Pike Pole, Butt Grip   | Polythylene Butt | 10 x 4.25    | 2.5    | 96     | Fiberglass                        |
| 36751            | 6894290     | 4GFY8         | 10 Ft. 2Pc Pike Pole, Butt Grip  | Polythylene Butt | 10 x 4.25    | 2.5    | 120    | Fiberglass                        |
| 36753            | 6894291     | 4GFY9         | 8 Ft. 2Pc Pike Pole, D-Grip  | Steel D          | 10 x 4.25    | 2.5    | 96     | Fiberglass                        |
| 36754            | 6894292     | 4GFZ1         | 10 Ft. 2Pc Pike Pole, D-Grip   | Steel D          | 10 x 4.25    | 2.5    | 120    | Fiberglass                        |
| 36759            | 6894293     | 4GFZ2         | 8 Ft. 2Pc Rubbish/Roof Vent Hook   | Polythylene Cap  | 12 x 6.5     | 5.18   | 96     | Fiberglass                        |
| 36760            | 6894294     | 4GFZ3         | 10 Ft. 2Pc Rubbish/Roof Vent Hook  | Polythylene Cap  | 12 x 6.5     | 5.18   | 120    | Fiberglass                        |
| 36762            | 6894295     | 4GFZ4         | 8 Ft. 2Pc Rubbish/Roof Vent Hook, D-Grip                                 | Steel D          | 12 x 6.5     | 5.18   | 96     | Fiberglass                        |
| 36763            | 6894296     | 4GFZ5         | 10 Ft. 2Pc Rubbish/Roof Vent Hook D-Grip                                 | Steel D          | 12 x 6.5     | 5.18   | 120    | Fiberglass                        |

For more information contact your Grainger Representative or visit [Grainger.com](http://Grainger.com)®

