


# RED BRASS

# SOLID & CORED PLUGS

## Features

- 125 Class
- 100% Inspected and tested
- Max pressure 150 PSI
- Temperature -65° to 250°F

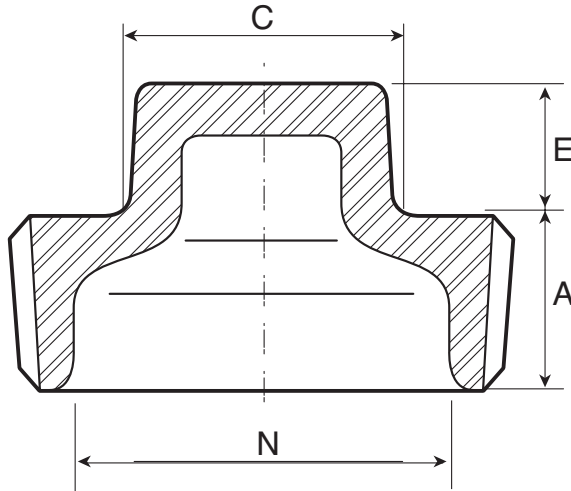

Part No.	Size	
1VFP6	1/8"	Threaded
1VFP8	1/4"	Threaded
1VFR1	3/8"	Threaded
1VFR3	1/2"	Threaded
1VFR5	3/4"	Threaded
1VFR7	1"	Threaded
1VFR9	1-1/4"	Threaded
1VFT2	1-1/2"	Threaded
1VFT4	2"	Threaded
1VFT6	2-1/2"	Threaded
1VFT8	3"	Threaded
1VJV1	4"	Threaded

Dimensions are in inches

Part No.	Size	A	C	E	N
1VFP6	1/8"	0.27	9/32	0.24	—
1VFP8	1/4"	0.41	3/8	0.28	—
1VFR1	3/8"	0.41	7/16	0.61	—
1VFR3	1/2"	0.54	9/16	0.38	0.53
1VFR5	3/4"	0.55	5/8	0.44	0.72
1VFR7	1"	0.69	13/16	0.50	0.93
1VFR9	1-1/4"	0.71	15/16	0.56	1.25
1VFT2	1-1/2"	0.73	1-1/8	0.62	1.47
1VFT4	2"	0.76	1-5/16	0.68	1.91
1VFT6	2-1/2"	1.07	1-1/2	0.74	2.32
1VFT8	3"	1.13	1-11/16	0.80	2.90
1VJV1	4"	1.22	2-1/4	0.92	3.83

- Bronze material meets ANSI/ASTM B62 standard
- Dimensions meet ANSI/ASME B16.15-1985 standard
- Threads meet ANSI B1.20.1