

INSULATED CUSHION GRIP SCREWDRIVERS 15 PIECE SET

wiha 

Tools that work for you

Insulation according to ASTM F-1505, VDE 0682/part 201, EN/IEC 60900, NFPA70E & CSA specifications. Individually tested to 10,000 Volts & certified to 1000 Volt AC or 1500 Volt DC. Responds to OSHA's use specification 29 CFR1910

SKU: 32190 **Grainger #: 1YUL5**

Details

- Solid Molded Core Handle Has Soft Outer Cushion Grips For Comfort, 40% More torque than Conventional Handles
- Blade Chrome-Vanadium-Molybdenum Tool Steel, Hardened For Best Wear Resistance
- Black Finish Tips, Precision Machined For Exact Fit
- In Zipper Carry Case
- Professional Quality Tools - Made By Wiha



15 Piece Set Include:

Slotted

- Slotted 2.0mm
- Slotted 2.5mm
- Slotted 3.0mm
- Slotted 3.5mm
- Slotted 4.5mm
- Slotted 6.5mm
- Slotted 8.0mm

Phillips

- Phillips #1
- Phillips #2
- Phillips #3

Inch Nut Drivers

- Inch 1/4
- Inch 5/16
- Inch 3/8
- Inch 7/16
- Inch 1/2

Weight (lbs)	5.9000
RoHS Compliant	Yes
Head Type	Slotted, Phillips, Inch Nut Drivers
Pieces In Set	15
UPC	084705321905
UNSPSC	27111736

Insulation Test Standards:

Insulation according to EN/IEC 60900, ASTM F-1505, New VDE 0682/part 201, DIN 7437, NFPA70E & CSA


Insulation

Molded directly onto the blade for permanent bonding

 1000V

Blade

CVM tool steel, hardened to average 58/60RC

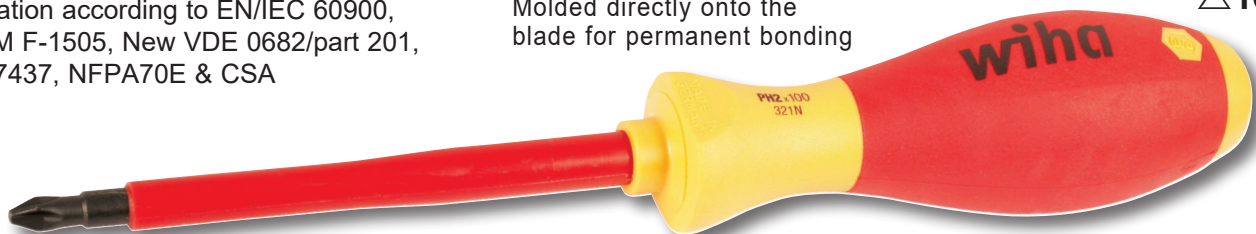

Each tool individually tested to 10,000 Volts & certified to 1000 Volt ac or 1500 Volt dc