

# Miller MightyLite™ Self-Retracting Lifelines

## FEATURES

- Corrosion-resistant stainless steel and aluminum housing components and housing extend service life
- No annual factory recertification required\*  
\*Except in Canada where the Canadian Standards Association requires annual factory recertification.
- Rated to 310-lbs. (140.6 kg) capacity
- Carabiner and tagline included\*\*
- Available in 20-ft. (6 m), 30-ft. (9 m), 50-ft. (15 m), 65-ft. (20 m), 100-ft. (30 m), 130-ft. (40 m) and 175-ft. (53 m) lengths

UP TO 30% LIGHTER THAN  
COMPETITIVE MODELS




SKU	Description	Length	Weight
<b>MILLER MIGHTYLITE SELF-RETRACTING LIFELINES</b>			
<b>ANSI Z359</b>			
RL20G-Z7/20FT	Galvanized wire rope (3/16-in. [5 mm]) w/tagline & carabiner	20-ft. (6 m)	12 lbs. (5.4 kg)
RL20P-Z7/20FT	Polyester webbing (1-in. [25 mm]) w/tagline & carabiner	20-ft. (6 m)	11 lbs. (5.0 kg)
RLS30G-Z7/30FT	Galvanized wire rope (3/16-in. [5 mm]) w/tagline & carabiner	30-ft. (9 m)	14 lbs. (6.4 kg)
RL50G-Z7/50FT	Galvanized wire rope (3/16-in. [5 mm]) w/tagline & carabiner	50-ft. (15 m)	22 lbs. (10.0 kg)
RL50P-Z7/50FT	Polyester webbing (1-in. [25 mm]) w/tagline & carabiner	50-ft. (15 m)	21 lbs. (9.5 kg)
RL65G-Z7/65FT	Galvanized wire rope (3/16-in. [5 mm]) w/tagline & carabiner	65-ft. (20 m)	30 lbs. (10.4 kg)
RL100G-Z7/100FT	Galvanized wire rope (3/16-in. [5 mm]) w/tagline & carabiner	100-ft. (30 m)	53 lbs. (24.0 kg)
RL130G-Z7/130FT	Galvanized wire rope (3/16-in. [5 mm]) w/tagline & carabiner	130-ft. (40 m)	56 lbs. (25.4 kg)
RL175G-Z7/175FT	Galvanized wire rope (3/16-in. [5 mm]) w/tagline & carabiner	175-ft. (53 m)	70 lbs. (31.8 kg)
<b>ANSI A10.32</b>			
RL20P/20FT	Polyester webbing (1-in. [25 mm]) w/tagline & carabiner	20-ft. (6 m)	11 lbs. (5.0 kg)
RL20G/20FT	Galvanized wire rope (3/16-in. [5 mm]) w/tagline & carabiner	20-ft. (6 m)	12 lbs. (5.4 kg)
RL20SS/20FT	Stainless steel wire rope (3/16-in. [5 mm]) w/tagline & carabiner	20-ft. (6 m)	12 lbs. (5.4 kg)
RLS30G/30FT	Galvanized wire rope (3/16-in. [5 mm]) w/tagline & carabiner	30-ft. (9 m)	14 lbs. (6.4 kg)
RLS30S/30FT	Stainless steel wire rope (3/16-in. [5 mm]) w/tagline & carabiner	30-ft. (9 m)	14 lbs. (6.4 kg)
RL50P/50FT	Polyester webbing (1-in. [25 mm]) w/tagline & carabiner	50-ft. (15 m)	19 lbs. (8.6 kg)
RL50G/50FT	Galvanized wire rope (3/16-in. [5 mm]) w/tagline & carabiner	50-ft. (15 m)	20 lbs. (9.1 kg)
RL50SS/50FT	Stainless steel wire rope (3/16-in. [5 mm]) w/tagline & carabiner	50-ft. (15 m)	21 lbs. (9.5 kg)
RL65G/65FT	Galvanized wire rope (3/16-in. [5 mm]) w/tagline & carabiner	65-ft. (20 m)	24 lbs. (10.9 kg)
RL65SS/65FT	Stainless steel wire rope (3/16-in. [5 mm]) w/tagline & carabiner	65-ft. (20 m)	24 lbs. (10.9 kg)
RL100G/100FT	Galvanized wire rope (3/16-in. [5 mm]) w/tagline & carabiner	100-ft. (30 m)	54 lbs. (24.5 kg)
RL100SS/100FT	Stainless steel wire rope (3/16-in. [5 mm]) w/tagline & carabiner	100-ft. (30 m)	54 lbs. (24.5 kg)
RL130G/130FT	Galvanized wire rope (3/16-in. [5 mm]) w/tagline & carabiner	130-ft. (40 m)	56 lbs. (25.4 kg)
RL130SS/130FT	Stainless steel wire rope (3/16-in. [5 mm]) w/tagline & carabiner	130-ft. (40 m)	56 lbs. (25.4 kg)
RL175G/175FT	Galvanized wire rope (3/16-in. [5 mm]) w/tagline & carabiner	175-ft. (53 m)	70 lbs. (31.8 kg)
RL175SS/175FT	Stainless steel wire rope (3/16-in. [5 mm]) w/tagline & carabiner	175-ft. (53 m)	70 lbs. (31.8 kg)

\*\*Available without the tagline and carabiner. To order, add a "B" to the corresponding model number (Ex: RL20BP/20FT). Also available with a stainless steel swivel top and stainless steel swivel snap hook. To order, add an "S" to corresponding model number (Ex: RL20SS-S/20FT). Locking Snap Hook – 3/4-in. (19 mm) gate opening; Locking Rebar Hook – 2-1/2-in. (64 mm) gate opening.

## Miller MightyLite Swivel Brackets

Swivel bracket reduces webbing or cable wear and increases worker mobility. Applications include leading edge deck construction, warehouse pickers, bridge construction, steel erection and industrial. Constructed of corrosion-resistant, heavy-duty zinc-plated steel and stainless steel, the swivel bracket is easy to retrofit on existing MightyLite units.

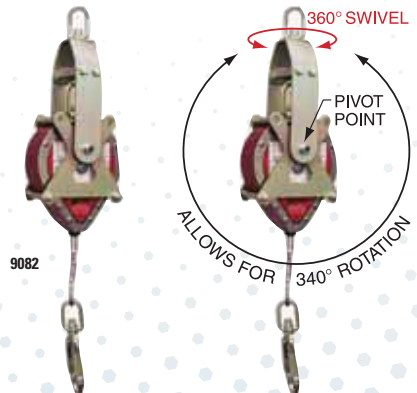

SKU	Description
<b>MILLER MIGHTYLITE SWIVEL BRACKETS</b>	
9082	Swivel bracket (retrofit) for 20-ft. (6 m) & 30-ft. (9 m) MightyLite units
9083	Swivel bracket (retrofit) for 50-ft. (15 m) & 65-ft. (20 m) MightyLite units