

Miller MightyLite™ Self-Retracting Lifeline

Description

Miller MightyLite Self-Retracting Lifelines (SRLs) are up to 30% lighter than competitive models in their class. Durable and dependable, they are constructed of corrosion-resistant stainless steel and aluminum housing.

Materials

Housing:	Aluminum Alloy, Stainless
Drum:	Aluminum Alloy, Stainless
Mainspring:	Stainless Steel
Break Pawls:	Stainless Steel
Main Shaft:	RL20 Aluminum Alloy, all other units Stainless Steel
Bushing:	RL20 Rulon, all other units Ball & Roller Bearing


Technical

Max. Working Load:	310 lbs. (141kg)
Working Load Capacity:	20 ft. (6.1 m), 30 ft. (10 m), 40 ft. (12 m), 50 ft. (15 m), 65 ft. (20 m), 80 ft. (24 m), 100 ft. (30 m) 130 ft. (40 m), 175 ft. (53 m)
Max. Arrest Distance	54-in. (1.4 m)
Avg. Arresting Force:	900 lbs. (4kN) (When tested to ANSI Z359.14)
Max. Peak Arresting Force:	1,800 lbs. (8kN) (When tested to ANSI Z359.14)
Max. Peak Arresting Force:	900 lbs. (4kN) (When tested to OSHA 1926.502 and CSA Z259.2.2)
Ultimate Strength:	3,000 lbs. (13kN)

Certification

Meets OSHA 1926.502, 1910.66, ANSI A10.32, *ANSI Z359.14-2012 Class B and CSA Z259.2.2-98 Type 2 requirements

*ANSI Z359 compliant for connectors which meet the 3,600lb gate requirements.

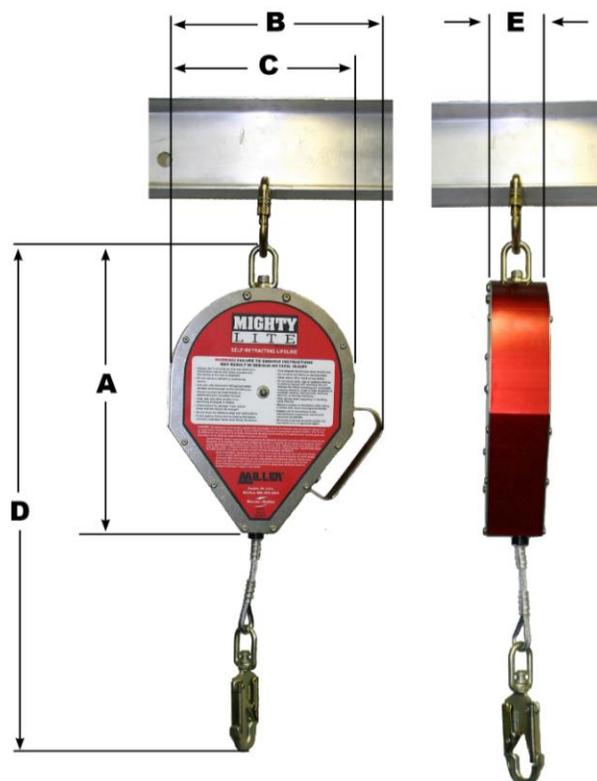

RL50G/50FT shown
Dimensions specified on page 2



RL20P-Z7/20FT

Miller MightyLite™ Self-Retracting Lifeline

Model	Lifeline	Length	*Weight	A	B	C	D	E
ANSI A10.32 Compliant								
RL20P/20FT	1" Polyester	20 ft	8 lbs	10.5"	N/A	6.38"	23.5"	2.25"
RL20G/20FT	3/16" Galvanized	20 ft	10 lbs	10.5"	N/A	6.38"	23.5"	2.25"
RL20K/20FT	3/16" Kevlar Rope	20 ft	10 lbs	10.5"	N/A	6.38"	23.5"	2.25"
RL20SS/20FT	3/16" Stainless	20 ft	10 lbs	10.5"	N/A	6.38"	23.5"	2.25"
RLS30G/30FT	3/16" Galvanized	30 ft	12 lbs	10.5"	N/A	6.38"	23.5"	3.15"
RLS30S/30FT	3/16" Stainless	30 ft	12 lbs	10.5"	N/A	6.38"	23.5"	3.15"
RL30G/30FT	3/16" Galvanized	30 ft	14 lbs	15.75"	11.75"	10.0"	28.75"	3.0"
RL30SS/30FT	3/16" Stainless	30 ft	14 lbs	15.75"	11.75"	10.0"	28.75"	3.0"
RL40K/40FT	3/16" Kevlar Rope	40 ft	24 lbs	15.75"	11.75"	10.0"	28.75"	3.0"
RL50P/50FT	1" Polyester	50 ft	20 lbs	15.75"	11.75"	10.0"	28.75"	3.0"
RL50G/50FT	3/16" Galvanized	50 ft	20 lbs	15.75"	11.75"	10.0"	28.75"	3.0"
RL50SS/50FT	3/16" Stainless	50 ft	20 lbs	15.75"	11.75"	10.0"	28.75"	3.0"
RL65G/65FT	3/16" Galvanized	65 ft	22 lbs	15.75"	11.75"	10.0"	28.75"	3.0"
RL65SS/65FT	3/16" Stainless	65 ft	46 lbs	15.75"	11.75"	10.0"	28.75"	3.0"
RL80K/80FT	3/16" Kevlar Rope	80 ft	46 lbs	16.0"	12.0"	10.0"	28.75"	5.25"
RL100G/100FT	3/16" Galvanized	100 ft	46 lbs	15.75"	11.75"	10.0"	28.75"	5.0"
RL100SS/100FT	3/16" Stainless	100 ft	46 lbs	15.75"	11.75"	10.0"	28.75"	5.0"
RL130G/130FT	3/16" Galvanized	130 ft	48 lbs	15.75"	11.75"	10.0"	28.75"	5.0"
RL130SS/130FT	3/16" Stainless	130 ft	48 lbs	15.75"	11.75"	10.0"	28.75"	5.0"
RL175G/175FT	3/16" Galvanized	175 ft	71 lbs	15.75"	11.75"	10.0"	28.75"	7.18"
RL175SS/175FT	3/16" Stainless	175 ft	70 lbs	16.0"	12.0"	10.0"	28.75"	7.5"
ANSI Z359 and CSA Z259.12-11 Compliant								
RL20P-Z7/20FT	1" Polyester	20 ft	8 lbs	10.5"	N/A	6.38"	23.5"	2.25"
RL20G-Z7/20FT	3/16" Galvanized	20 ft	10 lbs	10.5"	N/A	6.38"	23.5"	2.25"
RL20K-Z7/20FT	3/16" Kevlar Rope	20 ft	10 lbs	10.5"	N/A	6.38"	23.5"	2.25"
RL20SS-Z7/20FT	3/16" Stainless	20 ft	10 lbs	10.5"	N/A	6.38"	23.5"	2.25"
RLS30G-Z7/30FT	3/16" Galvanized	30 ft	12 lbs	10.5"	N/A	6.38"	23.5"	3.15"
RLS30S-Z7/30FT	3/16" Stainless	30 ft	12 lbs	10.5"	N/A	6.38"	23.5"	3.15"
RL30G-Z7/30FT	3/16" Galvanized	30 ft	14 lbs	15.75"	11.75"	10.0"	28.75"	3.0"
RL30SS-Z7/30FT	3/16" Stainless	30 ft	14 lbs	15.75"	11.75"	10.0"	28.75"	3.0"
RL40K-Z7/40FT	3/16" Kevlar Rope	40 ft	24 lbs	15.75"	11.75"	10.0"	28.75"	3.0"
RL50P-Z7/50FT	1" Polyester	50 ft	20 lbs	15.75"	11.75"	10.0"	28.75"	3.0"
RL50G-Z7/50FT	3/16" Galvanized	50 ft	20 lbs	15.75"	11.75"	10.0"	28.75"	3.0"
RL50SS-Z7/50FT	3/16" Stainless	50 ft	20 lbs	15.75"	11.75"	10.0"	28.75"	3.0"
RL65G-Z7/65FT	3/16" Galvanized	65 ft	22 lbs	15.75"	11.75"	10.0"	28.75"	3.0"
RL65SS-Z7/65FT	3/16" Stainless	65 ft	46 lbs	15.75"	11.75"	10.0"	28.75"	3.0"
RL80K-Z7/80FT	3/16" Kevlar Rope	80 ft	46 lbs	16.0"	12.0"	10.0"	28.75"	5.25"
RL100G-Z7/100FT	3/16" Galvanized	100 ft	46 lbs	15.75"	11.75"	10.0"	28.75"	5.0"
RL100SS-Z7/100FT	3/16" Stainless	100 ft	46 lbs	15.75"	11.75"	10.0"	28.75"	5.0"
**RL130G-Z7/130FT	3/16" Galvanized	130 ft	48 lbs	15.75"	11.75"	10.0"	28.75"	5.0"
**RL130SS-Z7/130FT	3/16" Stainless	130 ft	48 lbs	15.75"	11.75"	10.0"	28.75"	5.0"
**RL175G-Z7/175FT	3/16" Galvanized	175 ft	71 lbs	15.75"	11.75"	10.0"	28.75"	7.18"
RL175SS-Z7/175FT	3/16" Stainless	175 ft	70 lbs	16.0"	12.0"	10.0"	28.75"	7.5"
**RL175SS-Z7/175FT	3/16" Stainless	175 ft	71 lbs	15.75"	11.75"	10.0"	28.75"	7.18"
RL20P-Z7/20FT	1" Polyester	20 ft	8 lbs	10.5"	N/A	6.38"	23.5"	2.25"

*Weight does not include carabiner or tagline

**Meets ANSI Z359.1-2007 only.



by Honeywell

Toll Free 800.873.5242 (press 4) • hsptechsupport@honeywell.com • www.millerfallprotection.com

WARNING! THIS DOCUMENT PROVIDES AN OVERVIEW OF FALL PROTECTION PRODUCTS AVAILABLE FROM HONEYWELL AND CARE HAS BEEN TAKEN TO ASSURE THE ACCURACY OF THE DATA. IT DOES NOT PROVIDE IMPORTANT PRODUCT WARNINGS AND INSTRUCTIONS. HONEYWELL RECOMMENDS ALL USERS OF FALL PROTECTION EQUIPMENT UNDERGO THOROUGH TRAINING, AND THAT ALL WARNINGS AND INSTRUCTIONS PROVIDED WITH THE PRODUCTS BE THOROUGHLY READ AND UNDERSTOOD PRIOR TO EACH USE. FAILURE TO READ AND FOLLOW ALL PRODUCT WARNINGS AND INSTRUCTIONS COULD RESULT IN SERIOUS INJURY OR DEATH.