

6200 Series

ROUND HARDBOARD HEAVY DUTY STEEL STOOLS



products meet or exceed applicable ANSI/BIFMA standards




MODEL 6218HB SHOWN



BACK ADJUSTS 2" UP/DOWN AND 2" FORWARD/BACK

8 RIVETS ON SEAT TO PREVENT WARPING

MODEL 6224H SHOWN

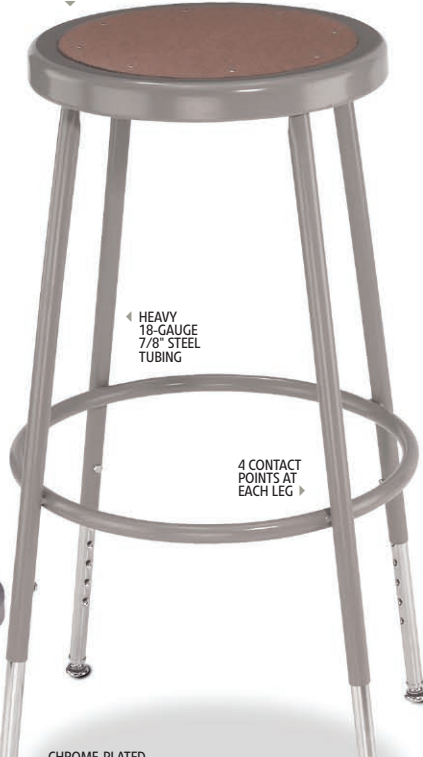

HEAVY 18-GAUGE 7/8" STEEL TUBING

4 CONTACT POINTS AT EACH LEG

MODEL 6218 SHOWN



CHROME-PLATED ADJUSTABLE HEIGHT INSERTS

PLASTIC GUIDES

300lb. weight capacity!

Stools come in 3 convenient sizes:

- **18"** for use with your **30"** table
- **24"** for use with your **36"** table
- **30"** for use with your **42"** table

or use adjustable legs for alternate height options

SPECS:

- 18"H, 24"H or 30"H sizes fixed height and adjustable with an optional backrest
- 7/8" O.D. 18-gauge steel tubing
- Seat is a full 14" diameter with 11 1/2" diameter masonite board recessed into the pan with 8 rivets and will not chip or crack
- Foot rings, 5/8" O.D. are welded to each leg by 4 contact points at each leg for added rigidity
- Optional backrest; 6"H x 12"W, adjusts up/down and forward/back
- Optional height adjustable legs; adjust in 1" increments up to eight additional inches

National Public Seating



800.261.4112 | www.nationalpublicseating.com

