



Cut



Medium Duty

High visibility with superior cut resistance and durability

- Experience exceptional comfort and durability combined with ANSI Level 5 Cut performance and high visibility. The new HyFlex® 11-515 glove is ergonomically designed so users are more likely to wear the glove
- It helps keep workers visible in low light situations thus reducing the opportunities for hand injuries to occur
- The HyFlex® 11-515 glove has several outstanding features, including INTERCEPT TECHNOLOGY® yarn developed by Ansell and DuPont™, which incorporates Kevlar® Stretch Armor Technology
- The extended cuff provides additional cut protection in the highly sensitive wrist area. Our foam nitrile formulation provides longer wear for increased durability
- The HyFlex® 11-515 offers superior grip and tactility in light oil or dry environments, providing sure grip and assurance when handling sharp objects and knives.
- With incredible cut protection, high visibility and a relaxed fit, the HyFlex® 11-515 enables your workers to perform safely and efficiently

Industries

- Automotive
- Metal fabrication

Applications

- Press shop operations
- Handling metal sheets & panels
- Inspection, selecting, checking parts
- Processing sheets, coils, tubes
- Cutting glasses, sheets, panels




Key Features

- Ability to handle sharp parts and knives with confidence, increasing worker output and security in light oil or dry applications
- Provides ANSI Level 4 abrasion resistance for longer life
- New coating technology provides increased wear in high stress areas
- Silicone-free and latex-free for worker and product protection
- Available in a wide range of sizes to protect more workers
- Also available in vend pack

Performance Standards & Regulatory Compliance

REACH Compliant

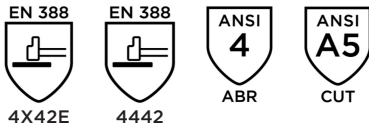

Technologies



Specifications

| BRAND STYLE | DESCRIPTION | Gauge | SIZE | LENGTH | COLOR | PACKAGE |
|----------------|---|-------|--------------------|---------------------------------|--------|--|
| HyFlex® 11-515 | Finishing: Palm Coated Coating Material: Nitrile Liner Material: Kevlar®, Spandex, Stainless steel Cuff Style: Knitwrist | 13 | 6, 7, 8, 9, 10, 11 | 235 - 270 mm; 9.01-11.53 inches | Orange | • 12 pairs in a bag, 12 bags in a carton |

For additional information visit us at www.ansell.com, or call us at

Europe, Middle East & Africa Region

Ansell Healthcare Europe NV
Riverside Business Park
Blvd International, 55
1070 Brussels, Belgium
T: +32 (0) 2 528 74 00
F: +32 (0) 2 528 74 01

North America Region

Ansell Healthcare Products LLC
111 Wood Avenue South,
Suite 210
Iselin, NJ 08830, USA
T: +1 800 800 0444
F: +1 800 800 0445

Australia

Ansell Limited
Level 3,678 Victoria Street,
Richmond, Vic, 3121
Australia
T: +61 1800 337 041
F: +61 1800 803 578

Asia Pacific Region

Ansell Global Trading Center
(Malaysia) Sdn Bhd
Prima 6, Prima Avenue
Block 3512, Jaijan Teknokrat 6
T: +603 8310 6688
F: +603 8310 6699

Latin America & Caribbean Region

Ansell Commercial Mexico S.A. de C.V.
Blvd. Bernardo Quintana No. 7001-C,
Q7001 Torre II,
Suites 1304, 1305 y 1306,
Col. Centro Sur, c.p. 76079
Queretaro, Qro. Mexico
T: +52 442 248 1544 / 248 3133

Canada

Ansell Canada
105 Lauder
Cowansville, QC J2K 2K8
Canada
T: +1 800 363 8340
F: +1 800 267 3551

Ansell, ® and ™ are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending: www.ansell.com/patentmarking © 2021 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.