



Technical data

Voltage	U	120	V
Phase		1	~
Frequency		60	Hz
Speed		1635	RPM
Power consumption	P _e	250	W
Nominal current	I	2.5	A
Maximum current	I	2.7	A
Capacitor		20/250	µF
Ambient temperature	T _{amb min/max}	-13...104	°F
Insulation Class		CL.F	
IP Class Fan		IP55	
Weight		23.6	Lbs.
Packing dimensions		22.1x22.1x12.4	inch

Fan details


Impeller blades	6
Impeller type	3
Impeller system	C
Impeller material	PP

Control options

Triac controller	Yes
Transformer	Yes
Frequency drive	No
Intelligent Fan Drive	No

Characteristics

0.00 in. wg	2943 CFM
0.20 in. wg	2531 CFM

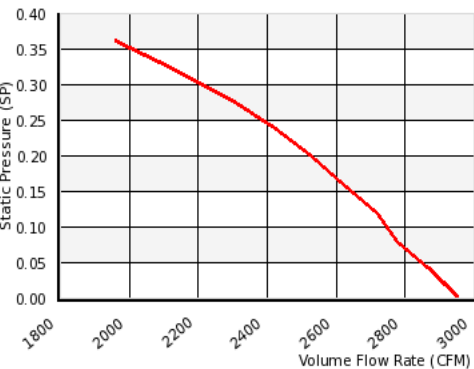


Please note: Picture may deviate from original product

Approval(s)




Wiring diagram - Fan

AA01 - 1 Phase - Standard - CCW

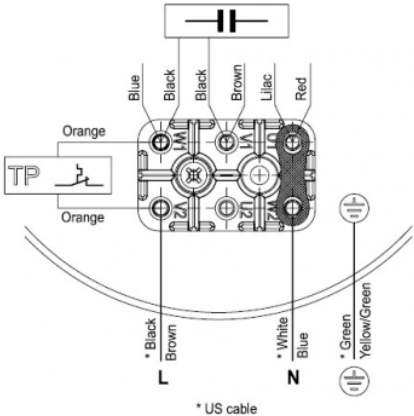

Dimensions

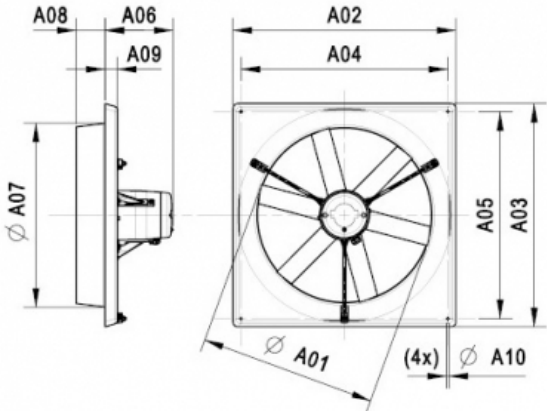

A01	16.3 inch
A02	21.4 inch
A03	21.4 inch
A04	19.5 inch
A05	19.5 inch
A06	7.6 inch
A07	17.3 inch
A08	3.3 inch
A09	1.4 inch
A10	0.3 inch