


Installation Instructions
Liquid-Tight Flexible
Non-Metallic
Conduit/Tubing Connector

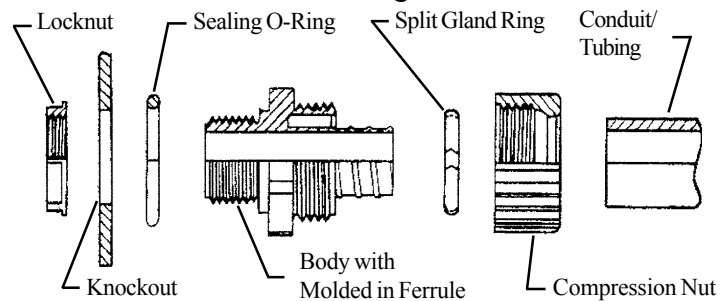

Suitable for wet locations

1. CUT CONDUIT/TUBING END SQUARE.
2. APPLY COMPRESSION NUT OVER CONDUIT/TUBING.
3. SLIP ON SPLIT GLAND RING.
4. THREADED BODY FERRULE END INTO CONDUIT/TUBING UNTIL BOTTOMED.
5. POSITION GLAND RING AGAINST BODY FERRULE CAVITY AND THREAD COMPRESSION NUT ONTO BODY.
6. **HAND TIGHTEN** TO INSURE FULL GRIPPING CAPABILITY.
7. SNAP SEALING O-RING ONTO SEAT PROVIDED FOR A LIQUID-TIGHT SEAL THROUGH ANY BOX APPLICATION.
8. SECURE WITH LOCKNUT OR INTO FEMALE THREADS AS REQUIRED.

Wiring Device-Kellems
Hubbell Incorporated (Delaware)
Shelton, CT 06484
1-800-288-6000
www.hubbell-wiring.com

PD1858 (Page 1) 06/11



Recommended Knockout Holes

Trade Size	Recommended Min. to Max.
1/2"	.859 - .906
3/4"	1.094 - 1.141
1"	1.359 - 1.406
1-1/4"	1.719 - 1.766
1-1/2"	1.969 - 2.016
2"	2.453 - 2.500