

# YellowGate

One Gate. Fits All. Stops Falls.

## Industrial Swing Gate Fall Protection



Easily adjusts from  
**16"**[406mm] wide to **36"**[914mm]



**YellowGate** 

Give us a call **1.888.663.0015**

visit us online **YellowGate.com**

YellowGate® Fall Protection

# The Most Adjustable Swing Gate Available


- Universal mount for easy installation – no additional parts to order
- Helps meet OSHA regulations
- Durable - built to last indoors and out
- In-stock and ready-to-ship



YellowGate 



16" [406mm] 36" [914mm]

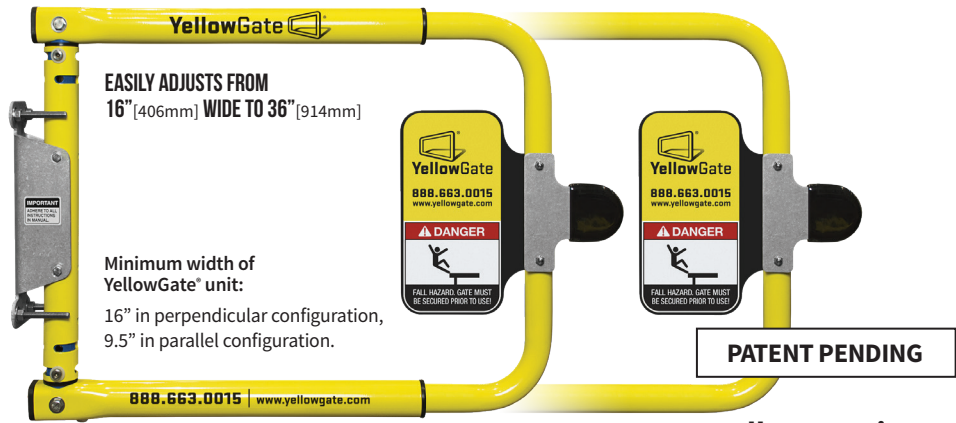


EASILY ADJUSTS FROM 16" [406mm] WIDE TO 36" [914mm]

Minimum width of YellowGate® unit:  
16" in perpendicular configuration,  
9.5" in parallel configuration.

**PATENT PENDING**

**Malbec Tensioner**  
No spring to fail.



**UNIVERSAL MOUNT** 

Order a pallet of 10 today

**YellowGate XL**

**Fork truck and Dock gates**  
Adjustable from 6 to 12' and 42" in height

Patent Pending **Malbec Tensioner**  
No spring to fail.

The Malbec Tensioner eliminates the need for a swing gate's most common failure point, the spring. The patent pending system provides field adjustable tension and maintenance free closure, every time.

YellowGate® can swing either in or out by simply relocating two bolts.

**Parallel Mounting Option**

**Perpendicular Mounting Option**