



Model BFP-9

Hose Connection Vacuum Breaker

Application

Designed for installation on water lines such as service sinks, laundry tubs and hose bibbs to protect against backsiphonage of polluted water into the potable water supply. A break-away set screw is included to prevent unauthorized removal. Assembly shall provide protection where a potential health hazard does not exist.

Standards Compliance

- ASSE® Listed 1011
- IAPMO® Listed
- CSA® Certified B64.2 (BFP-8F)
- cUPC® Certified B64.2 (BFP-9)

Material

Valve body Brass, ASTM B 16
 Elastomers Buna Nitrile, FDA 21, 177.2600
 Internals Stainless steel, 300 series
 Brass, ASTM B 16
 Polymers Acetal (Delrin™), NSF Listed

Features

Sizes: 3/4"
 Maximum working water pressure 125 PSI
 Maximum working water temperature 180°F
 Thread connection Hose Thread ANSI B1.20.7



BFP-9




BFP-8F

Options

- CH - with chrome finish
- with manual drain feature for freeze protection (BFP-8F)

Accessories


- Hose bibb (Model 195)

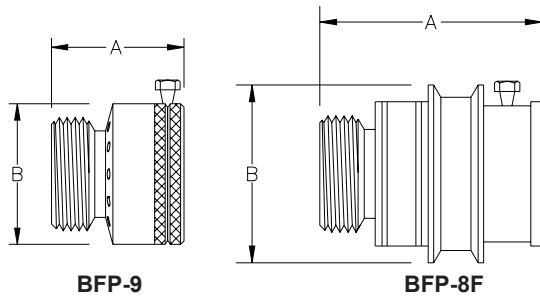


BFP-9

BFP-8F

TYPICAL INSTALLATION

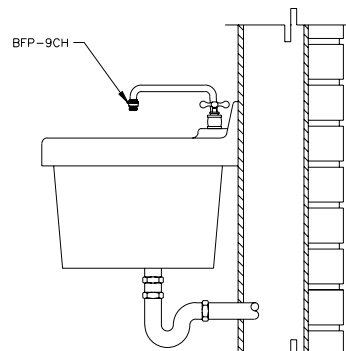

TYPICAL SERVICE SINK INSTALLATION

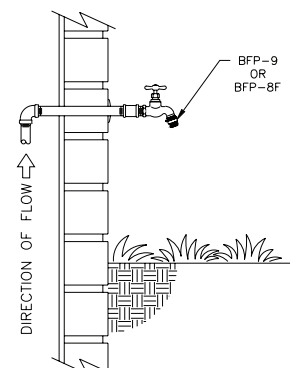

TYPICAL HOSE BIBB INSTALLATION

Dimensions & Weights (do not include pkg.)

MODEL	DIMENSIONS (approximate)				WEIGHT	
	A in.	A mm	B in.	B mm	lbs.	kg
BFP-9	1 5/16	33	1 1/4	32	0.3	0.1
BFP-8F	1 15/16	49	1 5/8	41	0.3	0.1

