

HyFlex®

ADVANCED MECHANICAL PROTECTION

11-644

Ansell Cut Protection Technology with Ergonomic Design



Cut



Medium Duty

Safety, durability and comfort combined

- HyFlex® 11-644 offers a dynamic mix of performance, durability and comfort
- The ANSI Level 2 cut performance and lightweight ergonomic fit strike the perfect balance of protection and precision when working with small, sharp parts
- The HyFlex 11-644 glove with Ansell Cut Protection Technology is an effective way to decrease injury expenses without reducing productivity or quality. That's because it combines superior cut protection, abrasion resistance, grip, tactility, and dexterity in a comfortable glove your workers are more likely to wear



Industries

- Automotive
- Machinery and Equipment
- Metal fabrication

Applications

- Press shop operations
- Handling metal sheets & panels
- Handling parts with sharp, rough edges
- Seizing structural and body parts
- Inspection (picking, checking and marking)
- Feeding the press and removing spare parts from it
- Cutting glasses, sheets, panels

Key Features

- Enhanced cut protection, wear life, and comfort with a high level of dexterity
- High dexterity with longer wear due to low palm weight and excellent abrasion resistance
- Available in a broad range of sizes to fit all workers from 5-12 (XS-XXXL)
- Also available in vend pack


Technologies



Performance Standards & Regulatory Compliance



EN 388:2003 EN 388:2016

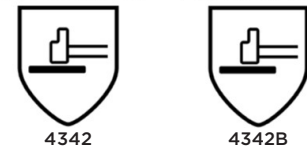

REACH Compliant

Specifications

BRAND STYLE	DESCRIPTION	Gauge	SIZE	LENGTH	COLO R	PACKAGE
HyFlex® 11-644	Palm Coated, Polyurethane, HPPE, Nylon, Spandex, Knitwrist	13	5, 6, 7, 8, 9, 10, 11, 12	207-277 mm; 8.14-10.90 inches	Grey	<ul style="list-style-type: none"> • 12 pairs in a bag; 12 bags in a carton



For additional information visit us at www.ansell.com, or call us at

Europe, Middle East & Africa Region

Ansell Healthcare Europe NV
Riverside Business Park
Blvd International, 55
1070 Brussels, Belgium
T: +32 (0) 2 528 74 00
F: +32 (0) 2 528 74 01

North America Region

Ansell Healthcare Products LLC
111 Wood Avenue South,
Suite 210
Iselin, NJ 08830, USA
T: +1 800 800 0444
F: +1 800 800 0445

Australia

Ansell Limited
Level 3,678 Victoria Street,
Richmond, Vic, 3121
Australia
T: +61 1800 337 041
F: +61 1800 803 578

Asia Pacific Region

Ansell Global Trading Center
(Malaysia) Sdn Bhd
Prima 6, Prima Avenue
Block 3512, Jalan Teknokrat 6
T: +603 8310 6688
F: +603 8310 6699

Latin America & Caribbean Region

Ansell Commercial Mexico S.A. de C.V.
Blvd. Bernardo Quintana No. 7001-C,
Q7001 Torre II,
Suites 1304, 1305 y 1306,
Col. Centro Sur, c.p. 76079
Queretaro, Qro. Mexico
T: +52 442 248 1544 / 248 3133

Canada

Ansell Canada Inc.
105, rue Lauder
Cowansville (Québec)
J2K 2K8, Canada
T: 1 800 363-8340
F: 1 888 267-3551

Ansell, ® and ™ are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending: www.ansell.com/patentmarking © 2019 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.