



MCR
SAFETY

9694

UltraTech

Dipped

Specification Sheet

PRODUCT DESCRIPTION:

UltraTech® provides Ultra comfort, Ultra fit, and Ultra protection! The seamless nylon shell offers outstanding breathability and comfort while the nitrile palm and finger coating provides grip, puncture resistance, abrasion resistance and dexterity. Great for small parts handling. The 9694 features a 15 gauge white nylon shell and gray air infused nitrile coating on the palm and fingertips.

FEATURES:

- Great tactile sensitivity
- Excellent comfort and fit
- Excellent grip
- Greater dexterity
- Abrasion resistance

APPLICATIONS:

Airport , Manufacturing, Material Handling, Janitorial , Assembly
Line Production, Automotive Assembly, Landscaping,
Electronic Assembly, Semiconductor assembly



TECHNICAL DATA FOR: 9694

Series	UltraTech
Material Group	Strings
Product Type	Dipped
Glove Size	Large
Gauge	15 Gauge
Material	Nylon

EN 388 : CE Score - Abrasion	3
EN 388 : CE Score - Cut	1
EN 388 : CE Score - Tear	3
EN 388 : CE Score - Puncture	2




MCR
SAFETY

9694

UltraTech

Dipped

Specification Sheet

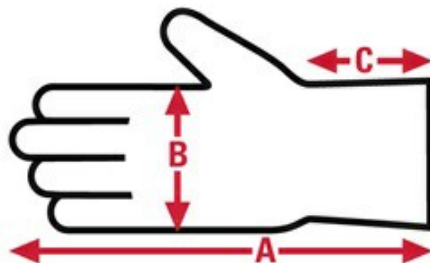

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
9694XS	X - Small	8.27	4.36	2.36	13.980 lb.	1.165
9694M	Medium	9.05	4.56	2.83	15.672 lb.	1.306
9694XL	X - Large	10.43	5.16	2.95	20.760 lb.	1.730
9694S	Small	8.86	4.44	2.56	15.216 lb.	1.268
9694L	Large	9.85	5.32	2.76	19.008 lb.	1.584

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved