



MCR
SAFETY

9784

Predaknit

Supported / Dipped gloves
Specification Sheet

PRODUCT DESCRIPTION:

The Predakni® offers you outstanding protection and comfort you will appreciate through the day. The 9784 features a full premium nitrile coating on a soft interlock liner for comfort. The 14 inch cuff ensures additional protection and the rough texture offers extra grip. Actifresh is added to help reduce odor and bacteria.

FEATURES:

- Premium Nitrile Coating
- Interlock lining
- 14 inch gauntlet cuff
- Rough finish
- CE score 3121

APPLICATIONS:

Agriculture, Construction, Farming, Fisheries, Janitorial ,
Material Handling, Petrochemical industries, Dairy, Food



TECHNICAL DATA FOR: 9784

Series	Predaknit
Material Group	Supported
Product Type	Supported / Dipped gloves
Glove Size	Large
Material	Nitrile
Grade	Industrial Grade
Lining	Interlock
Thumb Style	Straight

Overall Length	14 in.
EN 388 : CE Score - Abrasion	4
EN 388 : CE Score - Cut	1
EN 388 : CE Score - Tear	2
EN 388 : CE Score - Puncture	2

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved




MCR
SAFETY

9784

Predaknit

Supported / Dipped gloves
Specification Sheet

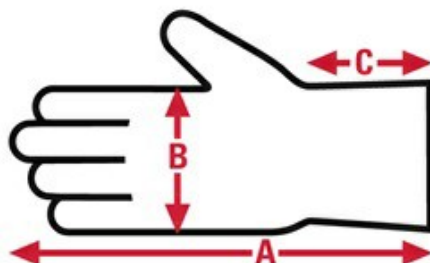

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
9784M	Medium	0	0	N/A	40.625 lb.	4.063
9784L	Large	13.780	6.339	N/A	41.680 lb.	4.168

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved