



**MCR
SAFETY**

9760K Predator

Supported / Dipped gloves Specification Sheet

PRODUCT DESCRIPTION:

The protection the Predator® gloves offer is unmatched in the market giving you the advantage over what you will face at work today. The 9760K Predator® features a premium nitrile palm and over the knuckle coating on a soft jersey liner. It also includes a Kevlar® reinforced palm with a Nitrile coated safety cuff. Actifresh is added to reduce odors.

FEATURES:

- Premium Nitrile Coating
- Soft Jersey Lining treated with Actifresh to reduce odor
- Kevlar® Reinforced Palm
- CE Score 4432
- Nitrile Coated Safety Cuff

APPLICATIONS:

Agriculture, Carpentry, Construction, Demolition, Farming, Forestry, Landscaping, Manufacturing, Lumber industry



TECHNICAL DATA FOR: 9760K

Series	Predator	Overall Length	10.5 in.
Material Group	Supported	EN 388 : CE Score - Abrasion	4
Product Type	Supported / Dipped gloves	EN 388 : CE Score - Cut	4
Glove Size	Large	EN 388 : CE Score - Tear	3
Material	Nitrile	EN 388 : CE Score - Puncture	2
Grade	Premium	ANSI Cut	ANSI Cut A3
Lining	Kevlar	ANSI Contact Heat	Level 3 (Applications less than 392 degrees F)
Thumb Style	Straight		

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com


©2018 MCR Safety - All Rights Reserved



MCR
SAFETY

9760K Predator

Supported / Dipped gloves
Specification Sheet

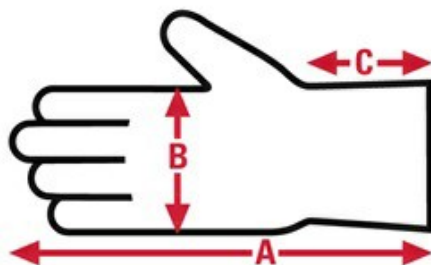

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
9760K	Large	10.630	6.457	2.500	49.596 lb.	4.133

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved