

INSULATED CUSHION GRIP SCREWDRIVERS 19 PIECE SET

wiha 

Tools that work for you

Insulation according to ASTM F-1505, VDE 0682/part 201, EN/IEC 60900, NFPA70E & CSA specifications. Individually tested to 10,000 Volts & certified to 1000 Volt AC or 1500 Volt DC. Responds to OSHA's use specification 29 CFR1910



SKU: 32095

Grainger #: 26X279



Details

- Solid Molded Core Handle Has Soft Outer Cushion Grips For Comfort, 40% More torque than Conventional Handles
- Blade Chrome-Vanadium-Molybdenum Tool Steel, Hardened For Best Wear Resistance
- Black Finish Tips, Precision Machined For Exact Fit
- Professional Quality Tools - Made By Wiha

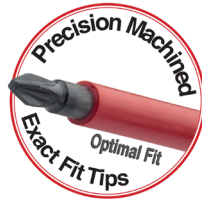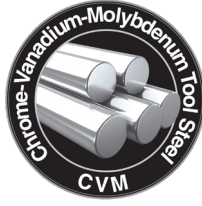

Weight (lbs)	6.4500
RoHS Compliant	Yes
Head Type	Slotted, Phillips, square Xeno Terminal Block
Pieces In Set	19
UPC	084705320953
UNSPSC	27111736

19 Piece Set Include:

Slotted

Slotted 2.5mm
Slotted 3.0mm
Slotted 3.5mm
Slotted 4.0mm
Slotted 4.5mm
Slotted 5.5mm
Slotted 6.0mm
Slotted 6.5mm
Slotted 8.0mm
Slotted 10.0mm

Phillips

Phillips #0
Phillips #1
Phillips #2
Phillips #3

Square

Square #1
Square #2

Xeno Terminal Block

Xeno #1
Xeno #2

**Cat. III
Voltage Detector**
(Battery Operated)

