



Classic vapor tight styling with modern efficiency.

LED VAPOR TIGHT - OLVT SERIES

The LED Vapor Tight is an energy-efficient solution for environments where some protection from dust and moisture and larger objects is required. Sturdy cast cage protects globe from damage. Ideal for factories, warehouses or simply to bring style to retail, hospitality and residential locations.



- 5 year limited warranty
- 50,000 - hour L70 rated life
- 4kV surge protection, standard
- Neutral 4000K Color Temp LEDs
- Rugged die cast aluminum housing
- Silicone Gaskets seals out moisture & dust
- MVOLT driver operates on any line voltage from 120-277V
- Frosted glass globe protects LEDs & ensures even light distribution
- Wall or Ceiling mount with integrated wet location junction box





RELATED PRODUCT:




LED VAPOR TIGHT OLVT SERIES



MODEL NO.	 OLVTCM	 OLVTWM
REPLACES	100-150W Incandescent	100-150W Incandescent
INPUT WATTS	15	15
DELIVERED LUMENS	600	600
LUMENS PER WATT	39	39
CRI	74	74
LIGHT COLOR (CCT)	4000K	4000K
VOLTAGE	120V - 277V	120V - 277V
WARRANTY	5 years	5 years


Iso-Illuminance Contours

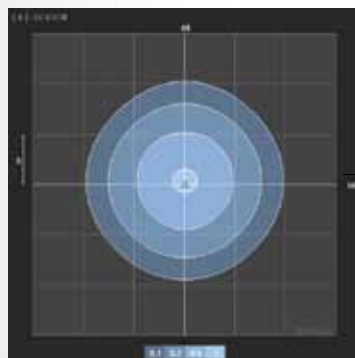

OLVTCM



OLVTWM

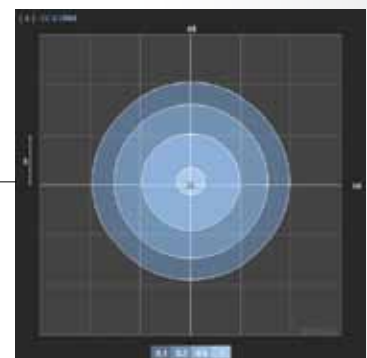

ORDERING INFO:

Example: OLVT

SERIES	COLOR TEMPERATURE	VOLTAGE	FINISH
OLVTCM OLVTWM	(blank) 4000k	(blank) MVOLT(120V-277V)	(Blank) Gray

Value and versatility defined

