

BREAK FREE from the cord



INDUSTRIAL CORDLESS METALWORKING SOLUTIONS



metabo[®]


PROFESSIONAL POWER TOOL SOLUTIONS



AMPLIFIED CORDLESS POWER

**100%
MORE
POWER***

NEW CELL TECHNOLOGY

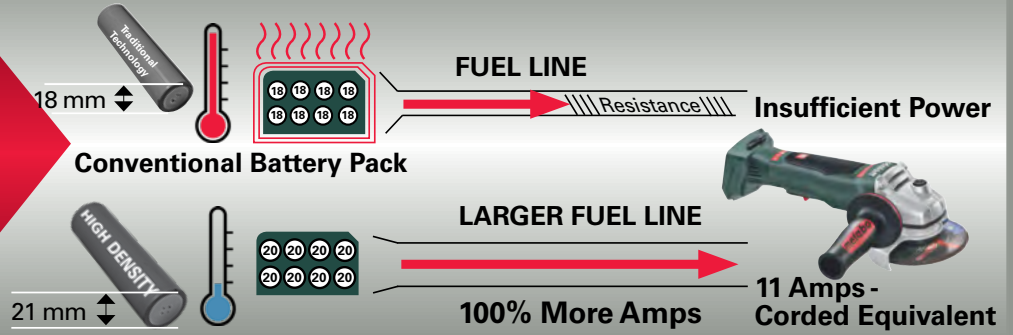

**115%
MORE
RUNTIME***

NEW BATTERY ARCHITECTURE

Air-Cooled design allows for faster charging cycles

Epoxy sealed electronics

Highest quality copper and nickel plating in connectors



Larger, higher current carrying contacts

More robust silver plated copper power rails

85+1
Power Tools Battery pack



THE ONLY CHOICE FOR CORDLESS METALWORKING!


* US Industry Standard 5.0 Li-ion

More robust silver plated copper power rails



Revolutionary LiHD high-performance cells

LiHD
TECHNOLOGY

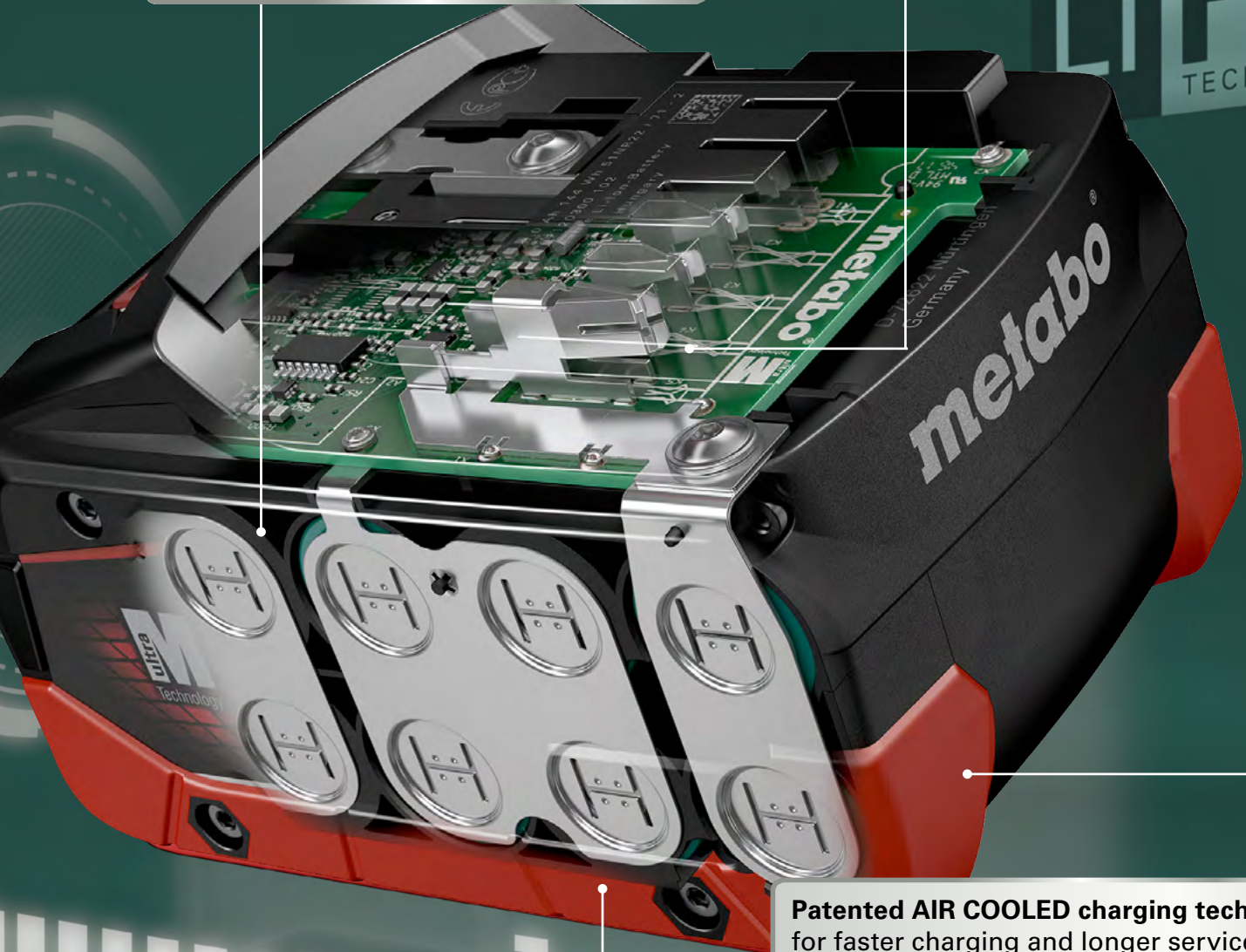

Patented AIR COOLED charging technology – for faster charging and longer service life.



100% compatibility
with all current and future
cordless machines from
Metabo.

BATTERIES

Li-Ion Power

2.0 Ah Li-Ion



48UT60

Most compact for maximum flexibility.

5.2 Li-Ion



28CP79

Generous runtime for heavy applications.



4.0 LiHD Compact



483U87

Significantly smaller and lighter than full size battery packs. Provides run-time similar to many industry standard full size 18V batteries.

5.5 Ah LiHD



45KC03

Extreme power output, run-time and performance for largest range of applications.

8.0 Ah LiHD



483U88


The ultimate professional battery for the most demanding industrial applications.

CHARGERS

ASC Multi 8

53YZ71

Air-Cooled Multi-Bay Charger

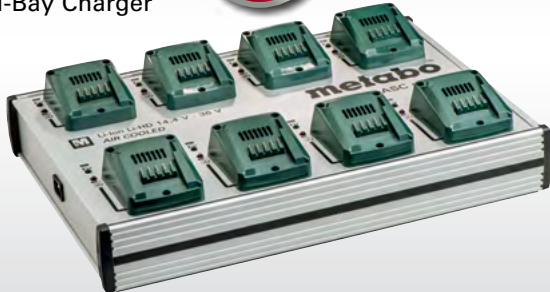

- Uninterrupted power availability
- Charges 8 batteries simultaneous
- Works with 18V and 36V batteries
- Heavy duty aluminum housing



ASC 30-36 Air-Cooled Charge

45KC05

For 18V and 36V batteries



ASC Ultra Fast Air-Cooled Charger

53YZ70

For 18V and 36V batteries
Cuts charging time in 1/2



ULTRA-M: THE MOST ADVANCED 18V BATTERY SYSTEM


Air-Cooled: The built-in fan system quickly cools a hot battery pack, reducing the overall charging time while increasing battery life.

Electronic Single Cell Protection (ESCP): Each cell evenly charges and discharges, extending the life of the battery, helping protect the motor and extending the life of the tool.



3-Year Unconditional Battery Warranty

The right BATTERY for the right APPLICATION

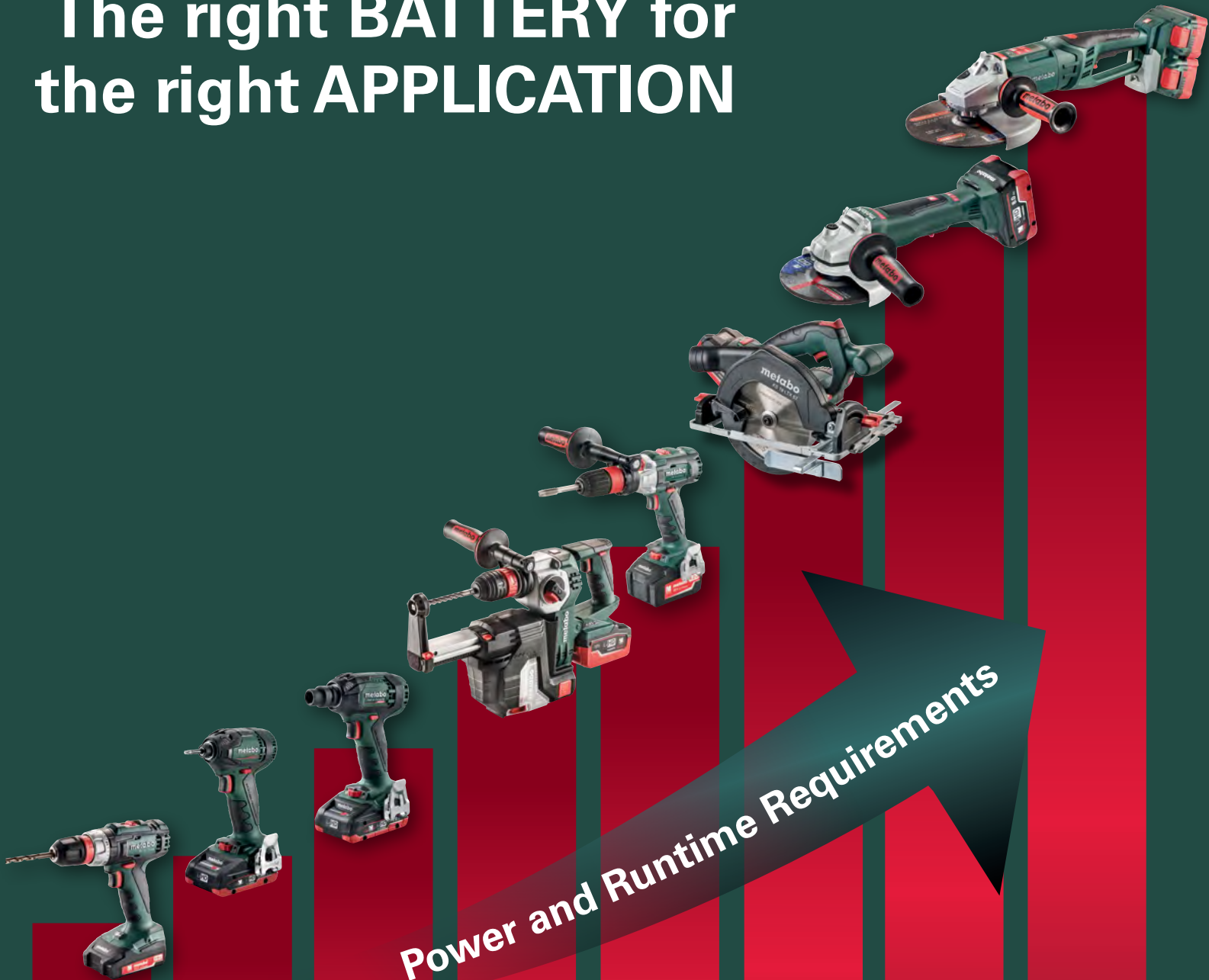

i
Li-Ion 2.0Ah Compact



i
LiHD 4.0Ah Compact



i
Li-Ion 5.2Ah



i
LiHD 8.0Ah



100% COMPATIBILITY

All battery packs are compatible with all existing and future Metabo 18V tools and chargers.



ASSEMBLY PROCESS FROM START TO FINISH

CUTTING + DRILLING



2.5" Metal Band Saw

MBS 18 LTX 2.5

53YZ44 (BARE)



Bandsaw Blades

32-7/8" x 1/2" x .020" 14TPI

#626427000*

32-7/8" x 1/2" x .020" 18TPI

#626428000*

32-7/8" x 1/2" x .020" 14/18TPI

#626429000*

**Items available through Grainger sourcing only*



4,000 RPM High-Speed Drill

BE 18 LTX 6

53YZ51 (BARE)



18V 3-Speed 1/2" Brushless Drill/Driver

BS 18 LTX-3 BL Q.I

53YZ49 (2 x 5.5 Ah)

53YZ50 (BARE)

Angle Grinders

WPB 18 LTX BL 115 (4 1/2")

45KA91 (BARE) **45KA90** (2 x 5.5 Ah)

WPB 18 TLX BL 150 (6")

45KA94 (BARE) **45KA95** (2 x 8.0 Ah)

WPB 36 LTX BL 230 (9")

53YZ43 (2 x 6.2Ah 36V)

WPB 36-18 LTX BL 230 (9")

483U67 (BARE)



Metabo Safety Clutch

Significantly reduces the risk of kick-back


Safety Brake: Quickly stops the wheel



Paddle Switch



Rotatable battery pack
Ideal for grinding and cutting applications in hard to reach areas

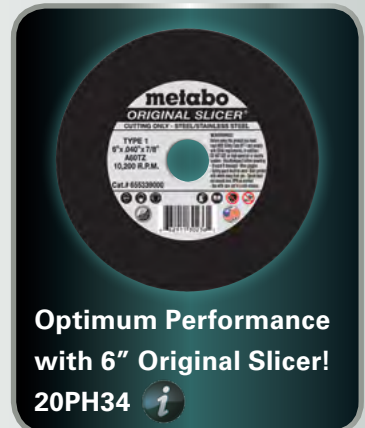

Optimum Performance with 6" Original Slicer!
20PH34



WITH METABO CORDLESS

TAPPING



2 in 1: Push pull tapping tool &

1/2" Brushless Drill/Driver

GB 18 LTX BL Q.I 483U74 (BARE)

Chucks for Tapper
1/2" Quick Change Tapping Chuck M8-M12
#627237000 *
1/2" Quick Change Tapping Chuck M4-M6 (up to 1/4")
#627235000 *

**Items available through Grainger sourcing only*

FASTENING

NEW



Brushless 1/4" Impact Driver

SSD 18 LTX 200 BL
483U85 (2 X 4.0 Ah)

483U86 (BARE)

NEW



Brushless High Torque 1/2" Impact Wrench

SSW 18 LTX 300 BL
#602395520* (2X 4.0 Ah)

#602395890* (BARE)

**Items available through Grainger sourcing only*

RIVETING

NEW



Rivet Gun

NP 18 LTX BL 5.0
483U83 (BARE)

Up to 3/16" Rivets in aluminum!





WELDING PREP AND DEBURRING



4 1/2"-5" Flat Head Paddle Switch Cordless Angle Grinder

WPF 18 LTX 125
i 45KA97 (2 X 8.0 Ah)
i 34TE48 (BARE)




Rotatable Battery Pack
 - For working in confined spaces



6" Brushless Paddle Switch Angle Grinder with Brake

WPB 18 LTX BL 150
i 45KA95 (2 X 8.0 Ah)
i 45KA94 (BARE)

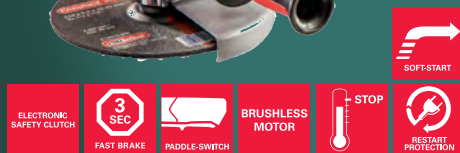

9" Cordless Angle Grinder
 WPB 36 LTX BL 230 (1 - 36V)
 53YZ43 (2 X 6.2 Ah) *i*

WPB 36-18 LTX BL 230 (2 - 18V)
 #613102840 * (BARE)



Detachable Dust Filter
 - Protects motor components from damage

Additional Cutting Guide
 - For increased precision of straight edges

Patented One-Touch Controller
 - Tool free depth adjustment
 - Unmatched precision
 - Locked in depth settings



Chamfering Radius Beveling Tool

KFM 18 LTX 3 RF
i 49EX42 (2 X 5.5 Ah)
i 49EX43 (BARE)



Optimum Performance with 9" Slicer Plus!
 #655797000 *



First cordless beveling tool for 45° chamfers up to 5/32" and radii 5/64" / 1/8"



STAINLESS STEEL PROCESSING AND FINISHING



Burnisher
S 18 LTX 115
#600154850 *(BARE)



Fillet Weld Grinder/Finisher
KNS 18 LTX 150
28CP41 (BARE)

Everything
needed to
create a #8
mirror finish!



Pipe / Tube Sander
RB 18 LTX 60
28CP42 (BARE)



Band File
BF 18 LTX 90
28CP49 (BARE)

The Right Drill for the Right Application

Quick Change Chuck with 1/4" hex bit holder

11 Electronically Controlled Clutch Settings:
 - Precise
 - Impuls mode for drilling into hard surfaces

Quick Accessories:
 - Right Angle Attachment
 - X3 Torque Multiplier
 - Lock-on Bit Holder

3-Speed Gearbox for Versatile Use:

- 3,800 RPM for fast drilling and pilot holes
- 2,050 RPM for most common applications
- 600 RPM for high torque needs

Most Powerful BL Motor
 - Up to 1,300 in. lbs. torque
 - Longest life and runtime

18V 1/2" Brushless Hammer Drill/Driver

SB 18 LTX-3 BL Q I
53YZ62 (2x 5.5Ah LiHD)

L

CLASS

HEAVY DUTY

for everyday applications



LT

CLASS

SUPER DUTY

for demanding applications



LTX

CLASS

EXTREME DUTY

with reserve power to go beyond



HEAVY DUTY

NEW



1/2" Drill/Driver
 BS 18 L Quick
483U75 (2x 2.0Ah)

Chuck: 1/2"
RPM: 0-450 / 0-1,800
Max Torque: 443 in. lbs.
BPM:

NEW



1/2" Hammer Drill/Driver
 SB 18 L
483U76 (2x 2.0Ah)

Chuck: 1/2"
RPM: 0-450 / 0-1,800
Max Torque: 443 in. lbs.
BPM: 27,000

SUPER DUTY

BRUSHLESS MOTOR



1/2" Brushless Drill/Driver
 BS 18 LT BL
53YZ46 (BARE)
53YZ45 (2x 2.0Ah)

Chuck: 1/2"
RPM: 0-600 / 0-2,100
Max Torque: 531 in. lbs.
BPM:

BRUSHLESS MOTOR



1/2" Brushless Hammer Drill/Driver
 SB 18 LT BL
53YZ59 (BARE)
53YZ58 (2x 2.0Ah)

Chuck: 1/2"
RPM: 0-600 / 0-2,100
Max Torque: 531 in. lbs.
BPM: 31,950

EXTREME DUTY

BRUSHLESS MOTOR



1/2" Brushless Drill/Driver
 BS 18 LTX BL I
53YZ48 (BARE)
53YZ47 (2x 5.2Ah)

Chuck: 1/2"
RPM: 0-500 / 0-1,850
Peak Torque: 1,300 in. lbs.
BPM:

BRUSHLESS MOTOR



1/2" Hammer Drill/Driver
 SB 18 LTX BL I
53YZ61 (BARE)
53YZ60 (2x 5.2Ah)

Chuck: 1/2"
RPM: 0-500 / 0-1,850
Peak Torque: 1,300 in. lbs.
BPM: 32,300

3 SPEED

BRUSHLESS MOTOR



1/2" Brushless Drill/Driver
 BS 18 LTX-3 BL Q I
53YZ50 (BARE)
53YZ49 (2x 5.5Ah LiHD)

Chuck: 1/2"
RPM: 0-600 / 0-2,050/0-3,800
Peak Torque: 1,300 in. lbs.

3 SPEED

BRUSHLESS MOTOR



1/2" Brushless Hammer Drill/Driver
 SB 18 LTX-3 BL Q I
53YZ63 (BARE)
53YZ62 (2x 5.5Ah LiHD)

Chuck: 1/2"
RPM: 0-600 / 0-2,050/0-3,800
Peak Torque: 1,300 in. lbs.
BPM: 32,300



Quick Change Chuck
with 1/4" hex bit holder

Brushless Motor for
quick and efficient work



Twelve speed/torque settings for
a wide range of applications

APS:
Automatic power shift for tek screws

Brushless 1/4" Impact Driver

SSD 18 LTX 200 BL
(BARE/Compact 4.0)
483U86 / 483U85

EXTREME DUTY

**Items available through Grainger sourcing only*

NEW

WITH APS

BRUSHLESS MOTOR

NEW

WITH APS

BRUSHLESS MOTOR

BRUSHLESS MOTOR

BRUSHLESS MOTOR

Brushless 1/4" Hex Impact Driver
SSD 18 LTX 200 BL
483U86 (BARE)

483U85 (2x 4.0Ah LiHD)

Drive: 1/4" hex
RPM: 0-2,900
Max Torque: 1,770 in. lbs.
Impacts/min: 4,000

Brushless 1/2" Impact Wrench
SSW 18 LTX 300 BL
#602395890 * (BARE)
#602395520 * (2x 4.0Ah LiHD)

1/2" square
0-2,650
221 ft. lbs.
3,750

Brushless High Torque
1/2" Impact Wrench
SSW 18 LTX 400 BL
34TE40 (BARE)

45KA86 (2x 4.0Ah LiHD)

45KA85 (2x 5.5Ah LiHD)

1/2" square
0-2,150
295 ft. lbs.
4,250

High Torque 1/2" Impact Wrench
SSW 18 LTX 600
34TE42 (BARE)

45KA87 (2x 5.5Ah LiHD)

1/2" square
0-1,600
450 ft. lbs.
2,200



**OSHA
COMPLIANT**

INSTALLATION IN CONCRETE



9/16" Dust Extraction Accessory
DDE 14 #630829000*

2-3/4" Dust Extraction Accessory
DDE 72 #631343000*

**Items available through Grainger sourcing only*

NEW



Cordless Vacuum
74 CFM
AS 18 LTX HEPA
483U92 (BARE)



1" SDS-Plus Combination Hammer with Dust Extraction
KHA 18 LTX BL 24 + ISA 18 LTX
483U69 (2 X 5.2 Ah)
483U70 (BARE)



Drywall Screw Gun
SE 18 LTX 2500 (2,500 RPM - High Torque)
53YZ53 (BARE)
SE 18 LTX 4000 (4,000 RPM)
53YZ54 (BARE)
SE 18 LTX 6000 (6,000 RPM - High Speed)
53YZ55 (BARE)

Dust Extraction Bits
SDS-Plus

Part#	Dia.	Length	Working Length
676301000*	7/16"	13"	7 7/8"
676302000*	1/2"	13"	7 7/8"
676303000*	9/16"	14"	9 1/2"
676304000*	5/8"	14"	9 1/2"
676305000*	3/4"	14"	9 1/2"

**Items available through Grainger sourcing only*



1-1/4" SDS-Plus Combination Hammer
KHA 36 LTX
483U77 (BARE)
19YL84 (2x 5.2 Ah 36V)

Screwdriver Magazine
SM 5-55
53YZ78



1-1/4" SDS-Plus Combination Hammer
KHA 36-18 LTX
483U68 (BARE)



INSTALLATION IN WOOD

LIGHTS / TRIPODS



18V LED Site Light

BSA 14.4-18
28CP53 (BARE)
34TE49 (1 x 5.2Ah)



18V LED Site Light

BSA 14.4-18 Industrial
53YZ64 (BARE)
(includes lens diffuser
and mounting - magnetic)



BSA Tripod

53YZ80



18V LED Flashlight

ULA 14.4-18
48UT49 (BARE)



Swivels 180°



18V LED Work Light

SLA 14.4-18 LED
48UT50 (BARE)



Construction Tripod

#628791000 *



**USB, Charger
and Adaptor**

PA 14.4-18 LED-USB
48UT59 (BARE)

*Items available through
Grainger sourcing only



NEW



Jig Saw (bow-handle grip)

STAB 18 LTX 100
483U73 (BARE)



Jig Saw (barrel grip)

STA 18 LTX 100
483U72 (BARE)



NEW

18V 6.5\"/>

KSA 18 LTX 57
483U71 (BARE)

Up to 2-1/4\"/>



Compact Reciprocating Saw

SSE 18 LTX Compact
483U79 (BARE)

Metabo Cordless Tool Program

A BATTERY FOR YOUR EVERY NEED
(tools are 18V unless indicated)

	Description	Model No.	BARE Grainger P/N	Kit Grainger P/N
Drill/Drivers	1/2" Drill/Driver (Quick chuck, 450/1,800RPM, 443in.lbs)	BS 18 L Quick NEW		483U75 (2x 2.0Ah)
	1/2" Brushless Drill/Driver (600/2,100RPM, 531in. lbs.)	BS 18 LT BL	53YZ46	53YZ45 (2x 2.0Ah)
	1/2" Brushless Drill/Driver (600/2,050RPM, 1,300in. lbs.)	BS 18 LTX BL I	53YZ48	53YZ47 (2x 5.2Ah)
	1/2" Brushless Drill/Driver (Quick, 600/2,050/3,800RPM, 1,300in. lbs.)	BS 18 LTX-3 BL Q I	53YZ50	53YZ49 (2x 5.5Ah LiHD)
	1/2" High Speed Drill (35 in. lbs., 4,000 RPM)	BE 18 LTX 6	53YZ51	
Tapping & Rivet Gun	Brushless Tapping Tool & Drill/ Driver (Quick, 600/2,050RPM, 1,300in. lbs.)	GB 18 LTX BL Q I	483U74	
	Brushless Rivet Gun (3/16" in steel, 1/4" in Aluminum, 10kN force)	NP 18 LTX BL 5.0	483U83	
Hammer Drills	1/2" Hmr Drill/Driver (450/1,800RPM, 443in. lbs., 27,000BPM)	SB 18 L NEW		483U76 (2x 2.0Ah)
	1/2" Brushless Hmr Drill/Driver (600/2,100RPM, 531in. lbs., 31,950BPM)	SB 18 LT BL	53YZ59	53YZ58 (2x 2.0Ah)
	1/2" Brushless Hmr Drill/Driver (600/2,050RPM, 1,300in. lbs., 32,300BPM)	SB 18 LTX BL I	53YZ61	53YZ60 (2x 5.2Ah)
	1/2" BL Hmr Drill/Driver (Quick, 600/2,050/3,800RPM, 1,300in. lbs., 32,300BPM)	SB 18 LTX-3 BL Q I	53YZ63	53YZ62 (2x 5.5Ah LiHD)
	1/2" Impact Drill (213in. lbs., 3,000RPM, 57,000BPM)	SBE 18 LTX	600845890*	
Impact Drivers	1/4" Hex Auto-Power Shift Impact Driver (2,900RPM, 1,770in. lbs., 4,000BPM)	SSD 18 LTX 200 BL NEW	483U86	483U85 (2x 4.0Ah LiHD)
	1/2" Auto-Power Shift Impact Wrench (2,650RPM, 221ft. lbs., 3,750BPM)	SSW 18 LTX 300 BL NEW	602395890*	602395520* (2x 4.0Ah LiHD)
	1/2" Brushless High Torque Impact Wrench (2,150RPM, 295ft. lbs., 4,250BPM)	SSW 18 LTX 400 BL	34TE40	45KA86 (2x 4.0Ah LiHD) 45KA85 (2x 5.5Ah LiHD)
	1/2" Ultra High Torque Impact Wrench (1,600RPM, 450ft. lbs., 2,200BPM)	SSW 18 LTX 600	34TE42	45KA87 (2x 5.5Ah LiHD)
Drywall Guns	Drywall Screw gun (2,500RPM, High Torque)	SE 18 LTX 2500 NEW	53YZ53	
	Drywall Screw gun (4,000RPM)	SE 18 LTX 4000 NEW	53YZ54	
	Drywall Screw gun (6,000RPM, High Speed)	SE 18 LTX 6000 NEW	53YZ55	
Angle Grinders	4-1/2" Brushless Angle Grinder w/Safety Brake (9,000RPM)	WPB 18 LTX BL 115	45KA91	45KA90 (2x 5.5Ah LiHD)
	4-1/2" / 6" Brushless Angle Grinder w/Safety Brake (9,000RPM)	WPB 18 LTX BL 150	45KA94	45KA95 (2x 8.0Ah LiHD)
	5" Flat Head Paddle Switch Grinder (8,000RPM)	WPF 18 LTX 125	34TE48	45KA97 (2x 8.0Ah LiHD)
	9" 36V Brushless Angle Grinder w/Safety Brake (6,600RPM)	WPB 36 LTX BL 230		53YZ43 (2x 6.2Ah LiHD 36V)
	9" 2x18V Brushless Angle Grinder w/Safety Brake (6,600RPM)	WPB 36-18 LTX BL 230	483U67	
Die Grinders	Die Grinder w/Paddle Switch (25,000RPM)	GPA 18 LTX	34TE38	
	High Torque Die Grinder (6,000RPM)	GA 18 LTX G	28CP51	
Metal Finishing	4.5" Burnisher (3,000RPM)	S 18 LTX 115	600154850*	
	6" Fillet Weld Grinder (3,800RPM)	KNS 18 LTX 150	28CP41	
	Pipe and Tube Sander (1,812RPM)	RB 18 LTX 60	28CP42	
	Band File (1,576RPM)	BF 18 LTX 90	28CP49	
	Chamfer / Radius Tool (8,000RPM)	KFM 18 LTX 3 RF	49EX43	49EX42 (2x 5.5Ah LiHD)
Saws	2.5" Band-Saw w/Safety Brake (32-7/8" Blade)	MBS 18 LTX 2.5 NEW	53YZ44	
	6.5" Circular Saw (4,600RPM)	KS 18 LTX 57 NEW	483U71	
	Reciprocating Saw (2,700SPM)	ASE 18 LTX	38D155	
	Compact Reciprocating Saw (3,300SPM)	SSE 18 LTX Compact	483U79	
	Multi-Tool (16,000RPM)	MT 18 LTX	613021890*	
	Wood planner (16,000RPM, 3"w, 5/32"d)	HO 18 LTX 20-82 NEW	483U84	
	Jig Saw (bow-handle) (2,800SPM, 4" cut)	STAB 18 LTX 100 NEW	483U73	
	Jig Saw (barrel grip) (2,800SPM, 4" cut)	STA 18 LTX 100 NEW	483U72	
	Jig Saw (Barrel Grip) (3,000SPM, 5-9/16" cut)	STA 18 LTX 140	48UT48	
Vac	74 CFM / 120 mbar HEPA Vacuum Cleaner	AS 18 LTX HEPA NEW	483U92	
Rot. Hrms	1" SDS-Plus Combination Hammer (1,100RPM, 4,000BPM, 2.2J)	KHA 18 LTX	39RY55	
	1" SDS-Plus Combination-Hammer with Dust extraction (1,200RPM, 4,500BPM, 2.2J)	KHA 18 LTX BL 24 + ISA 18 LTX	483U70	483U69 (2x 5.2Ah)
	1-1/4" 36V SDS-Plus Combination Hmr (1,100RPM, 4,500BPM, 3.1J)	KHA 36 LTX	483U77	19YL84 (2x 5.2Ah 36V)
	1-1/4" 2x18V SDS-Plus Combination Hmr (1,100RPM, 4,500BPM, 3.1J)	KHA 36-18 LTX 32	483U68	
Caulk Gun	13oz Caulking Gun with Cartridge Adaptor	KPA 18 LTX 400	483U81	
	20oz Caulking Gun	KPA 18 LTX 600	483U82	
Mixer	760 RPM High-Torque Mixer	RW 18 LTX 120	483U80	
Misc.	Shop Fan	AV 18	45KA99	
	Shop Blower	AG 18	45KC01	

*Items available through Grainger sourcing only

Metabo Cordless Tool Program

A BATTERY FOR YOUR EVERY NEED
(tools are 18V unless indicated)

	Description	Model No.	BARE P/N	Kit - Grainger P/N
Lights	LED Flashlight, 280 Lumens	ULA 14.4-18 LED	48UT49	
	LED Work Light, 480 Lumens	SLA 14.4-18 LED	48UT50	
	LED Site Lamp, 1,200/2,600 Lumens	BSA 14.4-18 LED	28CP53	34TE49 (1x 5.2Ah)
	LED Site Lamp Industrial, 1,200/2,600 Lumens, High Vis, Magnet base	BSA 14.4-18 LED Industrial	53YZ64	



Shop Fan - AV 18 - 45KA99



Mixer - RW 18 LTX 120 - 483U80

Featured Cordless Accessories

	Description	Model No.	Grainger P/N
Chucks, Adaptors, Tool Bags, Radio	18V AM/FM Bluetooth Radio NEW	R 12-18 BT	600777520*
	USB Power Adaptor for 18V	PA 14.4-18 LED-USB, Charges 2 cell phones/1 tablet, 7 hr LED light	48UT59
	X3 attachment	Multiplies torque by 3 times for tasks that demand more power	53YZ75
	Quick change right angle adaptor LTX	For BS 18 LTX-3 BL Q I and SB 18 LTX-3 BL Q I	53YZ73
	Quick change right angle adaptor L NEW	For BS 18 L Quick	627077000*
	Quick Bit Holder	1/4 Hex locking for all quick models	53YZ72
	1/2" Quick Change Chuck LTX	For BS 18 LTX-3 BL Q I and SB 18 LTX-3 BL Q I	53YZ76
	1/2" Quick Change Chuck L NEW	For BS 18 L Quick	636608000*
	1/2" Quick Change Tapping Chuck M8-M12	For GB 18 LTX BL Q I	627237000*
	1/2" Quick Change Tapping Chuck M4-M6	For GB 18 LTX BL Q I	627235000*
	Small Tool Bag	Holds up to 2 tools	657006000*
	Large Tool Bag	Holds up to 5 tools	657007000*
Batteries and Chargers	18V 2.0Ah Compact Li-Power		48UT60
	18V 4.0Ah Compact LiHD		483U87
	18V 5.2Ah Li-Power		28CP79
	18V 5.5Ah LiHD		625368000*
	18V 8.0Ah LiHD		483U88
	36V 5.2Ah Li-Power		53YZ67
	36V 6.2Ah LiHD		53YZ66
	Charger for 18V - 36V	ASC 30-36 Charger	45KC05
Fast Charger for 18V-36V	ASC Ultra Charger, Cuts charging time in half	53YZ70	
8 Multi-Bay Charger for 18V - 36V	ASC Multi 8	53YZ71	

*Items available through Grainger sourcing only

ADAPTORS



Quick Change Right Angle Drive Adaptor L **NEW**
627077000* For BS 18 L Quick



Quick Change Right Angle Drive Adaptor LTX
[53YZ73](#)
For BS 18 LTX-3 BL Q I and SB 18 LTX-3 BL Q I



Quick Bit Holder
[53YZ72](#)
1/4 Hex locking for all quick models



1/2" Quick Change Chuck LTX
[53YZ76](#)
For BS 18 LTX-3 BL Q I and SB 18 LTX-3 BL Q I



1/2" Quick Change Chuck L **NEW**
636608000* For BS 18 L Quick



1/2" Quick Change Tapping Chuck M8-M12
627237000* For GB 18 LTX BL Q I



1/2" Quick Change Tapping Chuck M4-M6
627235000* For GB 18 LTX BL Q I

X3 TORQUE MULTIPLIER



X3 Attachment
[53YZ75](#)
Multiplies torque by 3 times for tasks that demand more power. Fits the BS 18 LTX-3 BL Q I, and SB 18 LTX-3 BL Q I

18V AM/FM Bluetooth Radio



R 12-18 BT
600777520*

NEW

TOOL BAGS



Small Tool Bag
657006000*



Large Tool Bag
657007000*

*Items available through Grainger sourcing only

85+1
Power Tools Battery pack



metabo® club

PROS DESERVE PROFESSIONAL POWER TOOLS

JOIN THE CONVERSATION!

The Metabo® Club is a community of skilled, professional tradespeople that take pride in their craft, with a deep concern for quality, performance, productivity and safety (their own and others).

The Metabo® Club is a forum to exchange ideas with similar-minded pros to improve their skills and get the job done. It is a place of knowledge sharing, passion and pride.

For more information, contact your
Grainger Representative or visit Grainger.com

SD0818B

AVAILABLE THROUGH

GRAINGER®

FOR THE ONES WHO GET IT DONE