

Product data sheet

Characteristics

2601AG2

Switch, reversing drum, 2 HP at 230 VAC single phase, 2 HP at 575 VAC polyphase, handle operated, NEMA 1 enclosure



Main

Product	Reversing Drum Switch
Enclosure Rating	NEMA 1
Horsepower	1.5 Hp 115 V AC, 1 phase 2 Hp 230 V AC, 1 phase 2 Hp 200 V AC, 3 phase 2 Hp 230 V AC, 3 phase 2 Hp 460 V AC, 3 phase 2 Hp 575 V AC, 3 phase 0.25 Hp 115 V DC 0.25 hp 230 V DC
Maximum Rated Voltage	600 V AC 250 V DC
Number of Poles	3P

Complementary

Certifications	UL Listed CSA
Electrical Connection	Screw-clamp terminals
Type	A
Width	2.68 in (68.07 mm)
Height	5.38 in (136.65 mm)
Depth	4.61 in (117.09 mm)
Product weight	1.34 lb(US) (0.61 kg)

Ordering and shipping details

Category	21116 - 2601
Discount Schedule	CP1
GTIN	785901555414
Nbr. of units in pkg.	1
Package weight(Lbs)	20.00 oz (567 g)
Returnability	Yes
Country of origin	MX

Packing Units

Unit Type of Package 1	PCE
Package 1 Height	4.69 in (11.9 cm)
Package 1 width	5.59 in (14.2 cm)
Package 1 Length	7.01 in (17.8 cm)

Offer Sustainability


California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
RECh Regulation	RECh Declaration
EU RoHS Directive	Not compliant
China RoHS Regulation	China RoHS Declaration

Contractual warranty

Warranty


18 months

Approximate Dimensions

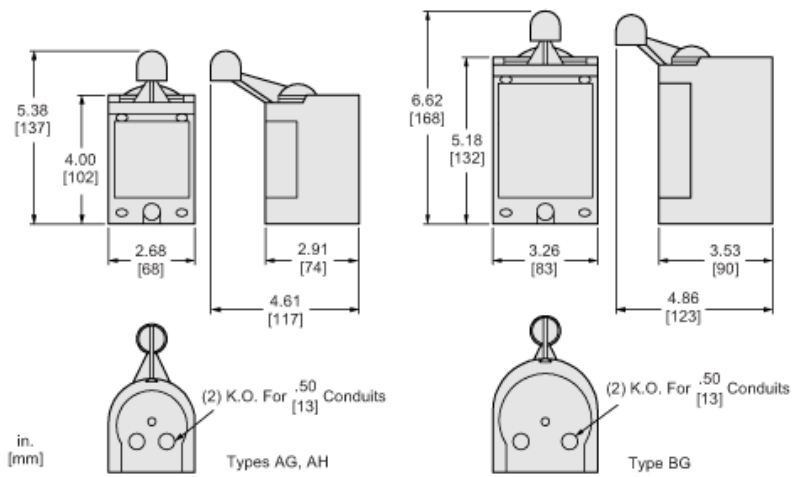

Connections and Wiring Diagrams

Internal Switching

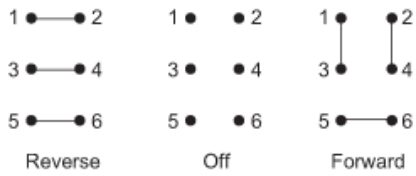

Three-Phase Wiring Diagram

