

Main

Range	Linergy
Product name	FT
Device short name	GV2G
Product or Component Type	Comb busbar
Accessory / separate part category	Connection accessory
Poles description	3P
Range compatibility	TeSys D TeSys GV2 TeSys K TeSys U
Number of tap-offs	4
[I _{th}] conventional free air thermal current	63 A
Connection pitch	2.13 in (54 mm)

Complementary

Mounting Location	On terminal
[U _i] rated insulation voltage	690 V
Length	8.11 in (206 mm)
Net Weight	0.19 lb(US) (0.085 kg)

Ordering and shipping details

Category	22367 - MANUAL STR PROTECTOR - GV2
Discount Schedule	I11
GTIN	3389110555875
Nbr. of units in pkg.	1
Package weight(Lbs)	3.10 oz (88 g)
Returnability	Yes
Country of origin	RO

Packing Units

Unit Type of Package 1	PCE
Package 1 Height	0.59 in (1.5 cm)
Package 1 width	1.57 in (4 cm)
Package 1 Length	8.27 in (21 cm)
Unit Type of Package 2	S01
Number of Units in Package 2	50
Package 2 Weight	9.96 lb(US) (4.519 kg)
Package 2 Height	5.91 in (15 cm)
Package 2 width	5.91 in (15 cm)
Package 2 Length	15.75 in (40 cm)
Unit Type of Package 3	P06
Number of Units in Package 3	1600
Package 3 Weight	345.02 lb(US) (156.5 kg)
Package 3 Height	29.53 in (75 cm)

Package 3 width	23.62 in (60 cm)
Package 3 Length	31.50 in (80 cm)


Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile

Contractual warranty

Warranty	18 months
----------	-----------

Sets of Busbars GV2G445, GV2G454, GV2G472, with Terminal Block GV2G05

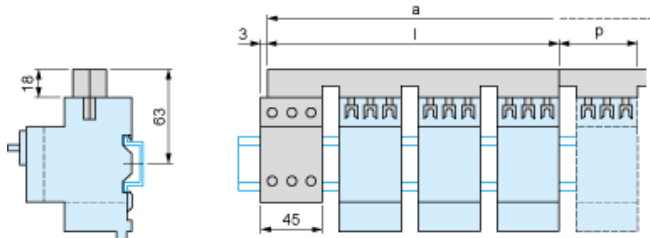

	l	p
GV2G445 (4 x 45 mm)	179	45
GV2G454 (4 x 54 mm)	206	54
GV2G472 (4 x 72 mm)	260	72

Number of tap-offs	a			
	5	6	7	8
GV2G445	224	269	314	359
GV2G454	260	314	368	422
GV2G472	332	404	476	548