



**1127-2**


**SURFACE (STRAP-ON) TYPE HYDRONIC CONTROL**

Attach Directly to Surface of Pipe. Types for Use as High Limit, Reverse Acting or SPDT Switching Action Control

**FEATURES**

- Sensing element has twice the contact area of competitive models.
- Hydraulic action element can be mounted in any position – no leveling required.
- Dustproof steel case.
- Special screw terminals with “ears” securely hold solid and stranded wires.
- Includes pipe strap and mounting screws.

**SPECIFICATIONS**

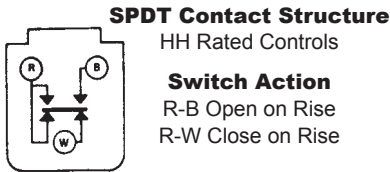

Dimensions . . . . . 6<sup>7</sup>/<sub>8</sub>”H (includes plate) x 2<sup>5</sup>/<sub>16</sub>” W x 3<sup>3</sup>/<sub>16</sub>”D  
Finish . . . . . Grey  
Agency . . . . . U.L. listed and C.S.A. approved

Model Number	Range	Differential	Switch Action	Full Electrical Rating	Motor Rating (Full Load)		Valves and Relays	
					120 VAC	240 VAC	24 VAC	0.3-12v DC
1127-2 ①	100 to 240°F (38 to 116°C)	Fixed 10°F (5.5°C)	SPDT	HH See page 222	7.4A	3.7A	2.9A	—

① Has U.L. approved adjustable dial stop, factory set at 150°F maximum.



**8A05A-101**

**RELAY / TRANSFORMER COMBINATIONS**

DPST Relay Models Enclosed with a Transformer Capable of Powering External Loads Up to 35VA. Ideal for Use on Boilers without Domestic Coil. Equally Adaptable for Zoned and Unzoned Systems

**FEATURES**

- Low voltage screw terminals — 3 color coded, end stripped line voltage leads.
- Internal transformer can power up to 35VA external loads.
- Mounts to 4” x 4” junction box.
- Dustproof steel case.

**SPECIFICATIONS**

Dimensions . . . . . 4<sup>1</sup>/<sub>4</sub>”H x 2<sup>3</sup>/<sub>4</sub>”W x 2<sup>3</sup>/<sub>4</sub>”D  
Finish . . . . . Grey  
Mounting . . . . . To 4” x 4” junction box  
Lead length . . . . . 8 inches  
Transformer . . . . . 35 VA maximum connected external load  
Agency . . . . . U.L. recognized and C.S.A. approved

Model Number	Input Voltage	Switch Action	Thermostat Current	Contact Ratings			
				Motor Rating		Valves & Relays	
				120 VAC		Terminals V1 & V2	
				Full Load	Locked Rotor	30 VAC	0.3-12v DC
8A05A-4	120 VAC, 60 Hz	DPST	0.28A	10.0A / 16.0A	60.0A / 96.0A	—	—
8A05A-101	120 VAC, 60 Hz	SPDT	0.13A	8.0A / 14.0A	48.0 / 84.0A	—	—

✻ Indicates Canadian Model Number: call 1-800-305-6953 to order

HYDRONIC / APPLIANCE