

Motorcycle Key Blank Reference

Includes Recreational Vehicles



The  to your success


A Member of the Kaba Group
www.kaba-ilco.com

About this Reference

The Ilco Motorcycle Key Blank Reference has been researched and compiled as accurately as possible. However, the historical use of locks and keys for motorcycles can be complex and unconventional in comparison to automotive keys.

Motorcycle manufacturers are known to use multiple keys, keyways, and code series in a single model year. They also “recycle” these for different model years. Therefore, it can be difficult to specify a single key blank that will be used for these models and model years.

In this reference, make, model, year and code series are provided to match the required key blanks. Where conflicting information has been found by Ilco, the information has been presented as simply as possible.

For example: X57, X58, X84 & X138 key blanks are listed for pre-84 Honda motorcycles. These keys were used for varying models, varying years. None of these key blanks were

used for every model, every year or even in one model in every year. The most consistent method of identification in this case is the code series. In some cases, the manufacturer has used the same keys and codes for several models. Those models are listed to assist in the identification process.

It is also important to note that some manufacturers have made modifications to original keys. In this case, the old key will not function for new models. However, the new key will work in both (old and new). For these models, we have substituted the new (most useful) key blank.

The body of this reference provides the Manufacturer, Model, Years, and Code Series, Ilco / Silca Key Blank number. In addition, we have included a Comments column. In this column, you will find information on the key (transponder, cloneable), application (steering lock) as well as “trim” suggestions (trim bow 0.250).

Table of Contents

Motorcycles

Manufacturer	Page No.	Manufacturer	Page No.
Aprilia	.3	Kymco	.9
Atala	.3	Laverda	.9
Beta	.3	Malaguti	.9
Bimota	.3	MBK	.9
BMW	.3	Moto Guzzi	.9
Buell	.3	MV Agusta	.9
Cagiva	.3-4	MZ	.9
Derbi	.4	Norton	.9
Ducati	.4	Peugeot	.10
Gilera	.4	Piaggio	.10
Harley-Davidson	.4	Rizzato	.10
Honda	.4-6	Suzuki	.10-12
Husqvarna	.6	Triumph	.12-13
Indian	.6	Vespa	.113
Italjet	.6	Victory	.13
Kawasaki	.6-9	Yamaha	.13-16
KTM	.9		

Recreational Vehicles

Manufacturer	Page No.	Manufacturer	Page No.
Artic Cat	.17	Kawasaki	.17-18
Bombardier	.17	KTM	.18
Can-Am	.17	Kymco	.18
Chrysler Boats	.17	Mercury Marine	.18
Clum Inboard Motors	.17	Misc. Switches	.18
Evinrude Motors	.17	Polaris	.18-19
Golf Carts	.17	Suzuki	.19
Husqvarna	.17	Yamaha	.19
Johnson Motors	.17		

We wish to thank the numerous sources that have provided assistance in preparing this reference.

This book is provided as a service and is intended for reference only. Kaba Ilco Corp. disclaims liability for any damage or action resulting from the use of this information.

Model	Years	Code Series	Ilco / Silca	Comments
APRILA				
Amico, Classic 125, Gulliver, Leonardo, Moto 6.5, Pegaso, Pegaso 3-650, Rally, RX50, SR50	1996+		ZD22RBP-SI	
Atlantic 125	1996+		ZD23RT5-SI	Cloneable Transponder Option
Atlantic 500	2003-2006		ZD23RT5-SI	Cloneable Transponder Option
Caponord, Futura	2001-2008		C300	Luggage
RVS 1000, Touno 1000R	2004+		ZD30T5-SI	Cloneable Transponder Option High Security Blade
Scarabeo 500	2003+		ZD23RT5-SI	Cloneable Transponder Option
Various Models	1996+	8001-9554	ZD16RP-SI	
			X270-TMC1	
ATALA				
Byte AT10-50, Green, Hacker AT12	1996+		ZD16RP-SI	
BETA				
Chrono, Chrono 502, Quadra, Tempo	1995+		ZD16RP-SI	
BIMOTA				
Various Models	1997+	8001-9554	ZD16RP-SI ZD22RBP-SI ZD23RCP-SI ZD24RDP-SI	
BMW				
F650	1997-1999	8001-9554	X270 - TMC1	
	2000-2007	H12353P-H53425P	X59 - BMW2	
F650 Xcountry, Xchallenge, Xmoto	2007+	8001-9554	X270 - TMC1	
K1100LS, K1100LT, R1100GS, R1100R, R1100RT	1994+		X59 - BMW2	
K1200LT	1997+	H12353P-H53425P	X59 - BMW2	
R100GS	1995-1997	011111-055555	Y16	
Various Models	2005+	HD0001-HD9999	1137B	
	1995-2005	H12353P-H53425P	X59 - BMW2	
	1997-1999	8001-9554	ZD23RCP	
	1984-1994	11111-55555	Y16	
	Pre 1984	11111-55555	N2M - SR61N	
BUELL				
Blast	2000+	8001-9554	X270 - TMC1	
Cyclone, Lightning, Thunderbolt	1995-2002	HD0001-HD9999	1137B	
Firebolt	2002+	8001-9554	X270 - TMC1	
Lightning	2003+	8001-9554	X270 - TMC1	
Ulysses	2006+	8001-9554	X270 - TMC1	
CAGIVA				
900 Elefant	1997		X259 - KW14	
City Models	1994+		ZD21P-SI	
Mito 500	2007+	B111111-B444444	X259 - KW14	
Mito Models	1994+		X259 - KW14	
River 600 Cat.	1995+		ZD16RP-SI	
Various Models	1999+	8001-9554	CG1P-SI	
			CG2RP-SI	
			X270-TMC1	
W8	1994+		HD57 or SZ4AP-SI	
W12 350	1994-1996		C300	
			ZD9P-SI	

Model	Years	Code Series	Ilco / Silca	Comments
W16	1997+		C300	
			ZD9P-SI	
DERBI				
Atlantis 1000	2003+		ZD24RDP-SI	
Boulevard 150	2003+	W0001-W9640	GT15RDT5-SI	Cloneable Transponder
Mulhacen	2006+		ZD24RDP-SI	
Predator	1999+		ZD24RDP-SI	
Various Models	1999+	8001-9554	X270 - TMC1	
DUCATI				
600 Monster, 600 S Sport, Monster S4	2001+		KW17T5-SI	Cloneable Transponder
600 Monster, 600S Monster, 900 Monster	1994-2001		X259 - KW14	
620 Monster Dark, Monster S2R, Monster S4R, ST3	2005+		KW17T5-SI	Cloneable Transponder
749, 999, 999R, 999S, 1000DS, 620 Sport, 800 Sport	2003+		KW17T5-SI	Cloneable Transponder
ST2	1997+		X259 - KW14	
ST4S	2002-2005		KW17T5-SI	Cloneable Transponder
Various Models	2001-2005		KW17T5-SI	Cloneable Transponder
	1991-2002	B1111111-B444444	X259 - KW14	
GILERA				
Atlantis 1000	2003+		ZD24RDP-SI	
Fouco, GP800, Nexus 500	2006+		SIP22T5-SI	Cloneable Transponder High Security Blade
NCR 50, Nexus, Runner	2006+		ZD24RDP-SI	
Storm 50, Typhoon, Free, Zip	1995+		ZD17RAP-SI	
HARLEY-DAVIDSON				
Sportster Models	1994+	A-S	X234 - HYD13	Will not enter some keyways
Various Models	1986-1995	000-199	X226 - HYD12	
	1996+	HD0001-HD9999	1137B	
HONDA				
CB 500, CBR 900RR	1994-1997		X84 - HD74	
CBF 500/600, CBR 900, SFX 50, SH 50/100, SJ 100 Bali EX, ST 1000	1997+	J00-U99	X265 - HD109	
		111111111-33333333		
CBR 600/1100	1999+	J00-U99 111111111-33333333	X265 - HD109	
CBR 600F/1100F, NX 650V	1999+		HON70T14-SI	Transponder Option
CBR 600F, CBR 1100F, NT 650V	1999+		HON70EHP-SI	Cloneable Transponder option Requires Ilco RW4 Plus Plus or Ilco EZ®-Clone Plus
CBR 600RR, CBR 900	2003+		HON70T14-SI	Transponder Option
CBR 600RR, CBR 900, Varadero	2003+		HON70EHP-SI	Cloneable Transponder option Requires Ilco RW4 Plus or Ilco EZ®-Clone Plus
CBR 900RR	1997-2003		X265 - HD109	
CBR 929, VFR	2000+	J00-U99	X265 - HD109	
Interceptor		111111111-33333333		
CBR 954 / 1000	2002+	J00-U99	X265 - HD109	Trim shoulder 0.197
CBR 1000, Shadow 750	2004+		HON70T14-SI	Transponder Option

Model	Years	Code Series	Ilco / Silca	Comments
CBR 1000, Shadow 750, VT 750 C4	2004+		HON70EHP-SI	Cloneable Transponder option Requires Ilco RW4 Plus or Ilco EZ®-Clone Plus
CBR 1000F	1997-1999		X265 - HD109	
CRF50/70/100/230	2003+	A00-A99, B00-B99	X84 - HD74	
		C00-C99, D00-D99	X138 - HD75	
DN-01, Silver Wing, Super Hawk, 919, ST1300, 599, Big Rukus	2001+	J00-U99	X265 - HD109	
		111111111-333333333	X265 - HD109	
Dylan 125	2004+		ZD24RDP-SI	
Elite	1984-2007	A00-A99, B00-B99	X84 - HD74	
		C00-C99, D00-D99	X138 - HD75	
Forza	2005+		X265 - HD109	
Gold Wing	2001+	5001-8442	HD110-P	
			HON58REHP-SI	Cloneable Transponder option Requires Ilco RW4 Plus or Ilco EZ®-Clone Plus
Helix	1993+	A00-A99, B00-B99	X246 - HD105	
		C00-C99, D00-D99	X252 - HD108	
Hornet	1998+		HON64BP-SI	
			HON64RBP-SI	
Lead 100	2003+		HON41-SI	
			HON41P-SI	
Magna	1983-2003	A00-A99, B00-B99	X84 - HD74	
		C00-C99, D00-D99	X138 - HD75	
Metropolitan, VTX	2002+	A00-A99, B00-B99	HON64BP-SI	
		C00-C99, D00-D99	HON64RBP-SI	
Nighthawk	1983-2008	A00-A99, B00-B99	X84 - HD74	
		C00-C99, D00-D99	X138 - HD75	
NTV 650	1997-1998		X265 - HD109	
NX 650	1997-2000		X265 - HD109	
Phanteon	2003+		ZD24RDP-SI	
PS 125i, PS 150i, SH 150i	2006+		ZD24RDP-SI	
Rebel	1985+	A00-A99, B00-B99	X84 - HD74	
		C00-C99, D00-D99	X138 - HD75	
Reflex	2001+	11111111-333333333	HON42-SI	
SFX 50	1994-1997		HON41-SI	
			HON41P-SI	
SH 125i	2005+		ZD24RDP-SI	
SH 300	2007+		ZD24RT14-SI	Transponder Option
			ZD24REHP-SI	Cloneable Transponder option Requires Ilco RW4 Plus or Ilco EZ®-Clone Plus
Shadow, XR80/ 100/650L	1983+	A00-A99, B00-B99	X84 - HD74	
		C00-C99, D00-D99	X138 - HD75	
SHI 50i	2010+	8001-9554	X270 - TMC1	
Silver Wing	2001+		HON58REHP-SI	Cloneable Transponder option Requires Ilco RW4 Plus or Ilco EZ®-Clone Plus
SJ 50 Bali	2004+		X265 - HD109	
Valkyrie	1997-2003	A00-A99, B00-B99	X84 - HD74	
		C00-C99, D00-D99	X138 - HD75	
Varadero	2003+		HON70T14-SI	Transponder Option
Various Models	1984+	A00-A99, B00-B99	X84 - HD74	
		C00-C99, D00-D99	X138 - HD75	
	1977+	101-.820	HD63	
		121-840	X138 - HD75	

Model	Years	Code Series	Ilco / Silca	Comments
Various models (con't)	1975-1976	22222-55555	X57 - HD723	
		00000-99999	X58 - HD7	
VT 750 C4	2004+		HON70T14-SI	Transponder Option
VTX 1800	2002+		HON58REHP-SI	Cloneable Transponder option Requires Ilco RW4 Plus or Ilco EZ®-Clone Plus
X 11	2001+		ZD24REHP-SI	Cloneable Transponder option Requires Ilco RW4 Plus or Ilco EZ®-Clone Plus
HUSQVARNA				
Various Models	1999+		ZD7-SI	
INDIAN				
Various Models	1999+	PK500-PK999	1041T - CG16	
ITALJET				
Dragster	1998+		ZD23RCP-SI	
Formula 50	1996+		ZD16RP-SI	
Pista, Scoop	1994+		YH34P-SI	
			YH34RP-SI	
Various Models	1996+	8001-9554	X270 - TMC1	
KAWASAKI				
305 CSR, KZ305A, KZ305B	1981-1982	A111111-A444444	KW14R	
	1987-1988	B111111-B444444	X259 - KW14	
4 Wheel	1987+		101K-175K	X254
			176K-250K	X255
			251K-325K	X256
			326K-400K	X257
650R, ER-6N, Versys, Z750S,Z1000, ZR7S, ZRX1100, ZRX1200, ZX10R, ZX12R, ZX14, ZZR1200	1999+	Z5001-Z6000	KW16CP-SI	
700 Sports, KZ700A	1984+		X41 - KA14	
1000 GP	1981+		X41 - KA14	
1100 Shaft, KZ700A	1981-1983		X41 - KA14	
Classic 1500 FI, Vulcan Drifter	2001+	B8001-B9000	KW15BP-SI	
Classic 1500, Vulcan 900	2005+	B8001-B9000	KW15BP-SI	
Classic 1600, Mean Streak, Nomad 1600, Vulcan 2000	2002+	G8001-G9000	X259 - KW14	
Concours	1986-2007		X41 - KA14	
Eliminator 125, KLR, Vulcan 500/ 800/1500	1987+	A111111-A444444	KW14R	
		B111111-B444444	X259 - KW14	
Eliminator 250/600/900	1985-1989	KZ, Z5001-Z6000	X41 - KA14	
	1996-1997			
ER-5	2003+		KW16CP-SI	
ER-6N	2009+		KW16CP-SI	
EX500	1987-1993		X41 - KA14	
GPZ 305	1983+	A111111-A444444	KW14R	
		B111111-B444444	X259 - KW14	
GPZ 500S, KLE 500	1994+		X103 - KW12	
			X41 - KA14	
			KW12BP-SI	
GPZ 550/750/1000/1100	1982-1985		X41 - KA14	
	1996-1997			

Model	Years	Code Series	Ilco / Silca	Comments
KFX 50/80/400, KLX 400	2003+	A32010-A79897	X120 - YH46	
		B32010-B79897	X119 - YH47	
		C32010-C79897	X117 - YH48	
		D32010-D79897	X118 - YH49	
KL250/600	1979-1989	A111111-A444444	KW14R	
		B111111-B444444	X259 - KW14	
KLR 600S, KLR 650	1994+		KW15BP-SI	
KLR250/650	1987-2007	A111111-A444444	KW14R	
		B111111-B444444	X259 - KW14	
KLR650	2008+		X259 - KW14	
KLX 1000	2004+		SZ14RAP-SI	
KLX110/125/140	2002+	A111111-A444444	KW14R	
		B111111-B444444	X259 - KW14	
KLX250	1994-1996	A111111-A444444	KW14R	
		B111111-B444444	X259 - KW14	
	2006-2007	A111111-A444444	KW14R	
		B111111-B444444	X259 - KW14	
	2009+	B8001-B9000	KW15BP-SI	
	KLX300	1997-2007	A111111-A444444	KW14R
B111111-B444444			X259 - KW14	
KLX 400 steering lock, Ninja ZX-12R, 6R, 7R	2003+	BA11111-BA55555	SR61N	
			KW16CP-SI	
KLX450R	2008-2009	A111111-A444444	KW14R	
		B111111-B444444	X259 - KW14	
KLX 650	1993-1996	8001-9000	X259 - KW14	
KZ200/250/400/440, LTD 250/400/440	1979-1983	A111111-A444444	KW14R	
		B111111-B444444	X259 - KW14	
KZ550/650/750/ 1000/1100/1300	1979-1984	KZ, Z5001-Z6000	X41 - KA14	
KZ1000C, KZ1000P, Police 1000	1979-2005	KZ, Z5001-Z6000	X41 - KA14	
LTD 454/550/650/ 700/750/1000/1100	1979-1990	KZ, Z5001-Z6000	X41 - KA14	
LTD 500, VN 800	1995+		KW14R-SI	
			KW14RAP-SI	
Ninja 250/500/ ZX11, GPZ 550/750/ 1000/1100, Concours, Voyager,Vulcan 700/ 750, ZL 600/1000	1979+	KZ, Z5001-Z6000	X41 - KA14	
Ninja 250R	1986-2007		X41 - KA14	
Ninja 500/500R	1994+		X41 - KA14	
Ninja 600/750	1979-1992	Z5001-Z6000	KW16CP-SI	
			ZD7-SI	
Ninja 600R	1985-1997		X41 - KA14	
Ninja 659R	2006+		KW16CP-SI	
Ninja 750R	1983-1990		X41 - KA14	
Ninja 1000R, ZL600/1000	1986-1987		X41 - KA14	
Ninja ZX-6	1993-2002		KW15BP-SI	
Ninja ZX-6, Zephyr 550/750, ZR550/750	1990-1992		X41 - KA14	
Ninja ZX-6/ZX-7/ZX-9 (except 2003+ ZX-6R)	1993+	B8001-B9000	KW15BP-SI	
Ninja ZX-6R	1995-2002		KW15BP-SI	
Ninja ZX-6R, Ninja ZX-10R, Z750S, Z1000,ZZR 1400	2004+		KW16EH2	Cloneable Transponder Requires Ilco RW4 or Ilco EZ®-Clone

Model	Years	Code Series	Ilco / Silca	Comments
Ninja ZX-7	1989-1990		X41 - KA14	
Ninja ZX-7, ZX-7R	1991-1992		X41 - KA14	
Ninja ZX-7, ZX-7R, ZX-7RR	1993-2003		KW15BP-SI	
Ninja ZX-9R	1994-2003		KW15BP-SI	
	2003+		KW16CP-SI	
Ninja ZX-10	1988-1990		X41 - KA14	
Ninja ZX-10R	2004+		KW16CP-SI	
Ninja ZX-11	1990-2001		X41 - KA14	
Ninja ZX-12R	2000-2005		KW16CP-SI	
Ninja ZX-14	2006+		KW16CP-SI	
Nomad FI	2001-2004	B8001-B9000	KW15BP-SI	
Spectre	1982-1984		X41 - KA14	
Super Sherpa	2000-2003		KW15BP-SI	
	2009+			
Tengai	1990+	A111111-A444444	KW14R	
		B111111-B444444	X259 - KW14	
Various Models	1979+	Z5001-Z6000	KW16CP-SI	
		A111111-A444444	KW14R	
		B111111-B444444	X259 - KW14	
		8001-9000	X259 - KW14	
	1991-1992	101K-400K	X254	
			X257	
1995+		X258		
1997+	G111111-L444444	X262		
VN 1600	2003+		KW14AP-SI	
Voyager	1983-2003		X41 - KA14	
Vulcan 88	1987-1995	A111111-A444444	KW14R	
		B111111-B444444	X259 - KW14	
Vulcan 500	1990-2009	A111111-A444444	KW14R	
		B111111-B444444	X259 - KW14	
Vulcan 700/750	1985-2006		X41 - KA14	
Vulcan 800	1990-2009	A111111-A444444	KW14R	
		B111111-B444444	X259 - KW14	
Vulcan 800 Drifter	2001-2006		KW15BP-SI	
Vulcan 900	2006+		KW15BP-SI	
Vulcan 1500	1996-2005	A111111-A444444	KW14R	
		B111111-B444444	X259 - KW14	
Vulcan 1500 Classic	2005-2008	B8001-B9000	KW15BP-SI	
Vulcan 1500 Classic Fi, 1500 Drifter, 1500 Nomad, 1500 Nomad Fi	2001-2005		KW15BP-SI	
Vulcan 1600	2003-2008		X259 - KW14	
Vulcan 1700	2009+		X259 - KW14	
Vulcan 2000	2004+		X259 - KW14	
Vulcan Nomad, Nomad Fi/Drifter 1500 Classic Fi	2001+	B8001-B9000	KW15BP-SI	
W650	1999-2007	Z5001-Z6000	KW16CP-SI	
Z1 Classic, Z1 R	1980+		X41 - KA14	
Z750	2004+		KW16CP-SI	
Z1000	2003+		KW16CP-SI	
ZG1400 Concours 14	2008+	A111111-A444444	KW14R	
ZL600 Eliminator	1997+		KW12BP-SI	
ZR7	1999-2003	Z5001-Z6000	KW16CP-SI	
ZR1100	1993+		X41 - KA14	
ZRX1100	1999-2000		KW16CP-SI	
ZRX1200	2001-2005		KW16CP-SI	
ZX6/9	1993+	B8001-B9000	KW15BP-SI	

Model	Years	Code Series	Ilco / Silca	Comments
ZX6R, ZX6RR, ZZR 1200	2003+	Z5001-Z6000	KW16CP-SI	
ZZR600	1994+	B8001-B9000	KW15BP-SI	
	2003-2008		KW15BP-SI	
ZZR1200	2002-2005		KW16CP-SI	
ZZR-1400	2007+		KW16EH2	Cloneable Transponder Requires Ilco RW4 or Ilco EZ® Clone
KTM				
4 Wheel, 450, 525, 530, 625-SXC	2003+		ZD7-SI	
Various Models	1996+	8001-9554	X270 - TMC1	
KYMCO				
2 Wheel	1997+		X234 - HYD13	
4 Wheel	1997+	A00-A99, B00-B99	X84 - HD74	
		C00-C99, D00-D99	X138 - HD75	
CX50,K1200, K1250, KB50, Sniper 50DD	1997+		HON31CP-SI	
Heroism	1997+		KYM1P-SI	
			KYM1RP-SI	
Various Models	1997+		KYM1P-SI	
			KYM1RP-SI	
			KYM2-SI	
			KYM2R-SI	
LAVERDA				
Phoenix	2003+		ZD21P-SI	
MALAGUTI				
Centro, SL, Crosser 50, F10 Jet, Phantom F12	1994+		ZD16RP-SI	
F15 Firefox	1996+		ZD23RCP-SI	
			ZD23RT5-SI	Cloneable Transponder Option
Madison	2003+		ZD23RCP-SI	
Various Models	1994+	8001-9554	X270 - TMC1	
MBK				
Booster	1995-1997		ZD16RP-SI	
	1997+		ZD23RT5-SI	Cloneable Transponder Option
	1998-1999		ZD24RDP-SI	
ER-5, Kilibre	2003+		ZD24RDP-SI	
Evolis, Forte, New Sorriso	1995+		ZD16RP-SI	
Ovetto	1998+		ZD24RDP-SI	Cloneable Transponder Option
			ZD23RT5-SI	
MOTO GUZZI				
350 & 750 Nevada	1994+		C300	
			ZD9P-SI	
Bellagio, Griso, Norge	2006+		ZD30T5-SI	Cloneable Transponder Option High Security Blade
Breva, California EV V11	2003+		ZD24RDP-SI	
Breva 1100, Griso 1100, Norge 1200	2006+		X234 - HYD13	
Various Models	pre 1995	E501-E710	ZD7 -SI	
	1995+	8001-9554	X270 - TMC1	
MV AUGUSTA				
Various Models	1996+	B111111-B444444	X259 - KW14	
MZ				
Various Models	1994+	8001-9554	X270 - TMC1	
NORTON				
Various Models	All	FS876-FS995	62FS	
		EJR01-EJR50	R62DM	

Model	Years	Code Series	Ilco / Silca	Comments
PEUGEOT				
Alise', Eliseo	1998+		NE74T5-SI	Cloneable Transponder
Boxy, For Lux, Speedake	1995+		ZD7-SI	
Speedfight	1997+		NE74T5-SI	Cloneable Transponder
Squab	1997+		NE74P-SI	
	1995-1997		ZD7-SI	
Various Models	1997+		NE71RDP-SI	
PIAGGIO				
BV200/250/500, Fly150, X9 500, X9 Evolution 500	2005+	W0001-W9640	GT15RDT5-SI	Cloneable Transponder
Beverly 200	2003+		GT15RDT5-SI	Cloneable Transponder
Fly 50	2005+	W0001-W9640	GT15RAP	
Free, Zip	1995+		ZD17RAP-SI	
Hexagon 125	1996+		ZD16RP-SI	
Liberty	2000+		GT15RAP	
MP3, X8, Xevo 400	2006+		SIP22T5-SI	Cloneable Transponder High Security Blade
Typhoon	2005+	8001-9554	X270 - TMC1	
Various Models	2005+	W0001-W9640	GT15RDT5-SI	Cloneable Transponder
Vespa	1996+		GT15RDT5-SI	Cloneable Transponder
RIZZATO				
Atala, Hacker AT12, Hacker Racking	1995+		ZD16RP-SI	
SUZUKI				
4 Wheel	1986-1999	B32010-B79897	X119 - YH47	
		C32010-C79897	X117 - YH48	
		D32010-D79897	X118 - YH49	
		F32010-F79897	YH51	
	2000+	2000-2149	YH34	
		2200-2349	YH33	
		2700-2848	YH33	
6700-6849	YH34			
Address 100	2004+		X179 - SUZ12	
AJ50 ZZ, AJ60ZZ, AP50	1995+		ZD16RP-SI	
AN125	1995+		X118 - YH49	
			YH29P-SI	
			YH29RP-SI	
AN125, Boulevard DR, DR 100/125/200/250/350, DR 125 SE, DR350, DR-Z, S40, S50, Intruder, Madura, Savage	1985+	C32010-C79897	X117 - YH48	
		D32010-D79897	X118 - YH49	
		E32010-E79897	YH50	
		F32010-F79897	YH51	
B-King	2008+		X241 - SUZ18	
		A6001-A7000	X276 - SUZ16	
Bandit, GSXR, Katana	1988-1995	6001-7000	X179 - SUZ12	
	1996+	A6001-A7000	X241 - SUZ18	
Boulevard C50, M50, DR 650, Gladius, GZ250, SV, TL 1000, TU250X, Versys, Volusia, V-Storm	1996+	A6001-A7000	X241 - SUZ18	
Boulevard C90, M109R, Marauder 800	1986+	BA11111-BA55555	Y16	
		CA11111-CA55555	Y16	
Boulevard C109R	2006+		X241 - SUZ18	
			N2M - SR61N	Steering Lock
Boulevard M90	2009+		X241 - SUZ18	

Model	Years	Code Series	Ilco / Silca	Comments
Boulevard M90, T90, GS 500, RF600/900, VX800	All	6001-7000	X179 - SUZ12	
Boulevard M95, Marauder 1600	2004+	G8001-G9000	X259 - KW14	
Boulevard S40, S50, S83	2005+	C32010-C79897	X117 - YH48	
		D32010-D79897	X118 - YH49	
		E32010-E79897	YH50	
		F32010-F79897	YH51	
			N2M - SR61N	
Burgman Moped	2003+	A6001-A7000	X276 - SUZ16 X241 - SUZ18	
DL1000, SV1000S, SV650, SV650S, SV750, VL800 Volusia	2003+		SZ14RAP-SI	
DR, DR-Z, Gladius	1986+		N2M - SR61N	Steering Lock
DR650	1990-1995	C32010-C79897	X117 - YH48	
		D32010-D79897	X118 - YH49	
		E32010-E79897	YH50	
		F32010-F79897	YH51	
DR650 RSE, GFS600, GS500E, GSX-R750 SP GSX-R750 W	1996+		SZ14RAP-SI X241 - SUZ18,	
GS500	1989+		X241 - SUZ18	
GSF Bandit , V-Storm 650/1000	2004-2007		SZ14RAP-SI	
GSF Bandit, V-Storm, V-Storm 650/1000	2007+		SZ17REH2-SI	Optional Equipment Cloneable Transponder Requires Ilco RW4 or Ilco EZ®-Clone
GSX 1100F Katana	1970-1993	101-499	X87 - SUZ11	
GSX Katana	1997+		ZD16RP-SI	
GSX-R1000	2003-2006		SZ14RAP-SI	
GSX-R600, GSX-R750	1997-2006		SZ14RAP-SI	
GSX1100G	1991-1993		X241 - SUZ18	
GSX600F Katana, GSX700F Katana	1988-2006		X241 - SUZ18	
GSX650F	2008+		X241 - SUZ18	
GSXR 600/750/1000	1988-2005		X241 - SUZ18	
	2006+	A6001-A7000	X276 - SUZ16	
GSXR 600/ 750/ 1000, GSX-R750	2006+		SZ17REH2-SI	Optional Equipment Cloneable Transponder Requires Ilco RW4 or Ilco EZ®-Clone
GSXR, Katana (except GSX1000F Katana), all GS500, RF600/900, VX800, Marauder 800, Intruder 1500, Boulevard C90	1988-1995	6001-7000	X179-SUZ12	
GSXR, SV, Katana, Bandit, Hayabusa, DR650, TL 1000, GZ250, Volusia, V-Storm, Boulevard C50/M50	1996+	A6001-A7000	X241 - SUZ18	
GZ250, SV650/1000	1999+		X241 - SUZ18	
Hyabusa	1996-2007	A6001-A7000	X276 - SUZ16	
	2008+		X241 - SUZ18	

Model	Years	Code Series	Ilco / Silca	Comments
Intruder 1500	All	6001-7000	X179 - SUZ12	
			X241 - SUZ18	
Intruder 700/750/800/ 1400	1986-2004	C32010-C79897	X117 - YH48	
		D32010-D79897	X118 - YH49	
		E32010-E79897	YH50	
		F32010-F79897	YH51	
Intruder, Savage, Marauder 800, Boulevard S40/S50/ S83/C90, DR steering lock	1986+	BA11111-BA55555	N2M - SR61N	
Katana R	2004+		ZD24RDP-SI	
LR GSX 600, Marauder GZ250, V-Storm 650 / 1000, GS500F, GSF Bandit, R1300, Hayabusa, Marauder LR, GSX 600, SV650, SV750	2004+		SZ14RAP	
LS650, VS 1400GPL	1995+		YH50	
			YH51	
Madura	1985-1986	C32010-C79897	X117 - YH48	
		D32010-D79897	X118 - YH49	
		E32010-E79897	YH50	
		F32010-F79897	YH51	
Marauder 800	1997-2004		X241 - SUZ18	
			N2M - SR61N	Steering Lock
Marauder 1600	2004+		X259 - KW14	
RF600R, RF900R, RG125	1995+		X179 - SUZ12	
			X241 - SUZ18	
Savage	1986-1988	C32010-C79897	X117 - YH48	
	1995-2004	D32010-D79897	X118 - YH49	
		E32010-E79897	YH50	
		F32010-F79897	YH51	
			N2M - SR61N	Steering Lock
TL 1000	1997-2003		X241 - SUZ18	
TU250X	2009+		X241 - SUZ18	
V-Storm	2002+		X241 - SUZ18	
	2003+	01-210	X226 - HYD12	Luggage
Various Models	1968-1988	101-499	X87 - SUZ11	
		RVS101-RVS499	X87 - SUZ11	
VL800 Volusia	2005+		SZ14RAP-SI	
Volusia	2001-2004		X241 - SUZ18	
VS 600GL, VS 800GL	1995+		X117 - YH48	
			X118 - YH49	
VX800	1990-1993		X241 - SUZ18	
TRIUMPH				
America	2002-2005		Y16	Steering Lock
	2006+		ZD7-SI	Steering Lock
America, Bonneville, Daytona, Rocket II, Scrambler, Speedmaster, Sprint ST, T100, Thrupton, Tiger	2006+	0001-1625	ZD7-SI	
		3001-4000	ZD24RDP-SI	
America, Bonneville, Speedmaster, T100 Truxton steering lock	2001-2005	AA11111-AA55555	Y16	
		C8001-C9000	X259 - KW14	Trim Tip

Model	Years	Code Series	Ilco / Silca	Comments
Thunderbird	1995-2000	C8001-C9000	X259 - KW14	Trim tip
Thunderbird Sport	1995-2000	8001-9554	X270 - TMC1	
Tiger	1995-1998	C8001-C9000	X259 - KW14	Trim tip
Trophy 1200	1995-2003	C8001-C9000	X259 - KW14	Trim tip
Various Models	pre 1995	FS876-FS995	62FS	
		EJR01-EJR50	R62DM	
	1995-1996	C8001-C9000	X259 - KW14	
	1997+	8001-4000	X270 - TMC1	
VESPA				
ET2 (2-stroke), LX150, LXV150	1996+	W0001-W9640	GT15RAP	
ET4, GT60 250, Granturismo 200, GT200, GTS200, GTV250, LX 150, LXV 150 various models	1996+	W0001-W9640	GT15RDT5-SI	Cloneable Transponder Optional on some models
PX150	1996+	8001-9000	X167 - YU2	
VICTORY				
Various Models	1999+	B111111-B444444	X259 - KW14	
YAMAHA				
4 Wheel	1993+	A32010-A79897	X120 - YH46	
		B32010-B79897	X119 - YH47	
		C32010-C79897	X117 - YH48	
		D32010-D79897	X118 - YH49	
Aerox, NEOS	1998+		ZD25RDP-SI ZD24RT5-SI	Cloneable Transponder Optional on some models
Axis, Breeze, Spy	1995+		ZD16RP-SI	
BT1100 Bulldog, FJR1300, FZS1000 Fazer, Majesty 400, MT-01, TDM600, T-Max600, YZF-R1, FZ1, FZ6, MT-03, XT660Z Tenere	2005+		YH35REH2-SI	Optional Equipment Cloneable Transponder Requires Ilco RW4 or Ilco EZ®-Clone
BT1100 Bulldog, Versity 300	2003-2005		ZD24RDP-SI	
C3 Moped	2007+	A7001-A8500	X248 - YM63	Trim bow 0.250
CT50 SS	1995+		YH34P-SI	
DT, FJ, FZR, GYTR, Maxim, Radian, RD, Riva, SR, TT-R50, TT-R90, TT-R125, TW, Virago, V Max, V Star 250, XV, XS, XT, YSR, YX	1984+	A32010-A79897	X120 - YH46	
		B32010-B79897	X119 - YH47	
		C32010-C79897	X117 - YH48	
		D32010-D79897	X118 - YH49	
DT50/80/100/125/175	1980-1983	A32010-A79897	X120 - YH46	
	1988-1990	B32010-B79897	X119 - YH47	
		C32010-C79897	X117 - YH48	
		D32010-D79897	X118 - YH49	
F1, FJR, FZ1, FZ6, GTS, Majesty, Morphous, R1, R6, Roadliner, Road Star, Royal Star, Seca, Stratoliner, T Max, TT-R225, TT-R250, V Star, Venture, Warrior, WR 250R, XJ, YZF	1993+	A7001-A8500	X248 - YM63	

Model	Years	Code Series	Ilco / Silca	Comments
FJ600/1100/1200	1984-1993	A32010-A79897	X120 - YH46	
		B32010-B79897	X119 - YH47	
		C32010-C79897	X117 - YH48	
		D32010-D79897	X118 - YH49	
FJR1300	2003+		X248 - YM63	
FZ1, Vino	2001+		X248 - YM63	
FZ6, XJR 1300, XJR 1300, XTR, XTX, XVS650A DragStar, XVS1000A DragStar, ZTR	2004+		YH35REH2-SI	Optional Equipment Cloneable Transponder Requires Ilco RW4 or Ilco EZ®-Clone
FZR400/600/600R/ 750R/1000	1984-1993	A32010-A79897	X120 - YH46	
		B32010-B79897	X119 - YH47	
		C32010-C79897	X117 - YH48	
		D32010-D79897	X118 - YH49	
FZR600, FZR600R, TDM850, XT600E	1995+		X248 - YM63	
GTS1000A	1993-1994		X248 - YM63	
Jog, Razz	1986-2001	A32010-A79897	X120 - YH46	
		B32010-B79897	X119 - YH47	
		C32010-C79897	X117 - YH48	
		D32010-D79897	X118 - YH49	
Luggage	2004+	CH751-CH751	M1069L	
Majesty 250, X-MAX 250	2005+		ZD24RDP-SI	
Majesty Scooter	2005+	A7001-A8500	X248 - YM63	
Maxim	1980-1986	A32010-A79897	X120 - YH46	
		B32010-B79897	X119 - YH47	
		C32010-C79897	X117 - YH48	
		D32010-D79897	X118 - YH49	
Neos	1998+		ZD24RDP-SI	
R1, R6, YZF-R1, YZF-R6, XVS1100 DragStar, V Star 650/ 950/1100/1300	1998+		X248 - YM63	
			YH35RBP-SI	
Radian, YX800	1986-1990	A32010-A79897	X120 - YH46	
		B32010-B79897	X119 - YH47	
		C32010-C79897	X117 - YH48	
		D32010-D79897	X118 - YH49	
Raider	2008+		X248 - YM63	
Rhino 450/660/700	2004+	5200-5349	X111 - YM55	
			YM56	
Riva	1983-2001	A32010-A79897	X120 - YH46	
		B32010-B79897	X119 - YH47	
		C32010-C79897	X117 - YH48	
		D32010-D79897	X118 - YH49	
Roadliner, Stratoliner	2006+		X248 - YM63	
Roadstar	1999+		X248 - YM63	
Route 66, XV250	1988-1990	A32010-A79897	X120 - YH46	
		B32010-B79897	X119 - YH47	
		C32010-C79897	X117 - YH48	
		D32010-D79897	X118 - YH49	
Royal Star, Royal Star Venture, TDM, XTZ660, XVS650 DragStar, XVC 1300, YP250 Majestic, YZF 600/1000	1996+		X248 - YM63	
RZ350	1984-1985	A32010-A79897	X120 - YH46	
		B32010-B79897	X119 - YH47	
		C32010-C79897	X117 - YH48	
		D32010-D79897	X118 - YH49	

Model	Years	Code Series	Ilco / Silca	Comments
Serca	1981-1983		X120 - YH46	
			X119 - YH47	
			X117 - YH48	
			X118 - YH49	
Serca II	1992		X120 - YH46	
			X119 - YH47	
			X117 - YH48	
			X118 - YH49	
	1993-1998		X248 - YM63	
Serow, XT225	1992-2000	A32010-A79897	X120 - YH46	
		B32010-B79897	X119 - YH47	
		C32010-C79897	X117 - YH48	
		D32010-D79897	X118 - YH49	
SR185/250/500	1980-1982	A32010-A79897	X120 - YH46	
		B32010-B79897	X119 - YH47	
		C32010-C79897	X117 - YH48	
		D32010-D79897	X118 - YH49	
T-MAX, XT 250	2009+	A7001-A8500	X248 - YM63	
TT-R	1999+		X120 - YH46	
			X119 - YH47	
			X117 - YH48	
			X118 - YH49	
			YH50	
			YH51	
TT-R 225/250	1999+		X248 - YM63	
TT350	1995+		YH35	
TW200	1987+	A32010-A79897	X120 - YH46	
		B32010-B79897	X119 - YH47	
		C32010-C79897	X117 - YH48	
		D32010-D79897	X118 - YH49	
V Star	2008+		X120 - YH46	
			X119 - YH47	
			X117 - YH48	
			X118 - YH49	
			YH50	
			YH51	
Various Models	1980+		X120 - YH46	
			X119 - YH47	
			X117 - YH48	
			X118 - YH49	
			YH50	
			YH51	
Venture, Venture Royale	1983-1993		X120 - YH46	
			X119 - YH47	
			X117 - YH48	
			X118 - YH49	
			YH50	
			YH51	
Versity 300	2003+		ZD24RDP-SI	
Vino	2001+	A code series	X277 - YM64	
		B32101-B79897	X119 - YH47	
	2008+	C or D code series	X248 - YM63	
		A or B code series	X277 - YM64	
Virago, XT, DT, TW, FZR, RD, Seca, SR, YX, XS, FJ, XV, YSR, V Max, Vina, Riva, mid 90's models, 4-wheelers, other model	1980-1983	A11111-A44444	X120 - YH46	
		B11111-B44444	X119 - YH47	
		C11111-C44444	X117 - YH48	
		D11111-D44444	X118 - YH49	
		E11111-E44444	YH50	
			F11111-F44444	YH51

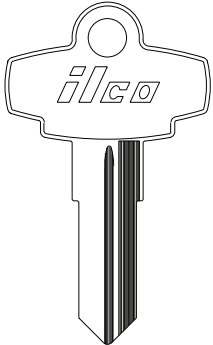

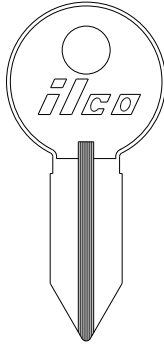

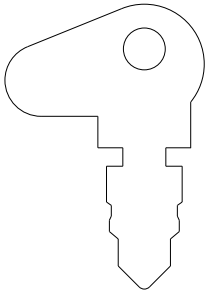
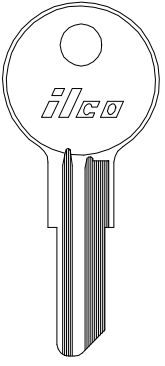

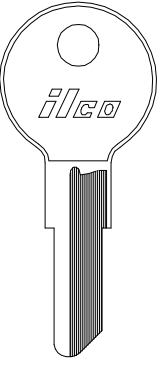

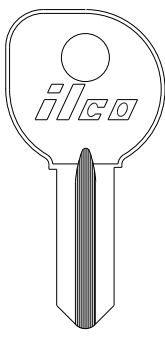



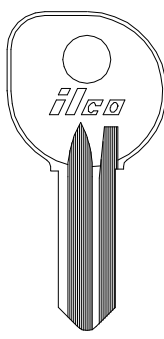

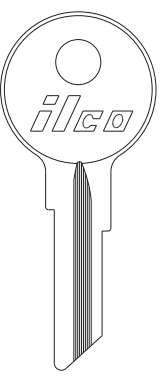

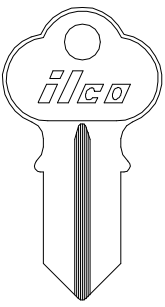

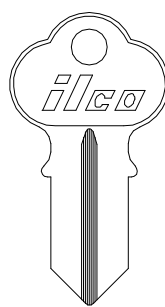



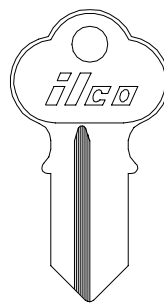

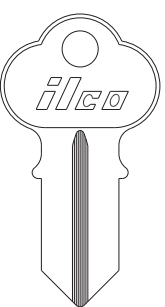

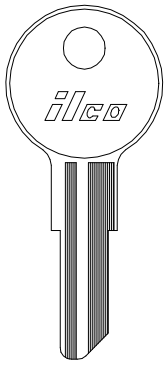

Model	Years	Code Series	Ilco / Silca	Comments
(con't)	1984+	A32010-A79897	X120 - YH46	
		B32010-B79897	X119 - YH47	
		C32010-C79897	X117 - YH48	
		D32010-D79897	X118 - YH49	
		E32010-E79897	YH50	
		F32010-F79897	YH51	
VMAX	1985-2007		X120 - YH46	
			X119 - YH47	
			X117 - YH48	
			X118 - YH49	
			YH50	
			YH51	
	2009+		X248 - YM63	
Warrior	2002-2009		X248 - YM63	
X-MAX 125	2006+		ZD24RAT22-SI	Transponder Optional
XT600E, XTZ600, XVS650, XVZ1300, YP250 Majestic, YZG1000, YZF300	1996+		X248 - YM63	
			YH35RPB-SI	
YZF-R6	2003+		YH35REH2-SI	Optional Equipment Cloneable Transponder Requires Ilco RW4 or Ilco EZ®-Clone
YZF, FZR, FZ1, FZ6, R1, R6, GTS, XJ, V Star, Road Star, Venture, Seca, F1, Warrior, TT-R Models	1993+	A7001-A8500	X248 - YM63	
Zuma	1997-2001	8001-9554	X270 - TMC1	
		1-700		
	2001+	B7001-B8000	X248 - YM63	
		8001-9554	X270 - TMC1	
	2002+	B7001-B8000	X248 - YM63	
		C7001-C8000		

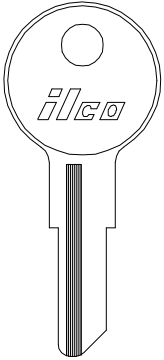
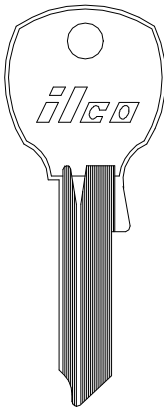
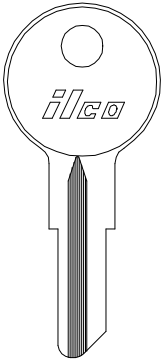
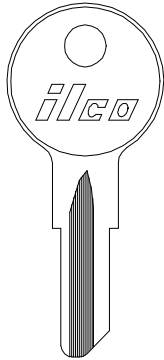
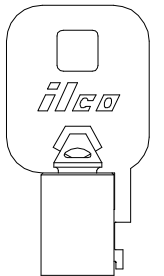

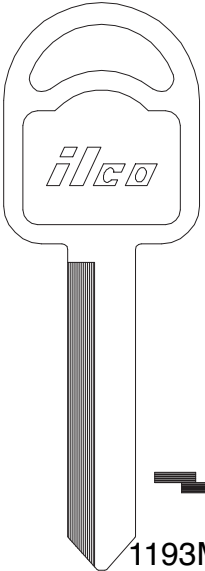
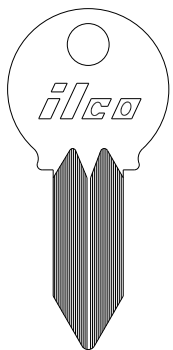


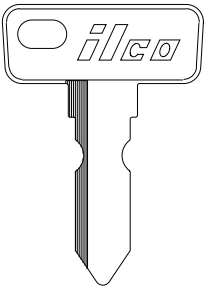

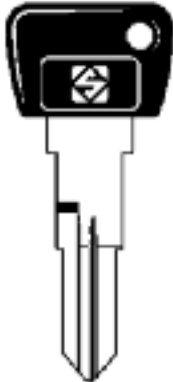
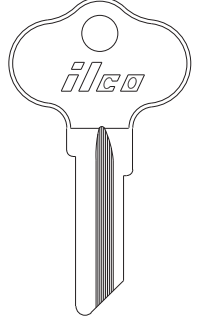
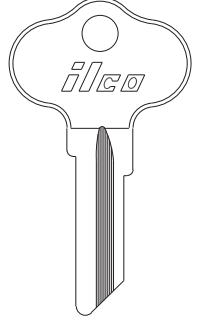
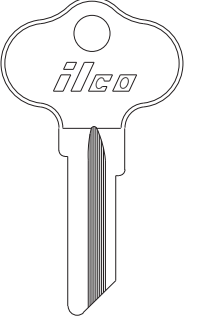
Recreational Vehicles


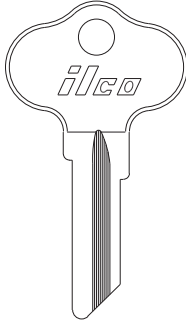
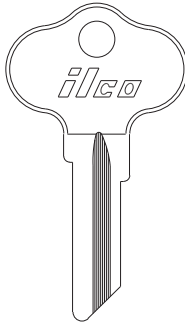
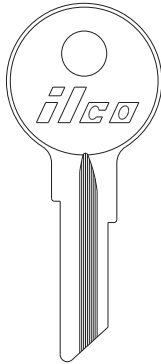
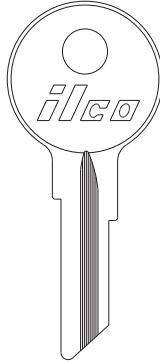
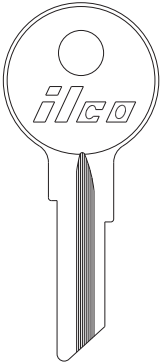
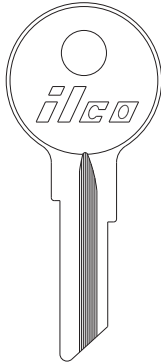
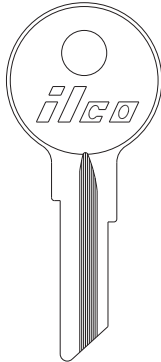

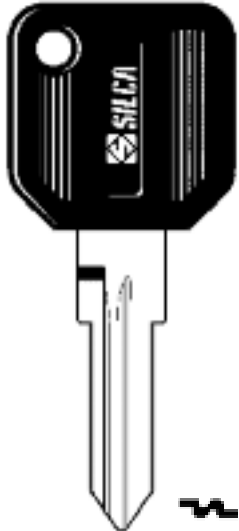

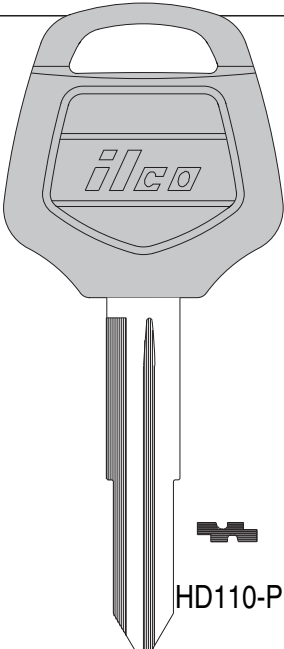
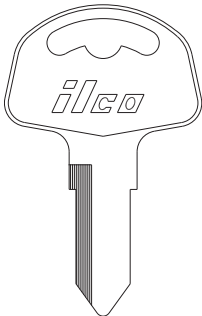
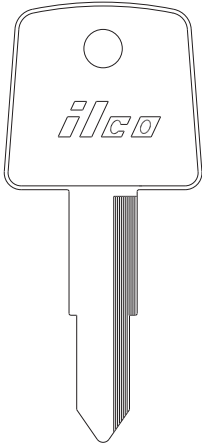
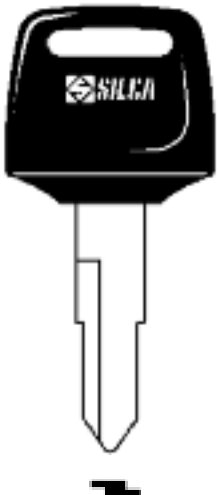
Model	Years	Code Series	Ilco / Silca	Comments
ARCTIC CAT				
Various Models	1996+		X117 - YH48	
			X118 - YH49	
Prowler	2006+		X72 - YH36	
BOMBARDIER				
Various Models	2001-2006		X120 - YH46	
			X119 - YH47	
			X117 - YH48	
			X118 - YH49	
			YH50	
			YH51	
			YM55	
			YM56	
CAN-AM				
Various Models	2007+		X120 - YH46	
			X119 - YH47	
			X117 - YH48	
			X118 - YH49	
			YH50	
			YH51	
			YM55	
			YM56	
CHRYSLER BOATS				
			CH3	
			CH4	
			CH5	
			CH6	
			CH7	
			CH8	
CLUM INBOARD MOTORS				
			1040	
			1040A	
			1040B	
			1040C	
			R1040C	
			1040E	
			R1040E	
EVINRUDE MOTORS				
			OM10	
			1041G - CG1	
			1041GA - CG2	
GOLF CARTS				
Club Car			CC1	
E-Z Go			1098L - B3	
Melex			F91G	
National Lock			1069B	Switch
Tractor			1147	
HUSQVARNA				
	1999+		ZD7-SI	
JOHNSON MOTORS				
			OM10	
			1041G - CG1	
			1041GA - CG2	
KAWASAKI				
4 Wheel	1987+	101K-175K	X254	5-Cut Keys
		176K-250K	X255	
		251K-325K	X256	
		326K-400K	X257	

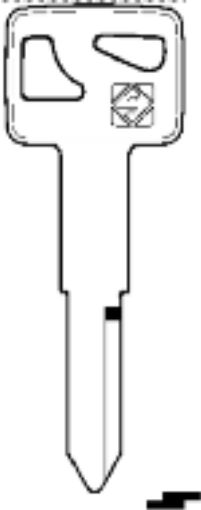

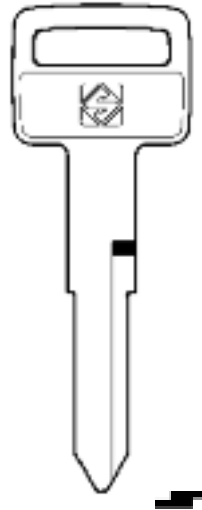
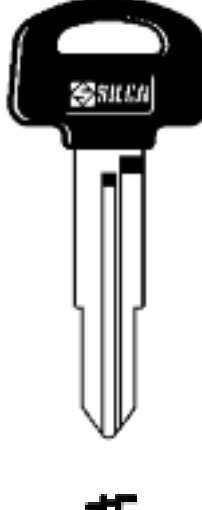
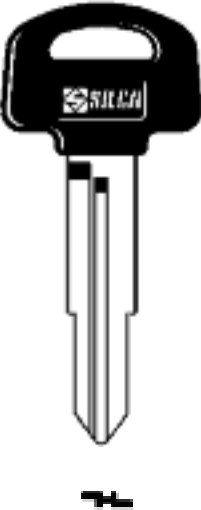
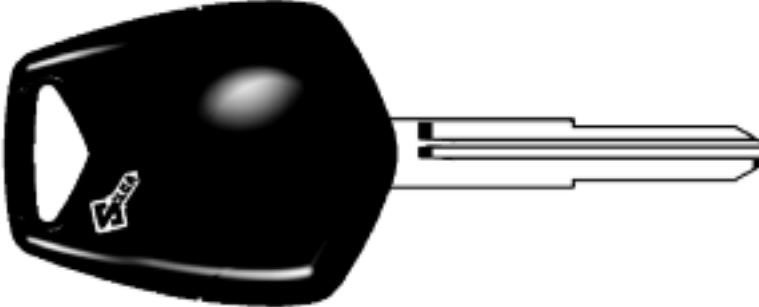

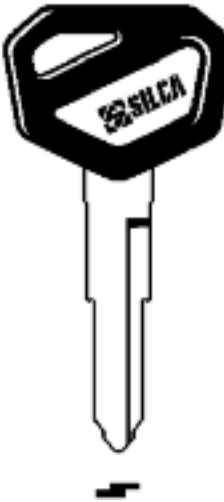

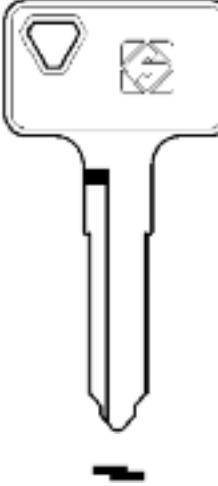
Model	Years	Code Series	Ilco / Silca	Comments				
4 Wheel (con't)	1987+	G, H, J, K, L-Series Codes	X259	6-Cut Keys				
			X260					
			X261					
KFX50 / 80 / 100	2003+	C or E Series D or F Series	X117 - YH48					
			X118 - YH49					
			YH50					
			YH51					
Mule	1988+	3101 - 3150	X120 - YH46	5-Cut Keys				
		3201 - 3250	X121 - YH47					
Various Models	1985+	Z-Series Codes	X41 - KA14					
KTM								
4 Wheel	2003+		ZD7-SI					
KYMCO								
4 Wheel	1997+	A00-A99, B00-B99 C00-C99, D00-D99	X84 - HD74					
			X138 - HD75					
			X270					
			ZD24RDP-SI					
MERCURY MARINE								
			CU7					
			CU8					
			CU9					
			CU10					
			CU12					
			1040U					
			1193M-H66					
1262A								
MISC. SWITCHES								
Briggs & Stratton			1098M - B1					
CCL			L1003M					
Illinois			1043B - IL9					
National Cabinet			1069LB - NA12					
Yale			01122 - Y11					
			01122AR - Y14					
POLARIS								
4 Wheel	1985-1999	3101 - 3150 3201 - 3250	YH26					
			YH38					
			X119 - YH47					
			YM53					
	2000+	A-Series Codes B-Series Codes C/E-Series Codes D/F-Series Codes 101K-175K 176K-250K 251K-325K 326K-400K		X120 - YH46				
				X121 - DC1				
				X117 - YH48/YH50				
				X118 - YH49/YH51				
				X120 - YH46	5-Cut Keys			
				X121 - DC1				
				X117 - YH48/YH50				
				X118 - YH49/YH51				
				G, H, J, K, L-Series Codes			X259	6-Cut Keys
							X260	
	X261							
	X262							
	YH33							
YH34								
YM55								
YM56								
Ranger	1997-2000		1041GB					
			1041GR					
			1041K					
			752					
			CH7-SI					

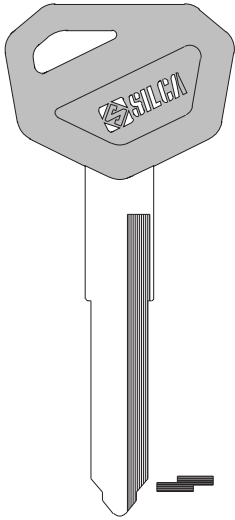

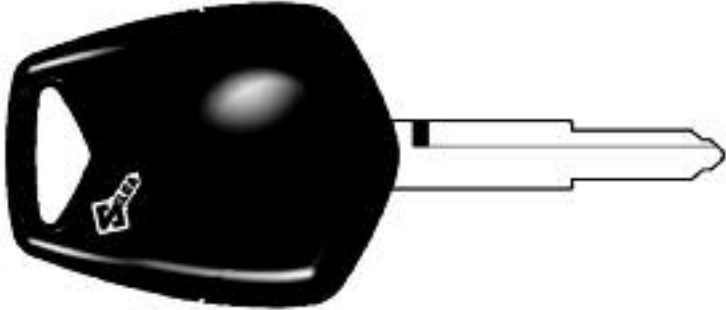



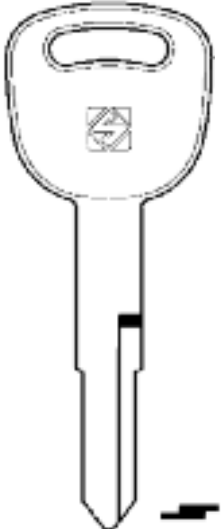
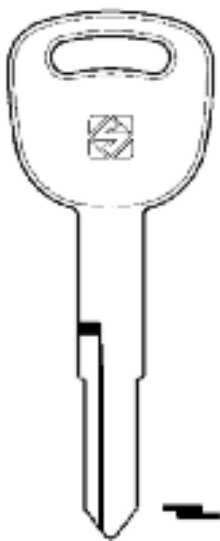
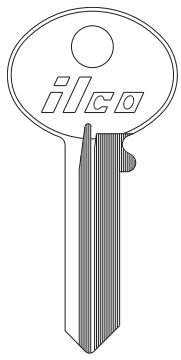
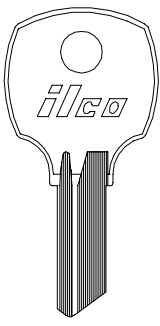
Model	Years	Code Series	Ilco / Silca	Comments
Snowmobiles	1997-2000		CH3-CH7	
SUZUKI				
4 Wheel	1986-1999	B32010-B79897	X119 - YH47	
		C32010-C79897	X117 - YH48	
		D32010-D79897	X118 - YH49	
		F32010-F79897	YH51	
	2000+	2000-2149	YH34	
		2200-2349	YH33	
		2700-2848	YH33	
		6700-6849	YH34	
YAMAHA				
4 Wheel	1980 - mid 1990's	3101 - 3150	YH38	
		3201 - 3250	X119 - YH47 YM53	
	1993+	A32010-A79897	X120 - YH46	
		B32010-B79897	X119 - YH47	
		C32010-C79897	X117 - YH48	
		D32010-D79897	X118 - YH49	

  752	  1040	 1147	  01122 - Y11	  01122AR - Y14
  1040A	  1040B	  1040C	  1040U	  1041G - CG1
  1041GA - CG2	  1041GB	  1041GR	  1041K	  1041T - CG16

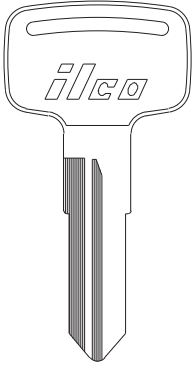
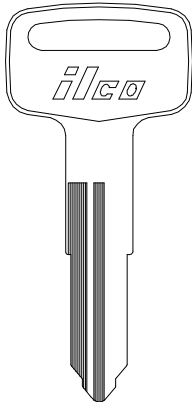
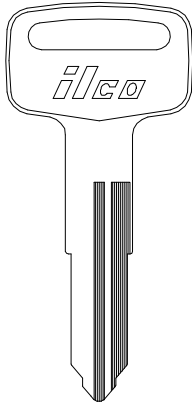
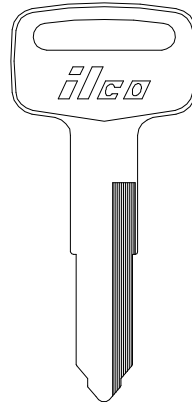
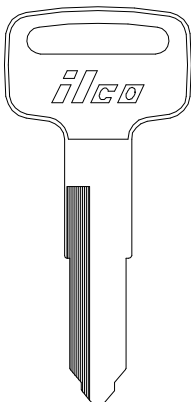
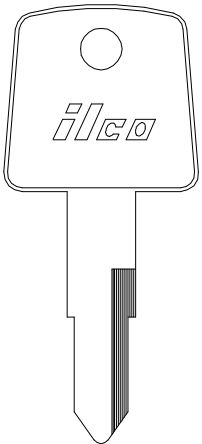
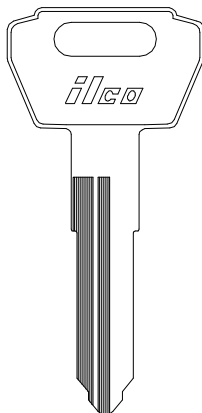
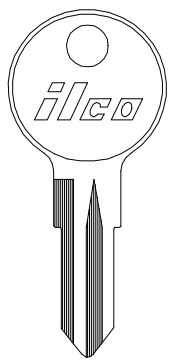
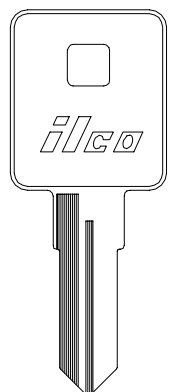
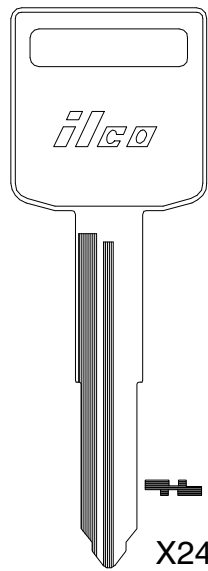
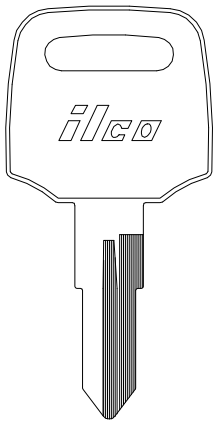
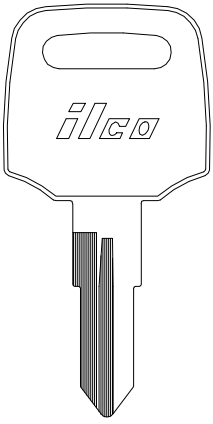
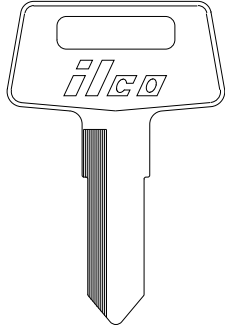
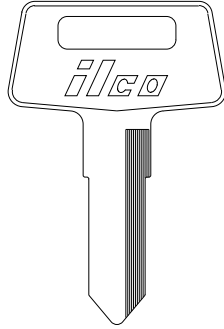
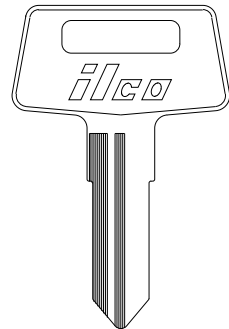
 <p>1043B - IL9</p>	 <p>1069LB - NA12</p>	 <p>1098L - B3</p>	 <p>1098M - B1</p>	  <p>1137B</p>
 <p>1193MU H66</p>	 <p>1262A</p>	 <p>62FS</p>	 <p>C300</p>	 <p>CC1</p>
 <p>CG1P-SI</p>	 <p>CG2RP-SI</p>	 <p>CH3</p>	 <p>CH4</p>	 <p>CH5</p>

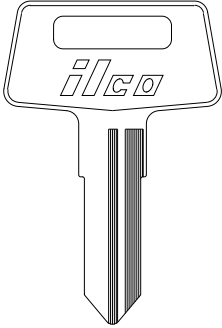

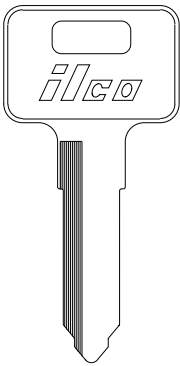
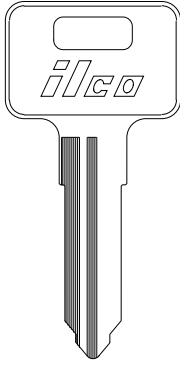
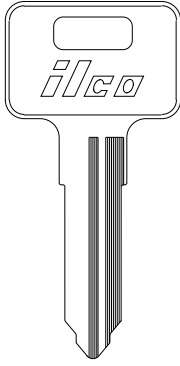
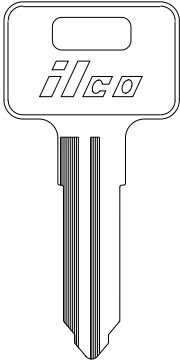
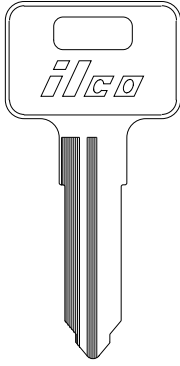

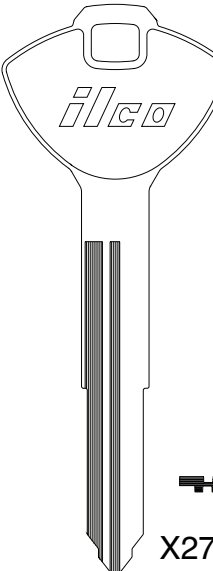
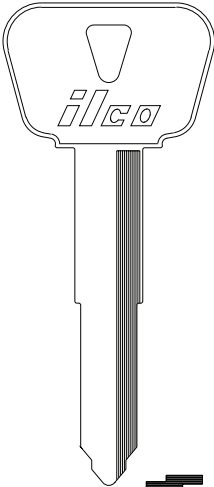
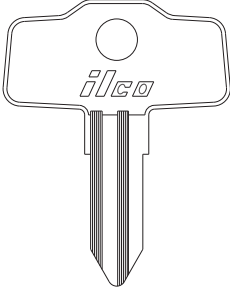

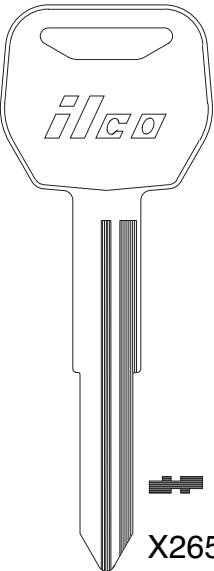
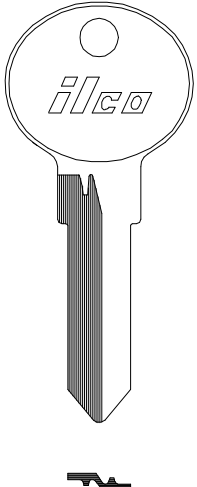
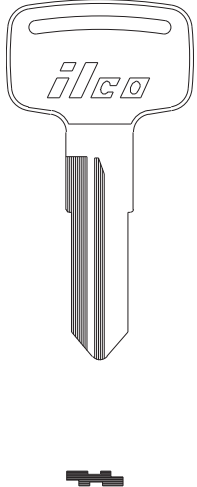
 <p>CH6</p>	 <p>CH7</p>	 <p>CH8</p>	 <p>CU7</p>	 <p>CU8</p>
 <p>CU9</p>	 <p>CU10</p>	 <p>CU12</p>	 <p>F91G</p>	 <p>GT15RAP</p>
 <p>GT15RDT5-SI</p>	 <p>HD110-P</p>	 <p>HD57</p>	 <p>HD63</p>	 <p>HON31CP-SI</p>

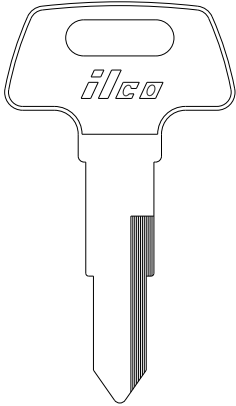
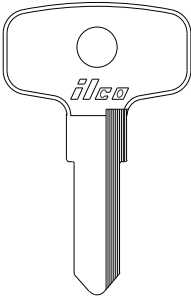
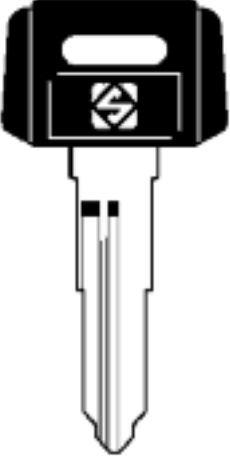
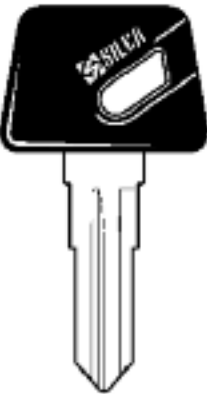
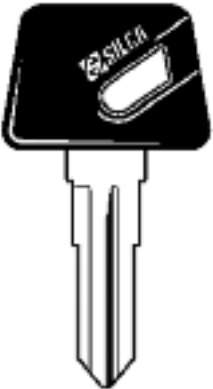
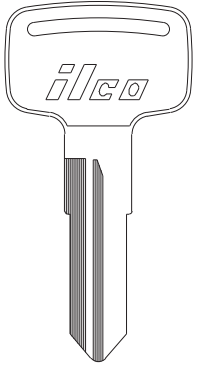
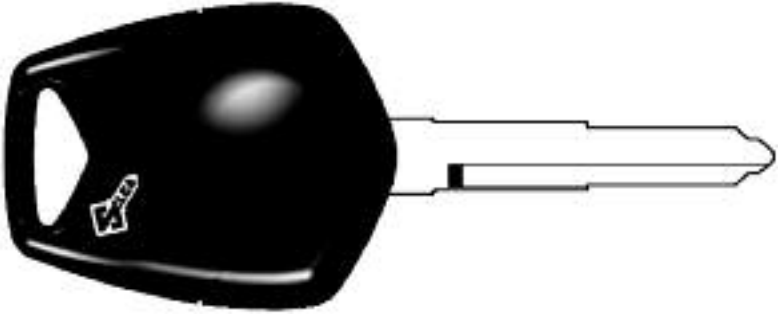
 <p>HON41-SI</p>	 <p>HON41P-SI</p>	 <p>HON42-SI</p>	<p>Image Not Available</p> <p>HON58REH-SI</p>	 <p>HON64BP-SI</p>
 <p>HON64RBP-SI</p>	 <p>HON70EHP-SI</p>			
 <p>HON70T14-SI</p>	 <p>KW12BP-SI</p>	 <p>KW14AP-SI</p>	 <p>KW14R</p>	

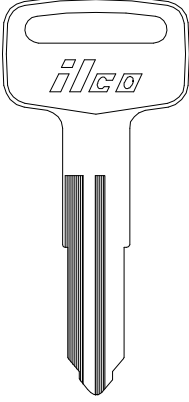
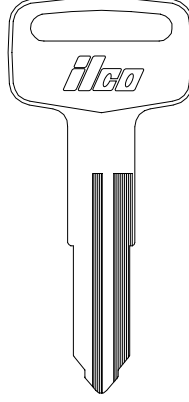
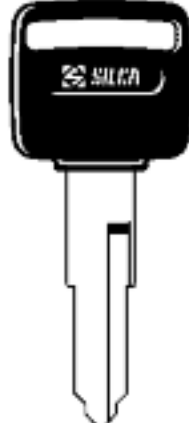


<p>Image Not Available</p>	 <p>KW15BP</p>	 <p>KW16CP-SI</p>		
 <p>KW16EH2</p>	 <p>KW17T5-SI</p>	 <p>KYM1P-SI</p>		
 <p>KYM1RP-SI</p>	 <p>KYM2-SI</p>	 <p>KYM2R-SI</p>	 <p>L1003M</p>	 <p>M1069L</p>

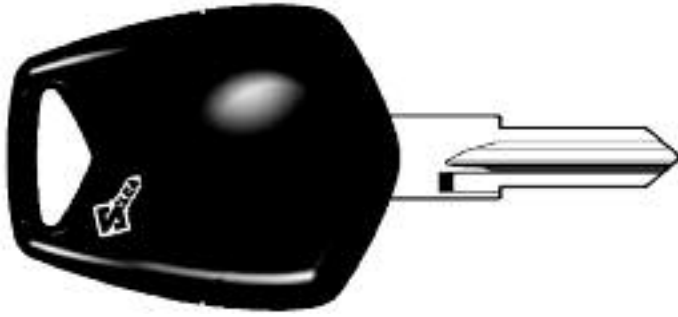
 <p>N2M - SR61N</p>	 <p>NE71RDP-SI</p>	 <p>NE74P-SI</p>	 <p>NE74T5-SI</p>	 <p>OM10</p>
 <p>R1040C</p>	 <p>R1040E</p>	 <p>R62DM</p>	 <p>SIP22T5-SI</p>	 <p>SZ14RAP-SI</p>
 <p>SZ17REH2-SI</p>		 <p>SZ4AP-SI</p>	 <p>X103 - KW12</p>	

 <p>X111 - YM55</p>	 <p>X117 - YH48</p>	 <p>X118 - YH49</p>	 <p>X119 - YH47</p>	 <p>X120 - YH46</p>
 <p>X138 - HD75</p>	 <p>X179 - SUZ12</p>	 <p>X226 - HYD12</p>	 <p>X234 - HYD13</p>	 <p>X241 - SUZ18</p>
 <p>X246 - HD105</p>	 <p>X252 - HD108</p>	 <p>X254</p>	 <p>X255</p>	 <p>X256</p>

 <p>X257</p>	 <p>X258</p>	 <p>X259 - KW14</p>	 <p>X260</p>	 <p>X261</p>
 <p>X262</p>	 <p>X265 - HD109</p>	 <p>X270 - TMC1</p>	 <p>X276 - SUZ16</p>	 <p>X277 - YM64</p>
 <p>X41 - KA14</p>	 <p>X57 - HD72</p>	 <p>X58 - HD73</p>	 <p>X59 - BMW2</p>	 <p>X72 - YH36</p>

 <p>X84 - HD74</p>	 <p>X87 - SUZ11</p>	 <p>Y16</p>	 <p>YH26</p>	 <p>YH29P-SI</p>
 <p>YH29RP-SI</p>	 <p>YH33</p>	 <p>YH34</p>	 <p>YH34P-SI</p>	 <p>YH34RP-SI</p>
 <p>YH35</p>	 <p>YH35RBP-SI</p>	 <p>YH35REH2-SI</p>		

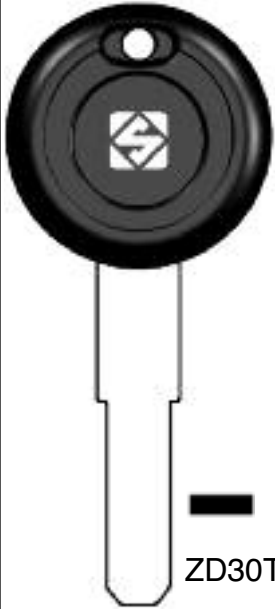
 <p>YH38</p>	 <p>YH50</p>	 <p>YH51</p>	 <p>YM55</p>	 <p>YM56</p>
 <p>X167 - YU2</p>	 <p>ZD16RP-SI</p>	 <p>ZD17RAP-SI</p>	 <p>ZD21P-SI</p>	 <p>ZD22RBP-SI</p>
 <p>ZD23RCP-SI</p>	 <p>ZD23RT5-SI</p>	 <p>ZD24RAT22-SI</p>	 <p>ZD24RDP-SI</p>	



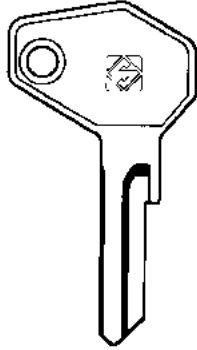
ZD24RT14-SI



ZD24RT5-SI



ZD30T5-SI



ZD7-SI



ZD9P-SI

