

Straight Blade Devices



15 and 20 Ampere, 125 Volts



15A 125V
NEMA 5-15R
UL CSA
0.5 HP




20A 125V
NEMA 5-20R
UL CSA
1 HP


Commercial Specification Grade Receptacles

Duplex	Color	Catalog Number	
Smooth polycarbonate face, duplex, back and side wired.	Black	BR15BLK	BR20BLK
	Blue	BR15BL	BR20BL
	Brown	BR15	BR20
	Gray	BR15GRY	BR20GRY
	Green	BR15GN	BR20GN
	Ivory	BR15I	BR20I
	Light Almond	BR15LA	BR20LA
	Red	BR15R	BR20R
	White	BR15WHI	BR20WHI
Tamper-Resistant, smooth polycarbonate face, duplex, back and side wired.	Black	BR15BLKTR	BR20BLKTR
	Blue	BR15BLTR	BR20BLTR
	Brown	BR15TR	BR20TR
	Gray	BR15GRYTR	BR20GRYTR
	Green	BR15GNTR	BR20GNTR
	Ivory	BR15ITR	BR20ITR
	Light Almond	BR15LATR	BR20LATR
	Red	BR15RTR	BR20RTR
	White	BR15WHITR	BR20WHITR
Weather Resistant, smooth polycarbonate face, duplex, back and side wired.	Black	BR15BLKWR	BR20BLKWR
	Brown	BR15WR	BR20WR
	Gray	BR15GRYWR	BR20GRYWR
	Ivory	BR15IWR	BR20IWR
	Light Almond	BR15LAWR	BR20LAWR
Weather and Tamper-Resistant, smooth polycarbonate face, duplex, back and side wired.	Black	BR15BLKWRTR	BR20BLKWRTR
	Brown	BR15WRTR	BR20WRTR
	Gray	BR15GRYWRTR	BR20GRYWRTR
	Ivory	BR15IWRTR	BR20IWRTR
	Light Almond	BR15LAWRTR	BR20LAWRTR
Isolated ground ^A , smooth nylon face, duplex, side wired only.	Gray	IG15CRGRY	IG20CRGRY
	Ivory	IG15CRI	IG20CRI
	Light Almond	IG15CRLA	IG20CRLA
	Orange	IG15CR	IG20CR
	White	IG15CRWHI	IG20CRWHI
Isolated ground ^A , Style Line [®] decorator*, smooth nylon face, duplex, back and side wired.	Gray	IG15DRGRY	IG20DRGRY
	Ivory	IG15DRI	IG20DRI
	Light Almond	IG15DRLA	IG20DRLA
	Orange	IG15DR	IG20DR
	White	-	IG20DRWHI


Note: ^ASee section N for additional information on isolated ground devices.
See page A-47 for accessories.
See page Tech-10 for Tamper and Weather Resistant descriptions.
See section O for wallplates.

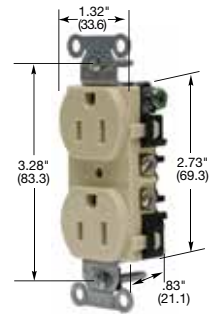


BR15I

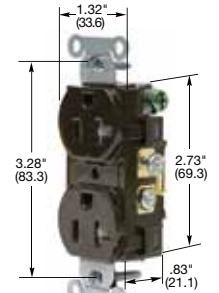


BR20TR

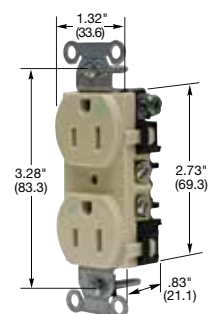

BR15IWR

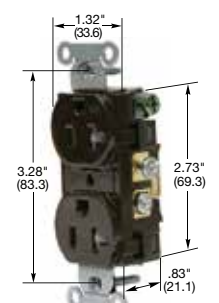

BR20WRTR

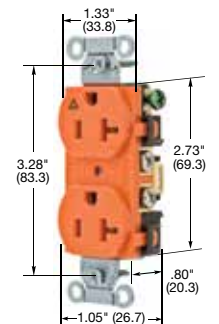

IG20CR

Dimensions in Inches (mm)