





15A 125V
NEMA 5-15R
UL CSA
0.5 HP




20A 125V
NEMA 5-20R
UL CSA
1 HP

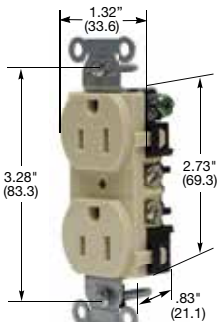


CR15I

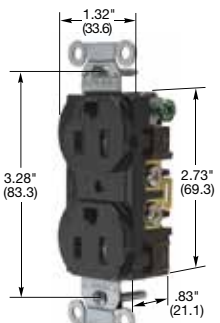

CR15TR

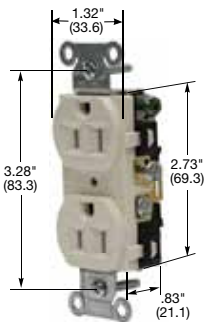

CRF15LA

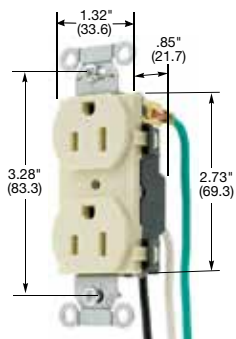

CR15IP1

Commercial Specification Grade Receptacles

Duplex

| | Color | Catalog Number | |
|--|--------------|--------------------|--------------------|
| Smooth polycarbonate face, duplex, side wired only. | Black | CR15BLK | CR20BLK |
| | Brown | CR15 | CR20 |
| | Gray | CR15GRY | CR20GRY |
| | Ivory | CR15I | CR20I |
| | Light Almond | CR15LA | CR20LA |
| | White | CR15WHI | CR20WHI |
| Tamper-Resistant, smooth polycarbonate face, duplex, side wired only. | Black | CR15BLKTR | CR20BLKTR |
| | Brown | CR15TR | CR20TR |
| | Gray | CR15GRYTR | CR20GRYTR |
| | Ivory | CR15ITR | CR20ITR |
| | Light Almond | CR15LATR | CR20LATR |
| | White | CR15WHITR | CR20WHITR |
| Finder groove, polycarbonate face, duplex, side wired only. | Black | - | CRF20BLK |
| | Brown | CRF15 | CRF20 |
| | Gray | CRF15GRY | CRF20GRY |
| | Ivory | CRF15I | CRF20I |
| | Light Almond | CRF15LA | CRF20LA |
| | White | CRF15WHI | CRF20WHI |
| Pre-wired receptacles, smooth polycarbonate face, duplex, side wired only, self-grounding, 8" solid wire leads. | Black | CR15BLKP1 | CR20BLKP1 |
| | Brown | CR15P1 | CR20P1 |
| | Gray | CR15GRYP1 | CR20GRYP1 |
| | Ivory | CR15IP1 | CR20IP1 |
| | Light Almond | CR15LAP1 | CR20LAP1 |
| | White | CR15WHIP1 | CR20WHIP1 |
| Pre-wired receptacles, smooth polycarbonate face, duplex, side wired only, self-grounding, 8" stranded wire leads. | Black | CR15BLKP2 | CR20BLKP2 |
| | Brown | CR15P2 | CR20P2 |
| | Gray | CR15GRYP2 | CR20GRYP2 |
| | Ivory | CR15IP2 | CR20IP2 |
| | Light Almond | CR15LAP2 | CR20LAP2 |
| | White | CR15WHIP2 | CR20WHIP2 |
| Pre-wired receptacles, Tamper-Resistant, smooth polycarbonate face, duplex, side wired only, self-grounding, 8" solid wire leads. | Black | CR15BLKTRP1 | CR20BLKTRP1 |
| | Brown | CR15TRP1 | CR20TRP1 |
| | Gray | CR15GRYTRP1 | CR20GRYTRP1 |
| | Ivory | CR15ITRP1 | CR20ITRP1 |
| | Light Almond | CR15LATRP1 | CR20LATRP1 |
| | White | CR15WHITRP1 | CR20WHITRP1 |
| Pre-wired receptacles, Tamper-Resistant, smooth polycarbonate face, duplex, side wired only, self-grounding, 8" stranded wire leads. | Black | CR15BLKTRP2 | CR20BLKTRP2 |
| | Brown | CR15TRP2 | CR20TRP2 |
| | Gray | CR15GRYTRP2 | CR20GRYTRP2 |
| | Ivory | CR15ITRP2 | CR20ITRP2 |
| | Light Almond | CR15LATRP2 | CR20LATRP2 |
| | White | CR15WHITRP2 | CR20WHITRP2 |

Note: See page A-47 for accessories.
See page Tech-10 for Tamper-Resistant descriptions.
See section O for wallplates.

Dimensions in Inches (mm)