


Dayton[®]**WASHDOWN PREMIUM
EFFICIENT MOTOR****CC082A**

MODEL NO. 2RKY5A		MFG.NO. WTL182T-4W	
		PH 3	
ENCL. TEFC		MAX.AMB. 40 °C	
HP 3/2		DUTY CONT.	
RPM 1765/1460		HZ 60/50	
VOLT 230/460		VOLT 190/380	
F.L.A. 8.0/4.0		F.L.A. 6.6/3.3	
S.F.A. 9.2/4.6		S.F.A. 7.6/3.8	
SER. FACT. 1.15	INS.CL. F	FRAME 182TC	
NEMA NOM.EFF. 89.5%	P.F. 0.81	CODE K	DES. B
BRG. SHAFT END 6308		BRG.OPPOSITE SHAFT END 6306	
Thermally Protected	NONE	DATE CODE 1207	

CONNECTION**WARNING**

Failure to properly operate and ground this motor may cause serious injury to property and/or personnel. Read operating instructions. Disconnect power before removing terminal box cover and/or performing maintenance. Ground in accordance with National Electric and local codes.

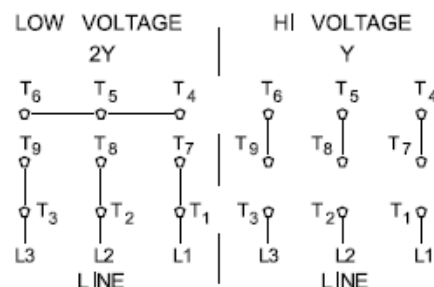

Mfd. For Dayton Electric Mfg. Co., Lake Forest, IL 60045 USA

Made in China