




T8 Light Fixtures & Lamps for Paint Booths

SPECIFICATIONS

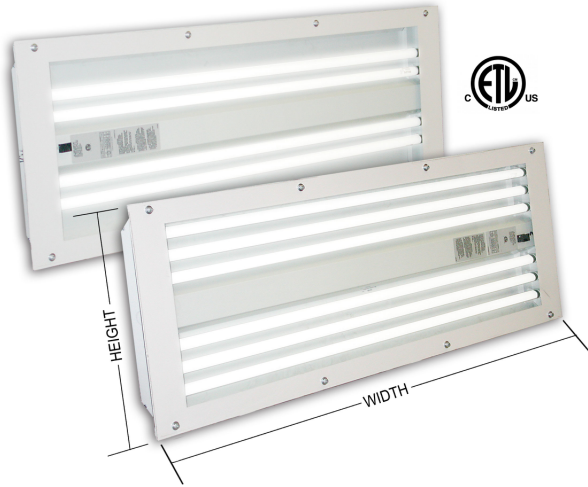

T8 FIXTURE FEATURES

- Energy-efficient T8, 32 watt electronic ballast
- ETL and ETL-C listed
- Enclosed and gasketed construction
- Twist-in lamp holders
- Inside access
- Interlock safety switch
- Easy lamp replacement and retrofits
- Template for installation into existing panels
- Corner enclosure (optional)

CLASS 1, DIVISION II - GROUPS A, B, C & D

These light fixtures were designed for locations in which volatile flammable liquids or gases are handled, processed or used. For an exceptional spraying environment, choose from six-tube, four-tube or corner fixture, tubes are included.

Fixture Models		Hertz	Voltage Range	Dual Input Amps	
Four-Tube	Six-Tube			Four-Tube	Six-Tube
LABW12-4	LABW12-6	50/60	120 - 277	0.94/0.41	1.42/0.62
LAR12-4	LAR12-6				
LAC12-4	LAC12-6				

Fixture Dimensions (Height x Width) Inches		
Fixture*	Lens	Panel Opening
18.5 x 51.538	18.876 x 52.118	18 x 50.25
21.684 x 50.837	26.898 x 52.399	24.812 x 50.223
18.5 x 51.538	18.876 x 52.118	18 x 50.25

* Dimensions are approximate

CLASS 1, DIVISION II - GROUPS A, B, C & D / CLASS 2, DIVISION II - GROUPS F & G

These light fixtures were designed for locations in which volatile flammable liquids or gases are handled, processed or used. Fixtures are suited for locations where combustible dust will not normally be in suspension nor will normal operations put dust in suspension, but where accumulation of dust may interfere with heat dissipation from electrical equipment or where accumulations near electrical equipment may be ignited. Fixtures are cost effective and are exceptional for spraying environments, tubes are included.

Fixture Models		Hertz	Voltage Range	Dual Input Amps	
Four-Tube	Six-Tube			Four-Tube	Six-Tube
LAB12-4-C2D2	LAB12-6-C2D2	50/60	120 - 277	0.94/0.41	1.42/0.62
LAR12-4-C2D2	LAR12-6-C2D2				
LAB12-4-LAM**	LAB12-6-LAM**				

** Not suitable for Paint Booth applications.

Fixture Dimensions (Height x Width) Inches		
Fixture***	Lens	Panel Opening
18.5 x 51.538	18.876 x 52.118	18 x 50.25
21.684 x 50.837	26.898 x 52.399	24.812 x 50.223
18.5 x 51.538	18.876 x 52.118	18 x 50.25

*** Dimensions are approximate

T8 LED LAMPS



GFS Part No.	Watt	Color Temperature	Brightness	CRI
230-281	32	5000 K	2850 Lumens	85