

# SPEAKMAN®

S-2460

## Installation, Maintenance & Operation Instructions ADJUSTA-SPRAY® SOLID BRASS WALL MOUNT SHOWER HEAD

### DESCRIPTION

Polished chrome plated solid brass ADJUSTA-SPRAY® wall mounted shower head, 2" face. 60 spray channels at three different angles to allow a full coverage shower. Drilled for but less mounting bolts. Water conserving pressure compensating AUTOFLO® device reduces flow to 2.5 GPM / 9.46 LPM maximum to meet existing ANSI A112.18.1M Standard. Vandal resistant standard. ½" NPTF back inlet.

### SPECIFICATIONS

SUPPLY INLET: ½" NPTF  
FLOW RATE: 2.5 GPM / 9.46 LPM MAXIMUM  
FLOW CONTROL: VARIABLE  
SHIPPING WEIGHT: 1.7 LBS

### OPTIONS:

<b>AP</b>	Anchor Plate Assembly with Mounting Screws
-----------	--

### INSTALLATION

Apply pipe thread tape in a clockwise direction to threads of supply nipple. Pipe joint compound may be used instead of tape. Turning in a clockwise direction, thread the shower head on to the supply nipple. Tighten & position with a strap wrench or a pair of soft jaw pliers. Mark and drill holes for mounting screws (not provided). Note: If necessary, remove shower head and use proper screw anchor (3) (not provided). Turn the water supply on and check for leaks. Tighten mounting screws (3).


### OPERATION

To adjust the spray pattern of the shower head, loosen the side set screw with a 3/32" hex wrench, then rotate the spray face with a 3/16" hex wrench to the desired spray. Tighten the side set screw.


### MAINTENANCE

The gleaming finish of your SPEAKMAN WATERSAVER® shower head can be cleaned by using mild soap and warm water. Dry immediately with a soft, clean cloth for best results. The flow control device limits water flow to 2.5 gallons per minute. The small orifices may become clogged with scale and other minerals found in potable water. To clean the flow regulator, remove the shower head from the wall, pull out the locking tab, dislodge the flow regulator and clean as necessary.


### ROUGH-IN MEASUREMENTS

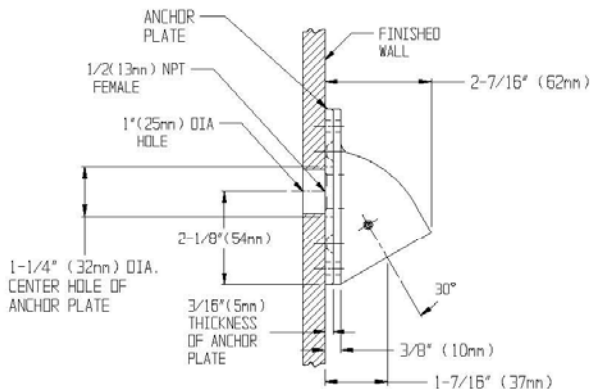

S-2460-AP

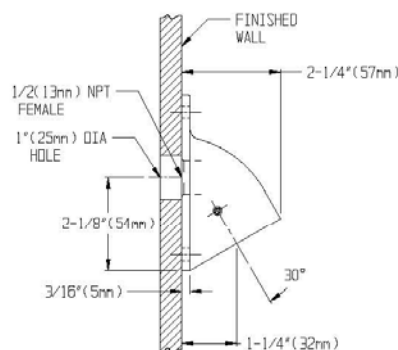

S-2460

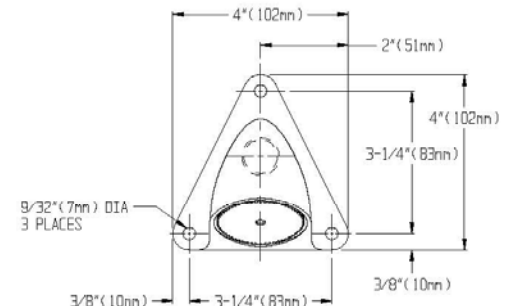

# SPEAKMAN®