 


# Straight Blade Devices








15 and 20 Ampere, 125 Volts

**IP20**  
SUITABILITY



## SNAPConnect® Extra Heavy Duty Hospital Grade Receptacles

Style Line® Decorator	Color	Catalog Number	Catalog Number
Hospital grade, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector on page A-15.	Black	<b>SNAP2172BKBA</b>	<b>SNAP2182BKBA</b>
	Brown	<b>SNAP2172A</b>	<b>SNAP2182A</b>
	Gray	<b>SNAP2172GYA</b>	<b>SNAP2182GYA</b>
	Ivory	<b>SNAP2172IA</b>	<b>SNAP2182IA</b>
	Light Almond	<b>SNAP2172LAA</b>	<b>SNAP2182LAA</b>
	Red	<b>SNAP2172RA</b>	<b>SNAP2182RA</b>
	White	<b>SNAP2172WA</b>	<b>SNAP2182WA</b>
Hospital grade, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector on page A-15. Assembled in USA.	Black	<b>SNAP2172BKNA</b>	<b>SNAP2182BKNA</b>
	Brown	<b>SNAP2172NA</b>	<b>SNAP2182NA</b>
	Gray	<b>SNAP2172GYNA</b>	<b>SNAP2182GYNA</b>
	Ivory	<b>SNAP2172INA</b>	<b>SNAP2182INA</b>
	Light Almond	<b>SNAP2172LANA</b>	<b>SNAP2182LANA</b>
	Red	<b>SNAP2172RNA</b>	<b>SNAP2182RNA</b>
	White	<b>SNAP2172WNA</b>	<b>SNAP2182WNA</b>
Hospital grade, Tamper-Resistant, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector on page A-15. Assembled in USA.	Black	<b>SNAP2172BKTRA</b>	<b>SNAP2182BKTRA</b>
	Brown	<b>SNAP2172TRA</b>	<b>SNAP2182TRA</b>
	Gray	<b>SNAP2172GYTRA</b>	<b>SNAP2182GYTRA</b>
	Ivory	<b>SNAP2172ITRA</b>	<b>SNAP2182ITRA</b>
	Light Almond	<b>SNAP2172LATRA</b>	<b>SNAP2182LATRA</b>
	Red	<b>SNAP2172RTRA</b>	<b>SNAP2182RTRA</b>
	White	<b>SNAP2172WTRA</b>	<b>SNAP2182WTRA</b>
Hospital grade, Tamper-Resistant, Split Circuit, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector on page A-15. Assembled in USA.	Black	<b>SNAP2172BKSCTRA</b>	<b>SNAP2182BKSCTRA</b>
	Brown	<b>SNAP2172SCTRA</b>	<b>SNAP2182SCTRA</b>
	Gray	<b>SNAP2172GYSCTRA</b>	<b>SNAP2182GYSCTRA</b>
	Ivory	<b>SNAP2172ISCTRA</b>	<b>SNAP2182ISCTRA</b>
	Light Almond	<b>SNAP2172LASCTRA</b>	<b>SNAP2182LASCTRA</b>
	Red	<b>SNAP2172RSCTRA</b>	<b>SNAP2182RSCTRA</b>
	White	<b>SNAP2172WSCTRA</b>	<b>SNAP2182WSCTRA</b>
Isolated ground <sup>A</sup> , Hospital grade, Tamper-Resistant.	Orange	<b>SNAP2172IGTRA</b>	<b>SNAP2182IGTRA</b>
	Red	<b>SNAP2172RIGTRA</b>	<b>SNAP2182RIGTRA</b>
Hospital grade, with Power Indicating LED, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector on page A-15. Assembled in USA.	Black	<b>SNAP2172BKBL</b>	<b>SNAP2182BKBL</b>
	Brown	<b>SNAP2172L</b>	<b>SNAP2182L</b>
	Gray	<b>SNAP2172GYL</b>	<b>SNAP2182GYL</b>
	Ivory	<b>SNAP2172IL</b>	<b>SNAP2182IL</b>
	Light Almond	<b>SNAP2172LAL</b>	<b>SNAP2182LAL</b>
	Red	<b>SNAP2172RL</b>	<b>SNAP2182RL</b>
	White	<b>SNAP2172WL</b>	<b>SNAP2182WL</b>
Isolated ground <sup>A</sup> , Hospital grade, with Power Indicating LED.	Orange	<b>SNAP2172IGL</b>	<b>SNAP2182IGL</b>
	Red	<b>SNAP2172RIGL</b>	<b>SNAP2182RIGL</b>
Hospital grade, Tamper-Resistant, with Power Indicating LED, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector on page A-15. Assembled in USA.	Black	<b>SNAP2172BKLTRA</b>	<b>SNAP2182BKLTRA</b>
	Brown	<b>SNAP2172LTRA</b>	<b>SNAP2182LTRA</b>
	Gray	<b>SNAP2172GYLTRA</b>	<b>SNAP2182GYLTRA</b>
	Ivory	<b>SNAP2172ILTRA</b>	<b>SNAP2182ILTRA</b>
	Light Almond	<b>SNAP2172LALTRA</b>	<b>SNAP2182LALTRA</b>
	Red	<b>SNAP2172RLTRA</b>	<b>SNAP2182RLTRA</b>
	White	<b>SNAP2172WLTRA</b>	<b>SNAP2182WLTRA</b>
Isolated ground <sup>A</sup> , Hospital grade, with Power Indicating LED.	Orange	<b>SNAP2172IGLTRA</b>	<b>SNAP2182IGLTRA</b>
	Red	<b>SNAP2172RIGLTRA</b>	<b>SNAP2182RIGLTRA</b>

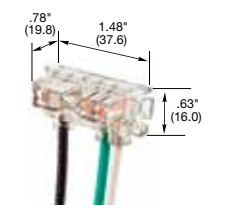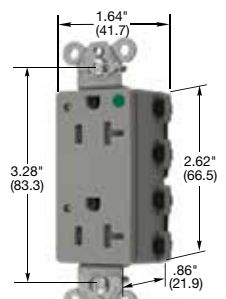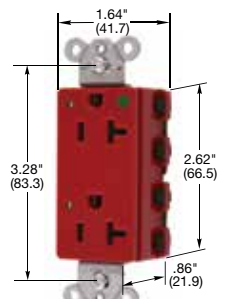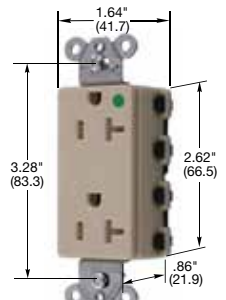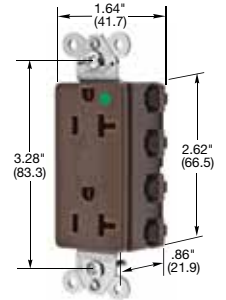

Note: <sup>A</sup>See section N additional information on isolated ground devices and section O for wallplates.  
See page A-5 for additional information on SNAPConnect features.  
See page Tech-10 for Tamper-Resistant and LED Power Indicators descriptions.  
See pages A-47 and A-48 for accessories.

## SNAPConnect® Right Angle Pigtailed Connector

Description	Wire Type	General Use	Assembled in USA
Clear right angle terminal with 6 inch leads #12 AWG THHN/THWN-2; Polycarbonate housing material.	Solid	<b>SNAP1RA</b>	<b>SNAP1RNA</b>
	Stranded	<b>SNAP2RA</b>	<b>SNAP2RNA</b>
Clear right angle terminal with 6 inch leads #12 AWG THHN/THWN-2; Polycarbonate housing material with WAGO terminals.	Solid	<b>SNAP1RAM2</b>	<b>SNAP1RNAM2</b>
	Stranded	<b>SNAP2RAM2</b>	<b>SNAP2RNAM2</b>

Note: For Assembled in USA products, must order connector with NA suffix.

Dimensions in Inches (mm)