


TECHNICAL DATA SHEET

Part#: 2844

Pliers - 2 Star Medium Chain Nose - SS
General purpose applications

The 2844 medium chain nose plier has an overall length is 5.75". It is made of stainless steel and features dual leaf springs for smooth action. It features a ergonomically molded antimicrobial Anti-Static grip (10^{10} ohms/sq surface resistivity) with dual leaf springs.

- Precision Level ★★
- Material SS (AISI 440)
- Surface Resistivity 10^{10} ohms/sq
- Shape Chain Nose
- Tip Size .035" x .04" (.875mm x 1mm)
- Tip Angle
- Tip Length 1.3"(32.5mm)
- Body Width
- Body Height
- OAL 5.75" (143.75mm)
- Weight (OZ) 4
- UPC 662847008733
- Schedule B 8203.20.60.30
- ECCN EAR99
- UNSPSC Code 27112148
- Country of Origin Pakistan
- Group Medium Nose

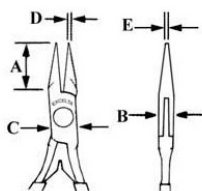

2844 Chain Nose Pliers
Smooth Jaw

- A= 1.182"
- B= .257"
- C= .375"
- D= .045"
- E= .055"

