

# Product data sheet

## Characteristics

# XVC6M3K

Harmony XVC, Monolithic precabled tower light, plastic, red orange green, Ø60, base mounting, steady, IP54, 100...240 V AC



### Main

Range of Product	Harmony XVC6
Product or Component Type	Complete pre-wired monolithic tower light
Beacon or indicator bank unit type	3 illuminated units
Sound signalling	Without
Mounting diameter	2.36 in (60 mm)
Component name	XVC
Light source	LED steady red LED steady orange LED steady green
[Us] rated supply voltage	100...240 V
Supply circuit type	AC

### Complementary

Material	Polycarbonate illuminated unit ABS (acrylonitrile butadiene-styrene) base unit PBT + ABS (UL94-V0) top cover
Product mounting	On base
Cable cross section	0.00 In <sup>2</sup> (0.83 mm <sup>2</sup> ) 0.00 in <sup>2</sup> (0.33 mm <sup>2</sup> )
AWG gauge	AWG 22 AWG 18
Cable length	29.53 In (750 mm) 33.46 in (850 mm)
Marking	CE
[Uimp] rated impulse withstand voltage	4 kV
Current Consumption	60 mA
Net Weight	1.21 lb(US) (0.55 kg)
Height	12.28 in (312 mm)

### Environment

Standards	EN/IEC 60947-5-1 EN/IEC 60947-1
Product Certifications	UL
Protective treatment	TC
Ambient Air Temperature for Storage	-31...158 °F (-35...70 °C)
Ambient air temperature for operation	14...122 °F (-10...50 °C)
Electrical shock protection class	Class I EN/IEC 61140
IP degree of protection	IP54 flat surface installation EN/IEC 60529

### Ordering and shipping details

Category	22617 - XVC TOWER LIGHTS
Discount Schedule	XV
GTIN	3606480072628
Nbr. of units in pkg.	1
Package weight(Lbs)	25.57 oz (725 g)

Returnability	No
Country of origin	ID

## Packing Units

Unit Type of Package 1	PCE
Package 1 Height	19.88 in (50.5 cm)
Package 1 width	3.43 in (8.7 cm)
Package 1 Length	3.43 in (8.7 cm)
Unit Type of Package 2	S04
Number of Units in Package 2	12
Package 2 Weight	21.94 lb(US) (9.952 kg)
Package 2 Height	11.81 in (30 cm)
Package 2 width	15.75 in (40 cm)
Package 2 Length	23.62 in (60 cm)
Unit Type of Package 3	P12
Number of Units in Package 3	240
Package 3 Weight	465.26 lb(US) (211.04 kg)
Package 3 Height	19.69 in (50 cm)
Package 3 width	31.50 in (80 cm)
Package 3 Length	47.24 in (120 cm)

## Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS Declaration</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
Circularity Profile	<a href="#">End Of Life Information</a>
WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.


## Contractual warranty

Warranty	18 months
----------	-----------

Pre-assembled and Pre-wired Tower Light

Dimensions

Below drawing shows the maximum configuration of the product. Select the number of stages according to the product characteristics in order to get b dimension.

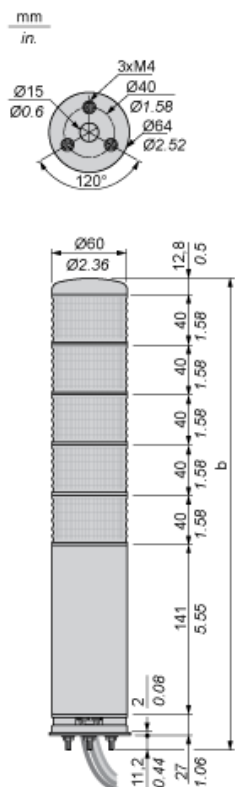

No. of illuminated units	b (mm)	b (in.)
1 stage	232	9.13
2 stages	272	10.71
3 stages	312	12.28
4 stages	352	13.86
5 stages	392	15.43

---

## Pre-assembled and Pre-wired Tower Light

---

### Mounting on Horizontal Support (Direct or with Fixing Plate)

Panel cut-out

