 



Rolling Trimmers

Professional Series

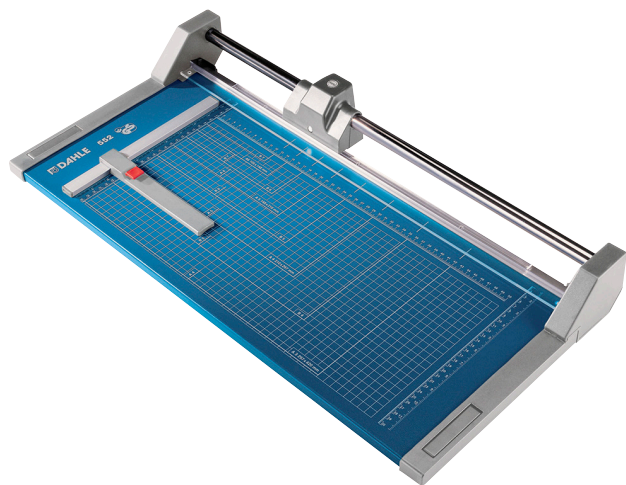

Rolling Trimmers are the new generation of paper cutters. Designed for safety and accuracy, the cutting blades are encased in a plastic housing that virtually eliminates the chance of personal injury. The rotary action of these trimmers allow the blade to cut in either direction and sharpen itself as it cuts. It's this self sharpening action that produces a clean burr-free cut and guarantees many years of smooth precise cutting.


Dahle Professional Rolling trimmers are designed for heavy duty applications where precision is essential. These trimmers are equipped with a ground self-sharpening blade that cuts in either direction. Most models in this series have a cutting capacity

of up to 20 sheets of paper at a time and are perfect for cutting paper, trimming photographs, and large format printing. These trimmers can be wall mounted and the two larger sizes have optional floor stands.

Dahle Professional Rolling Trimmers are available in 14 1/8", 20", 28 1/4", 37 3/4" and 51 1/8" cutting lengths and are a popular choice among professional photographers, print shops and graphic design agencies.

Features

- Blade is encased in a protective housing for safety
- Cuts up to 20 sheets of paper at a time (550 - 554)
- Self sharpening blade cuts in either direction
- Automatic paper clamp holds work securely
- Sturdy metal base with preprinted guides
- Imprinted protractor for angled cuts
- Optional stand maximizes floor space (556 - 558)
- German engineered for precision and accuracy

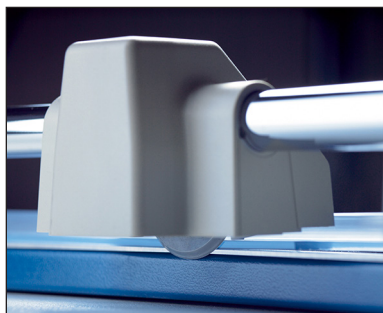

Features a ground self-sharpening rotary blade that cuts in either direction.



Automatic clamp holds work securely and prevents shifting while trimming.

Specifications

Item	Cut Length	Capacity	Dimensions	Floor Stand
550	14 1/8"	20 Sheets	22 3/4" x 14 1/8"	
552	20"	20 Sheets	27 3/4" x 14 1/8"	
554	28 1/4"	20 Sheets	36" x 14 1/8"	
556	37 3/4"	14 Sheets	45 1/2" x 14 1/8"	# 696
558	51 1/8"	12 Sheets	58 1/2" x 14 1/8"	# 698

