



*Saving Energy and Creating Healthy, Comfortable Environments*



Air Curtain Fans for ANSI/NSF37  
Customer Entry  
maximum mounting height is 7',  
for unheated single-speed only

*for outdoor use  
unheated models only*

***Maximum recommended mounting height is 7' for insect control,  
8' for environmental separation***



**Low-Profile  
air curtain**  
*Only 8 1/2" high*

# LOW PROFILE AIR CURTAIN MADE IN THE USA



Suitable for indoor & outdoor mounting - unheated only



\*PLUNGER DOOR SWITCH STANDARD WITH NSF 37 UNITS



\*THERMOSTAT, 24V DOOR SWITCH, TIME DELAY & TRANSFORMER STANDARD WITH HEATED UNITS

**For Front & Rear Doors,  
when there is minimal clearance above the door**

### Ideal Applications

- Kitchen Service Doors
- Restaurants
- Convenience Stores
- Grocery Stores
- Retail Stores
- Hospitals

### EPH Listed to NSF 37 Air Curtain:

- 8 1/2" high x 8" deep
- 1/5 hp single speed motor(s)
- Factory provided plunger door switch (to activate air curtain)
- White Powder Coated or Stainless Steel finish
- Wall & Top Mounting

### Electric Heated Air Curtain:

- 8 1/2" high x 13 1/2" deep
- 1/5 hp two speed motor(s)
- Factory installed fan speed switch
- White Powder Coated or Stainless Steel finish
- Wall & Top Mounting

### Benefits of Using a Berner Air Curtain:

#### SAVE ENERGY

An air curtain keeps outside air from entering and conditioned air from escaping when doors are opened.


#### CREATE COMFORT

Makes for a more comfortable environment inside for customers and employees.

#### PROMOTE INDOOR AIR QUALITY

Keeps insects, car fumes and dirt from entering the building.

## HOW A BERNER AIR CURTAIN WORKS

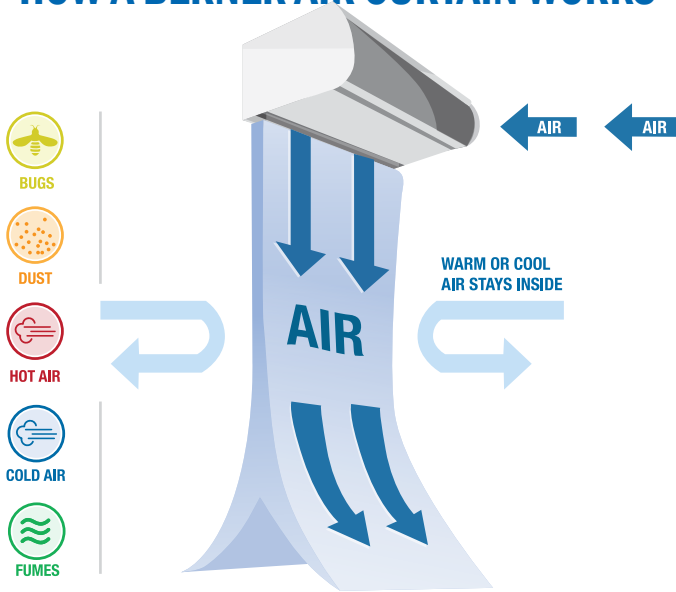

Low Profile, NSF Certified, Unheated Air Curtain		
SKU	Mfr. Model	Description
6JGF7	SLC07-1036AC-G	36" 115/208-240V
6JGF8	SLC07-1042AC-G	42" 115/208-240V
6JGF9	SLC07-1048AC-G	48" 115/208-240V
6JGG0	SLC07-1072AC-G	72" 115/208-240V



Five years parts warranty - Unheated  
Two years parts warranty - Heated

Low Profile, 2 Speed, Electric Heated Air Curtain		
SKU	Mfr. Model	Description
36WK02	CLC08-1036EX-G	36" 208/3
36WK05	CLC08-1036EZ-G	36" 460/3
36WK03	CLC08-1048EX-108-G	48" 208/3
36WK06	CLC08-1048EZ-100-G	48" 460/3
36WK04	CLC08-1072EX-150-G	72" 208/3
36WK07	CLC08-1072EZ-150-G	72" 460/3