

SpecSeal

CF

INTUMESCENT PADS


Closet Flange Firestop Gasket

SpecSeal® Closet Flange Firestop Gaskets are one-piece, molded rubber, intumescent pads that install beneath a 3 in (76 mm) or 4 in (102 mm) closet flange to effectively firestop the opening. The die cut rubber gasket is perforated to delineate removable inserts sized to accommodate various outer diameters of toilet flanges. Traditional firestopping methods require the firestop material to be applied around the pipe prior to setting the toilet flange, which can be problematic if the firestop material is not recessed a sufficient distance from the top to accommodate the throat of the flange. The alternative is to apply the firestopping from the underside of the floor, necessitating the use of ladders or lifts. SpecSeal® Closet Flange Firestop Gaskets solve the problem by providing a labor-friendly method of properly firestopping the opening.



Features & Benefits

- Seamless fit for fast, easy installation with no tools required
- Installs from the top, saving labor
- No caulk to clean up
- Always ready to use—no shelf life—no caulk tubes to dry out

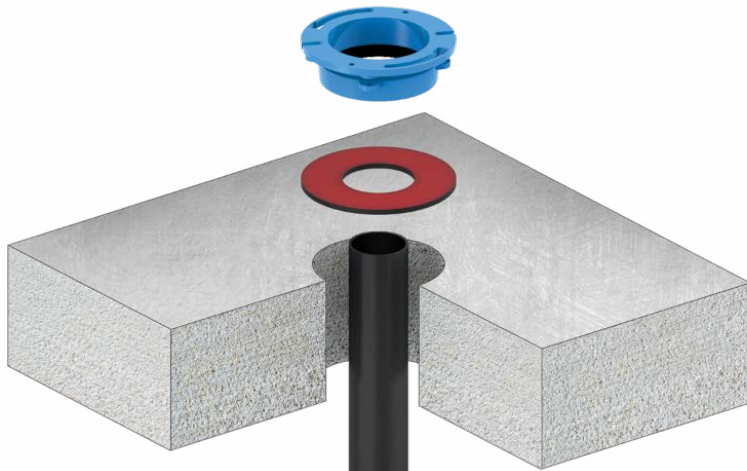

ORDERING INFORMATION

Catalog Number	UPC Number	Size	(UOM) Qty.	Case Qty.	Weight (Each)
CF34	73057303780	Gasket sized for 3" (76 mm) or 4" (102 mm)	1	10	0.20 lbs (0.09 kg)

TEST STANDARDS: ASTM E814 (UL 1479), CAN/ULC-S115



1-800-992-1180
stifirestop.com



Click here to learn more about



ZSTI3550 09020